

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

## Spiral Air Hose (with R1/4 nipple)




- Features**
- Has rubber elasticity and excellent restoring force.
- Specs**
- Working Fluid: Air
  - Fluid Temperature: -5 to 60° C
  - Working Pressure: 0.8MPa**
  - Coupling Connection Joint: R1/4 External Thread
  - Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Materials**
- Main Body: Polyurethane
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
231-5203	SAH-803	¥2,481	¥2,680	42	Yellow	2.0	780	180	10	190
231-5211	SAH-805	¥2,944	¥3,180	42	Yellow	4.0	1000	400	10	280
231-5220	SAH-808	¥4,018	¥4,340	42	Yellow	6.0	1230	630	10	370
231-5238	SAH-810	¥4,795	¥5,180	42	Yellow	8.0	1400	800	10	460

Contact us:0120-509-849 <http://www.orange-book.com/>

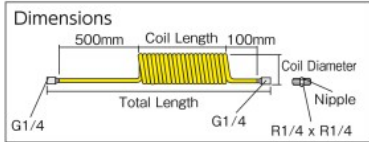

TRUSCO **Stock 38,650 Items**

## Spiral Air Hose (with coupling)




- Features**
- Because common coupling is installed as standard, detachment can be done smoothly with the air tool.
- Specs**
- Working Fluid: Air
  - Fluid Temperature: -5 to 60° C (to be freeze free)
  - Working Pressure: 0.8MPa**
  - Connecting Joint: 1/4 Coupling
  - Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Materials**
- Main Body: Polyurethane
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
336-2493	SAH-803C	¥2,870	¥3,100	42	Yellow	2.0	780	180	10	252
336-2507	SAH-805C	¥3,425	¥3,700	42	Yellow	4.0	1000	400	10	342
336-2515	SAH-808C	¥4,629	¥5,000	42	Yellow	6.0	1230	630	10	432
336-2523	SAH-810C	¥5,508	¥5,950	42	Yellow	8.0	1400	800	10	521

Contact us:0120-509-849 <http://www.orange-book.com/>

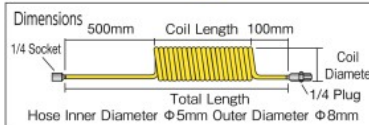

TRUSCO **Stock 38,650 Items**

## Spiral Air Hose (with coupling)




- Features**
- Has rubber elasticity and excellent restoring force.
- Specs**
- Working Fluid: Air
  - Fluid Temperature: -5 to 60° C
  - Working Pressure: 0.8MPa**
  - Coupling Joint: With G1/4 Internal Thread, G1/4 Universal Internal Thread
  - Hose Inner Diameter x Outer Diameter: 6.5 x 10mm
- Materials**
- Main Body: Polyurethane
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
231-5246	SAH-1003	¥2,944	¥3,180	52	Yellow	2.0	785	185	10	230
231-5254	SAH-1005	¥4,175	¥4,510	52	Yellow	4.0	1000	400	10	360

Contact us:0120-509-849 <http://www.orange-book.com/>

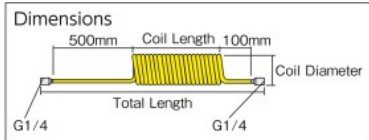

A pro-tool compact catalog that lists a wide variety of products all in one, including nearly every category on Orange-Book!

Published once every 2 years

Number of Products Listed: approx. **56,000** items

Number of Off-the-shelf Products: approx. **53,200**, off-the-shelf ratio **95%**

Number of Listed Manufacturers: approx. **1,419** companies

Number of Catalog Pages: approx. **2,700** pages

Order Code	Item No.	Price (tax not included)
858-5867	OBJM2018E	¥5,500



Artificial shock, bending, tension may cause damage.