

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items

Coupling for Lock Type Tube




- Features**
- Coupling for lock type tube (one touch connection) pursuing safety.
 - Safe with three-block structure.
 - Allows safety standard compliant workssuch as for pressing, cutting, automatic equipment, blowing out product scraps and with spray
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -20 to 60° C
 - **Working Pressure: 1.5MPa**
- Materials**
- Iron and Steel
- Origin**
- Japan



TL200-65SN

- Warning**
- Compatible with general coupling.

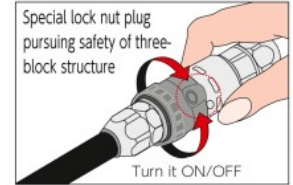

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Other Side Hose Size (mm)	SPQ (piece)	Weight (g)
284-1045	TL200-65SN	¥1,018	¥1,100	6.5 x 10.0	10	107
284-1053	TL200-85SN	¥1,157	¥1,250	8.5 x 12.5	10	114

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

"Swing Coupling" (auto lock type)



- Features**
- Safe for women or persons who are unfamiliar with the coupling because the connection can be done without pressure.
 - At the time of separation, residual pressure automatically comes off, recoil and unpleasant sounds are also reduced.
 - Can connect with common couplings. (except for some)
- Specs**
- Working Fluid: Air
 - Working temperature: -10 to 60° C
 - **Working Pressure: 1.5MPa**
- Materials**
- Aluminum, Brass
- Origin**
- Japan



TSC-23SM



TSC-23SF



TSC-23SH



TSRC-65SN

Video



Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Body Size (mm)	Applicable	SPQ (piece)	Weight (g)
309-3964	TSC-22SM	¥3,360	¥3,630	30 x 70	External Thread R1/4	12	120
309-3972	TSC-23SM	¥3,360	¥3,630	30 x 70	External Thread R3/8	12	120
309-3981	TSC-22SF	¥3,360	¥3,630	30 x 61	Internal Thread Rc1/4	12	120
309-3999	TSC-23SF	¥3,360	¥3,630	30 x 61	Internal Thread Rc3/8	12	120
309-4006	TSC-22SH	¥3,360	¥3,630	30 x 80	Hose Nipple Outer Diameter 9mm	12	120
309-4014	TSC-23SH	¥3,360	¥3,630	30 x 85	Hose Nipple Outer Diameter 10.5mm	12	120
309-4022	TSRC-65SN	¥3,666	¥3,960	30 x 152	For urethane hose, 6.5 to 7 x 9.5 to 10mm	10	160
309-4031	TSRC-80SN	¥3,971	¥4,290	30 x 152	For urethane hose, 8 to 8.5 x 12 to 12.5mm	10	160

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

"Air Adjust Holder"



- Features**
- Air pressure can be adjusted by pressing the air hose.
- Specs**
- Working Fluid: Air
 - Fluid temperature: 0 to 50° C
 - **Working Pressure: 0.7MPa**
- Materials**
- Main Body: Brass (chrome plate)
- Origin**
- Japan



Compatible Air Hose Outer Diameter

TAH-1



Example

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Air Hose Outer Diameter x Inner Diameter (mm)	SPQ (piece)	Weight (g)
285-4244	TAH-1	¥2,129	¥2,300	10 x 6.5	20	64

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

Drain Cock



- Features**
- Using a handle, opening and closing is easy.
 - Handle operation allows you to control drains more easily.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: 0 to 60° C
 - **Working Pressure: 1.5MPa**
- Materials**
- Main Body: Brass (nickel plate)
- Origin**
- Japan



TDC-P (plug type)



TDC-N

Connection Port Diameter R1/4



Example

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Connection Port Diameter	SPQ (piece)	Weight (g)
287-8976	TDC-P	¥787	¥850	43	Plug Type	10	52
287-8984	TDC-N	¥759	¥820	36	R1/4	10	50

Contact us:0120-509-849 <http://www.orange-book.com/>

Artificial shock, bending, tension may cause damage.