

Prices displayed include 8% tax.


For Replacement Nozzles, see p. 5-629 to 635

TRUSCO Stock 38,650 Items

Air Dusters



Use •Blowing of cutting chips etc. that is generated during machine processing.
Origin •Japan

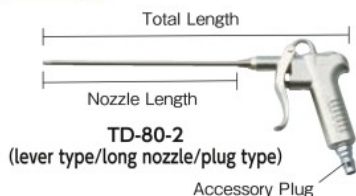

TD-80-2
(lever type/long nozzle/plug type)



TD-30-2
(button type/long nozzle/plug type)

Lever Type/Long Nozzle/Plug Type

Features •Since the air intake of the Main Body has a plug, it can be installed with one touch.
Specs •Max working pressure: 1MPa

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Air Mounting Outlet	Total Length (mm)	SPQ (piece)	Weight (g)
276-0240	TD-80-1	¥2,092	¥2,260	100	2	G1/8	1/4 Plug	188	12	226
299-9951	TD-80-2	¥2,361	¥2,550	200	2	G1/8	1/4 Plug	288	12	236
276-0258	TD-80-3	¥3,333	¥3,600	300	2	G1/8	1/4 Plug	388	12	247
276-0266	TD-80-5	¥4,611	¥4,980	500	2	G1/8	1/4 Plug	588	12	267

Button Type/Long Nozzle/Plug Type

Features •With a plug which can attach air hose with one touch.
Specs •Max working pressure: 1MPa

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Air Mounting Outlet	Total Length (mm)	SPQ (piece)	Weight (g)
276-0291	TD-30-1	¥2,037	¥2,200	100	2	G1/8	1/4 Plug	185	12	213
299-9943	TD-30-2	¥2,314	¥2,500	200	2	G1/8	1/4 Plug	285	12	222
281-7136	TD-30-3	¥3,240	¥3,500	300	2	G1/8	1/4 Plug	385	12	233
281-7144	TD-30-5	¥4,536	¥4,900	500	2	G1/8	1/4 Plug	585	12	254

Lever Type/Nipple Type

Features •We adopt a large trigger (trigger) that is less tired even when used for a long time.
Specs •Max working pressure: 1MPa

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Air Mounting Outlet	Total Length (mm)	SPQ (piece)	Weight (g)
227-5937	TD-70	¥1,278	¥1,380	24	2	G1/8	G1/4	112	10	215

Lever Type/Increase Nozzle/Nipple Type

Features •Increase the amount of input air by about 2.7 times taking in outside air.
Specs •Max working pressure: 1MPa

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Air Mounting Outlet	Total Length (mm)	SPQ (piece)	Weight (g)
231-4592	TD-73	¥2,916	¥3,150	47	15	G1/8	G1/4	135	10	260

Lever Type/For high pressure/With flow adjustment/Plug Type

Features •Air duster gun that can be used from high pressure compatible compressors.
•We adopt a large trigger (trigger type) that is less tired even when used for a long time.
Specs •Max Working Pressure: 2.8MPa
•With flow adjustment nozzle

For High Pressure Hoses, see p. 3-371

Warning

- The high pressure plug is used for the hose mounting port.
- Please use with a high pressure hose.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Air Mounting Outlet	Total Length (mm)	SPQ (piece)	Weight (g)
327-2770	TD-K80	¥2,870	¥3,100	27	2	G1/8	Special Plug for High Pressure	115	10	250

Lever Type/Long Nozzle/Nipple Type

Features •We adopt a large trigger (trigger) that is less tired even when used for a long time.
Specs •Max working pressure: 1MPa

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Air Mounting Outlet	Total Length (mm)	SPQ (piece)	Weight (g)
227-5945	TD-70-1	¥1,713	¥1,850	100	2	G1/8	G1/4	188	10	220
352-4663	TD-70-3	¥2,314	¥2,500	300	2	G1/8	G1/4	388	10	236
352-4655	TD-70-5	¥2,731	¥2,950	500	2	G1/8	G1/4	588	10	253

Lever Parts

Features •This is the replacement lever set for Air Duster.
Materials •Main Body: Iron

Order Unit: 1 Set


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Compatible Model	SPQ (set)	Weight (g/set)
855-1282	TDW-EPSET	¥417	¥450	TD-80 series,TD-K80 series,TD-70 series,TD70-R,TD-73	10	21

Contact us:0120-509-849 <http://www.orange-book.com/>



TD-K80
(lever type/for high pressure/with flow adjustment/plug type)

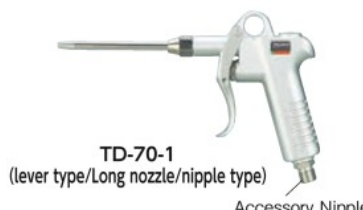

TD-70-1
(lever type/Long nozzle/nipple type)



TDW-EPSET
(lever parts)