


Air Duster Nozzles

The number next to the logo mark indicates items in stock for each brand.

TRUSCO Stock **38,650** Items **Air Duster Nozzles/High Rigid Type**

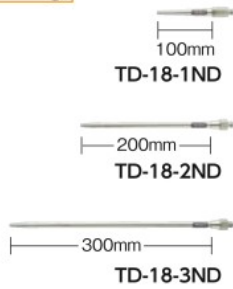

Features

- Replacement is possible according to applications.
- Wide and high rigid type having the outer diameter of 9mm.
- Japan

Origin

- Japan


SPQ: 10 Pieces

Order Unit: 1 Piece

| TRUSCO NAKAYAMA CORPORATION | | | | | | | |
|-----------------------------|-----------|-------------------|------------------|--------------------|------------------------------|----------------------|------------|
| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Nozzle Length (mm) | Nozzle Opening Diameter (mm) | Nozzle Mounting Port | Weight (g) |
| 381-8187 | TD-18-1ND | ¥ 666 | ¥ 720 | 100 | 2 | G1/8 | 62 |
| 381-8195 | TD-18-2ND | ¥ 1,221 | ¥ 1,320 | 200 | 2 | G1/8 | 80 |
| 381-8209 | TD-18-3ND | ¥ 2,074 | ¥ 2,240 | 300 | 2 | G1/8 | 110 |
| 381-8217 | TD-18-5ND | ¥ 3,185 | ¥ 3,440 | 500 | 2 | G1/8 | 170 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

KINKI Stock **102** Items **Air Duster Nozzles**

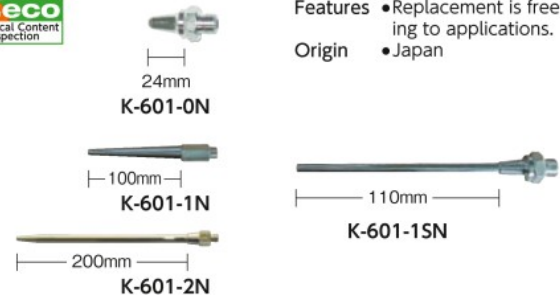

Features

- Replacement is free according to applications.
- Japan

Origin


- Japan

Order Unit: 1 Piece (Price revision date: Apr. 2015) KINKI SEISAKUSYO

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Nozzle Length (mm) | Nozzle Opening Diameter (mm) | Nozzle Mounting Port | SPQ (piece) | Weight (g) |
|------------|-----------|-------------------|------------------|--------------------|------------------------------|----------------------|-------------|------------|
| 103-5517 | K-601-0N | ¥ 379 | ¥ 410 | 24 | 2 | G1/8 | 20 | 16 |
| 103-5525 | K-601-1N | ¥ 741 | ¥ 800 | 100 | 2 | G1/8 | 10 | 62 |
| 391-3627 | K-601-2N | ¥ 1,296 | ¥ 1,400 | 200 | 2 | G1/8 | 10 | 80 |
| 103-5533 | K-601-3N | ¥ 2,361 | ¥ 2,550 | 300 | 2 | G1/8 | 10 | 110 |
| 103-5541 | K-601-5N | ¥ 3,564 | ¥ 3,850 | 500 | 2 | G1/8 | 10 | 170 |
| 292-4587 | K-601-1SN | ¥ 1,018 | ¥ 1,100 | 110 | 3 | G1/8 | 10 | 28 |

Contact us: 06-6700-2601 <http://www.kinki-seisakusho.co.jp/>

TRUSCO Stock **38,650** Items **Ultra Light Magnesium Nozzle for Air Duster**

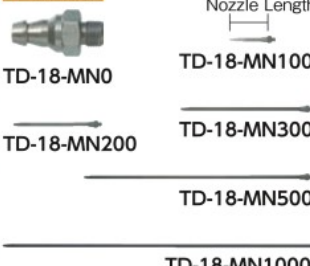


Features

- Weight is reduced to approximately 1/3 of conventional products, and air blowing work is reduced.
- China

Origin

- China

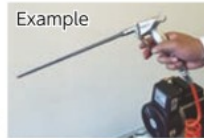


Order Unit: 1 Piece

| TRUSCO NAKAYAMA CORPORATION | | | | | | | |
|-----------------------------|--------------|-------------------|------------------|--------------------|------------------------------|----------------------|------------|
| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Nozzle Length (mm) | Nozzle Opening Diameter (mm) | Nozzle Mounting Port | Weight (g) |
| 768-5068 | TD-18-MN0 | ¥ 1,018 | ¥ 1,100 | 30 | 3.5 | G1/8 | 6 |
| 768-5114 | TD-18-MN100 | ¥ 2,314 | ¥ 2,500 | 100 | 3.5 | G1/8 | 15 |
| 768-5084 | TD-18-MN200 | ¥ 2,592 | ¥ 2,800 | 200 | 3.5 | G1/8 | 26 |
| 768-5092 | TD-18-MN300 | ¥ 2,916 | ¥ 3,150 | 300 | 3.5 | G1/8 | 34 |
| 768-5106 | TD-18-MN500 | ¥ 4,351 | ¥ 4,700 | 500 | 3.5 | G1/8 | 54 |
| 768-5076 | TD-18-MN1000 | ¥ 12,960 | ¥ 14,000 | 1000 | 3.5 | G1/8 | 106 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

KURITA Stock **47** Items **Air Gun Nozzle**

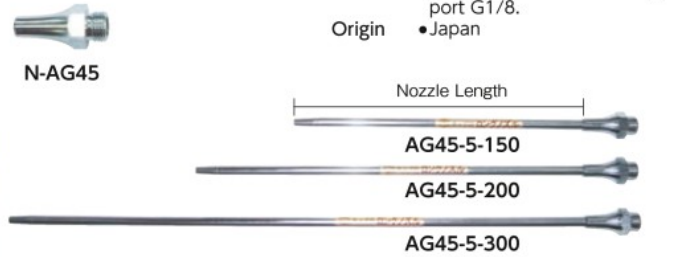

Features

- Can be used for the air gun having the nozzle mounting port G1/8.
- Japan

Origin

- Japan

Order Unit: 1 Piece (Price revision date: Jan. 2015) KURITA SEISAKUSHO

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Nozzle Length (mm) | Nozzle Opening Diameter (mm) | Nozzle Mounting Port | SPQ (piece) | Weight (g) |
|------------|------------|-------------------|------------------|--------------------|------------------------------|----------------------|-------------|------------|
| 363-4621 | N-AG45 | ¥ 284 | ¥ 283 | 22 | 2.0 | G1/8 | 20 | 10.5 |
| 363-4639 | AG45-5-150 | ¥ 853 | ¥ 850 | 170 | 2.3 | G1/8 | 20 | 24.0 |
| 363-4647 | AG45-5-200 | ¥ 973 | ¥ 970 | 220 | 2.3 | G1/8 | 20 | 28.0 |
| 363-4655 | AG45-5-300 | ¥ 1,094 | ¥ 1,090 | 320 | 2.3 | G1/8 | 20 | 36.0 |
| 363-4663 | AG45-5-500 | ¥ 1,455 | ¥ 1,450 | 500 | 2.3 | G1/8 | 20 | 53.0 |

Contact us: 03-5638-8261 <http://www.cup-kurita.co.jp/>

TRUSCO Stock **38,650** Items **Long Nozzle with Handle for Air Duster**




Features

- Long nozzle that fits the hand and is easy to turn.
- With handle, air blow at remote place can be done securely.
- China

Origin

- China

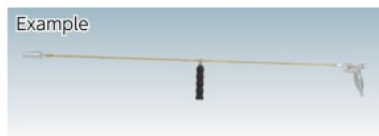

Warning


- Nozzle is not included. Purchase commercial product.

Order Unit: 1 Piece

| TRUSCO NAKAYAMA CORPORATION | | | | | | | |
|-----------------------------|-----------|-------------------|------------------|--------------------|------------------------------|----------------------|------------|
| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Nozzle Length (mm) | Nozzle Opening Diameter (mm) | Nozzle Mounting Port | Weight (g) |
| 768-5025 | TD18-10LN | ¥ 12,034 | ¥ 13,000 | 1000 | 3.5 | G1/8 | 320 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

KINKI Stock **102** Items **Super Long Nozzle**

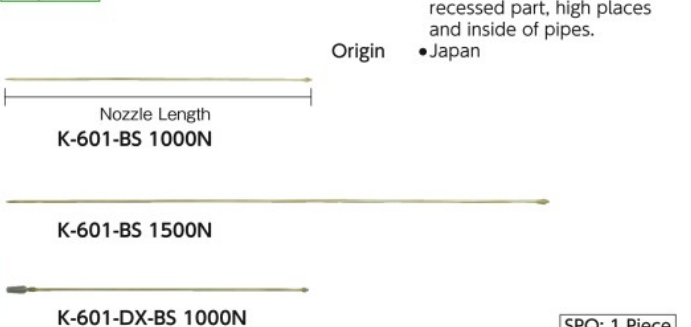

Features

- Ideal for air-blow at places that are hard to reach, recessed part, high places and inside of pipes.
- Japan

Origin

- Japan

SPQ: 1 Piece

Order Unit: 1 Piece KINKI SEISAKUSYO

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Nozzle Length (mm) | Nozzle Opening Diameter (mm) | Nozzle Mounting Port | Weight (g) |
|------------|-------------------|-------------------|------------------|--------------------|------------------------------|----------------------|------------|
| 363-1061 | K-601-BS 1000N | ¥ 6,750 | — | 1000 | 2 | G1/8 | 308 |
| 363-1079 | K-601-BS 1500N | ¥ 9,450 | — | 1500 | 2 | G1/8 | 456 |
| 363-1087 | K-601-DX-BS 1000N | ¥ 9,450 | — | 1000 | 16 | G1/8 | 362 |

Contact us: 06-6700-2601 <http://www.kinki-seisakusho.co.jp/>