

CBN Bars (shank diameter 3mm)

Stock 322 Items

5-1217

Prices displayed include 8% tax.

For Micro Grinders, see p. 5-242 to 268

 

TRUSCO **Stock 38,650 Items**

High End Black Bar (#325)



Com.eco Chemical Content Inspection Com. Drawing

Features • For finishing machining/chamfering.
Origin • Japan

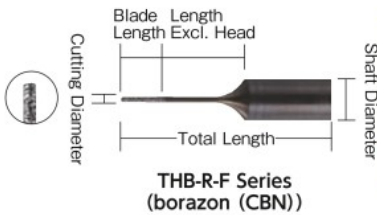

Borazon (CBN)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
299-5166	THB-R005F	¥1,636	¥2,020	325	0.5 x 3 x 3 x 50	6	80000	1	2.3
299-5174	THB-R006F	¥1,636	¥2,020	325	0.6 x 3 x 3 x 50	6	80000	1	2.3
299-5182	THB-R007F	¥1,636	¥2,020	325	0.7 x 3 x 3 x 50	6	80000	1	2.3
299-5191	THB-R008F	¥1,636	¥2,020	325	0.8 x 3 x 3 x 50	6	80000	1	2.3
299-5204	THB-R009F	¥1,636	¥2,020	325	0.9 x 3 x 3 x 50	6	80000	1	2.3
299-5212	THB-R010F	¥1,636	¥2,020	325	1.0 x 3 x 3 x 50	6	80000	1	2.3

For deep holes borazon (CBN)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
299-5280	THB-L005F	¥1,652	¥2,040	325	0.5 x 3 x 3 x 50	9	80000	1	2.2
299-5298	THB-L006F	¥1,652	¥2,040	325	0.6 x 3 x 3 x 50	9	80000	1	2.2
299-5301	THB-L007F	¥1,652	¥2,040	325	0.7 x 3 x 3 x 50	9	80000	1	2.2
299-5310	THB-L008F	¥1,652	¥2,040	325	0.8 x 3 x 3 x 50	9	80000	1	2.2
299-5328	THB-L009F	¥1,652	¥2,040	325	0.9 x 3 x 3 x 50	9	80000	1	2.2
299-5336	THB-L010F	¥1,652	¥2,040	325	1.0 x 3 x 3 x 50	9	80000	1	2.2

Diamond

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
299-5077	THB-R005DF	¥1,636	¥2,020	325	0.5 x 3 x 3 x 50	6	80000	1	2.3
299-5085	THB-R006DF	¥1,636	¥2,020	325	0.6 x 3 x 3 x 50	6	80000	1	2.3
299-5093	THB-R007DF	¥1,636	¥2,020	325	0.7 x 3 x 3 x 50	6	80000	1	2.3
299-5107	THB-R008DF	¥1,636	¥2,020	325	0.8 x 3 x 3 x 50	6	80000	1	2.3
299-5115	THB-R009DF	¥1,636	¥2,020	325	0.9 x 3 x 3 x 50	6	80000	1	2.3
299-5123	THB-R010DF	¥1,636	¥2,020	325	1.0 x 3 x 3 x 50	6	80000	1	2.3

For diamond deep holes

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
299-5492	THB-L005DF	¥1,652	¥2,040	325	0.5 x 3 x 3 x 50	9	80000	1	2.2
299-5506	THB-L006DF	¥1,652	¥2,040	325	0.6 x 3 x 3 x 50	9	80000	1	2.2
299-5514	THB-L007DF	¥1,652	¥2,040	325	0.7 x 3 x 3 x 50	9	80000	1	2.2
299-5522	THB-L008DF	¥1,652	¥2,040	325	0.8 x 3 x 3 x 50	9	80000	1	2.2
299-5531	THB-L009DF	¥1,652	¥2,040	325	0.9 x 3 x 3 x 50	9	80000	1	2.2
299-5549	THB-L010DF	¥1,652	¥2,040	325	1.0 x 3 x 3 x 50	9	80000	1	2.2

Contact us: 0120-509-849 <http://www.orange-book.com/>



TRUSCO **Stock 38,650 Items**

High End Black Bar (#600)



Com.eco Chemical Content Inspection Com. Drawing

Features • For precision finishing processing.
Origin • Japan

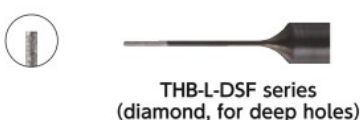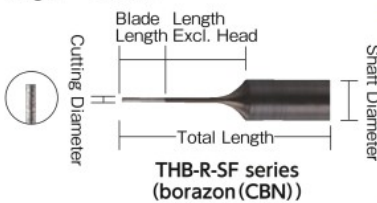

Borazon (CBN)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
299-5221	THB-R005SF	¥1,661	¥2,050	600	0.5 x 3 x 3 x 50	6	80000	1	2.3
299-5239	THB-R006SF	¥1,661	¥2,050	600	0.6 x 3 x 3 x 50	6	80000	1	2.3
299-5247	THB-R007SF	¥1,661	¥2,050	600	0.7 x 3 x 3 x 50	6	80000	1	2.3

For deep holes borazon (CBN)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
299-5344	THB-L005SF	¥1,661	¥2,050	600	0.5 x 3 x 3 x 50	9	80000	1	2.2
299-5352	THB-L006SF	¥1,661	¥2,050	600	0.6 x 3 x 3 x 50	9	80000	1	2.2
299-5361	THB-L007SF	¥1,661	¥2,050	600	0.7 x 3 x 3 x 50	9	80000	1	2.2

Diamond

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
323-7478	THB-R005DSF	¥1,661	¥2,050	600	0.5 x 3 x 3 x 50	6	80000	1	2.3
323-7486	THB-R006DSF	¥1,661	¥2,050	600	0.6 x 3 x 3 x 50	6	80000	1	2.3
323-7494	THB-R007DSF	¥1,661	¥2,050	600	0.7 x 3 x 3 x 50	6	80000	1	2.3

For diamond deep holes

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Cutting Diameter x Blade Length x Shaft Diameter x Total Length (mm)	Length Excl. Head (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
310-5750	THB-L005DSF	¥1,661	¥2,050	600	0.5 x 3 x 3 x 50	9	80000	1	2.2
310-5768	THB-L006DSF	¥1,661	¥2,050	600	0.6 x 3 x 3 x 50	9	80000	1	2.2
310-5776	THB-L007DSF	¥1,661	¥2,050	600	0.7 x 3 x 3 x 50	9	80000	1	2.2

Contact us: 0120-509-849 <http://www.orange-book.com/>