

# Spatter Sheets

The number next to the logo mark indicates items in stock for each brand.

Welding Machines

Engine Welders

Spot Welders

Plasma Cutting Machines

Welding Tables

Welding Rods

Accessories for Welding Equipment

Welding Scale Removers

Gas Torches

Gas Burners

Gas Cutting Equipments

Gas Regulators

Brazing Filler Metals

Welding Masks

Protective Eyewears for Welding

Protective Tools for Welding

Spatter Sheets

Protective Fences for Welding

Industrial Markers

**TRUSCO** Stock **38,650** Items

## Spatter Sheet "Basic One Side" (one side coating)



TSP-2BS

**Features** • It is a cheap product of class B accepted. • Dual purpose type for repelling of (front) and adhesion (back) to sparks and slag. • Non-asbestos/non-ceramic safe product, also containing no fibers that induce skin irritation. **Front Repel Back Attach**

**Use** • As a welding spark receiving sheet, fire proof cover, fire proof curtain, and curing sheet.

**Specs** • JIS A 1323 Class B Passing No. 04A2169 • (foundation) Japan Fire Retardant Association Flame Retardant Performance Test compliant No. CO050009 • Thickness: Approx. 1mm

**Materials** • Flame Resistant Fiber Fabrics • Silicone (white) Single-sided Processing **Origin** • Japan

**Order Unit:** 1 Sheet | **Blue** Factory direct | No freight charge | Excluding remote islands | **TRUSCO NAKAYAMA CORPORATION**

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
284-7221	TSP-1BS	¥ 5,971	¥ 6,450	No. 1	4	880	880	920 x 920	20	0.6
284-7230	TSP-2BS	¥ 11,757	¥ 12,700	No. 2	12	440	470	920 x 1920	10	1.2
284-7248	TSP-4BS	¥ 22,217	¥ 24,000	No. 4	16	470	470	1920 x 1920	5	2.4
284-7256	TSP-6BS	¥ 33,603	¥ 36,300	No. 6	20	470	480	1920 x 2920	5	3.6
284-7264	TSP-RBS	¥ 131,174	¥ 141,700	Roll	-	-	-	1000 x 30m	1	18.0
★855-8134	TSP-RBS-W	¥ 262,347	¥ 283,400	Roll	-	-	-	2000 x 30m	1	36.0

**Sell by Piece Type** Features • You can order with your preferred length (m unit).

**Order Unit:** 1m | Factory direct | Shipping not included

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★284-7272	TSP-RBS-CUT	¥ 5,045	¥ 5,450	Cut	-	-	-	1000 x In meter unit	0.6
★467-4014	TSP-RBS-CUT-W	¥ 10,090	¥ 10,900	Cut	-	-	-	2000 x In meter unit	1.2

Contact us: 0120-509-849 <http://www.orange-book.com/>

**TRUSCO** Stock **38,650** Items

## Spatter Sheet "Alpha" (one side coating)



SPS-2A

**Features** • Plain weave economical type that is affordable and easy to handle since the single side coating makes it soft. • Dual purpose type for repelling of (front) and adhesion (back) to sparks and slag. • Non-asbestos/non-ceramic safe product, also containing no fibers that induce skin irritation. **Front Repel Back Attach**

**Use** • As a welding spark receiving sheet, fire proof cover, fire proof curtain, and curing sheet.

**Specs** • JIS A 1323 Class C Passing No. 03A0412 • (foundation) Japan Fire Retardant Association Flame Retardant Performance Test compliant No. CO030040 • Thickness: Approx. 0.7mm

**Materials** • Flame Resistant Fiber Fabrics • Silicone (white) Single-sided Processing **Origin** • Japan

**Order Unit:** 1 Sheet | **Blue** Factory direct | No freight charge | Excluding remote islands | **TRUSCO NAKAYAMA CORPORATION**

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
120-9779	SPS-1A	¥ 4,999	¥ 5,400	No. 1	4	880	880	920 x 920	20	0.43
120-9787	SPS-2A	¥ 9,813	¥ 10,600	No. 2	12	440	470	920 x 1920	20	0.86
120-9795	SPS-4A	¥ 19,625	¥ 21,200	No. 4	16	470	470	1920 x 1920	10	1.72
120-9809	SPS-6A	¥ 29,345	¥ 31,700	No. 6	20	470	480	1920 x 2920	10	2.58
120-9817	SPS-RA	¥ 108,864	¥ 117,600	Roll	-	-	-	1000 x 30m	1	12.90
★855-8133	SPS-RA-W	¥ 217,728	¥ 235,200	Roll	-	-	-	2000 x 30m	1	25.80

**Sell by Piece Type** Features • You can order with your preferred length (m unit).


**Order Unit:** 1m | Factory direct | Shipping not included

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★467-3999	SPS-RA-CUT	¥ 4,073	¥ 4,400	Cut	-	-	-	1000 x In meter unit	0.43
★467-4006	SPS-RA-CUT-W	¥ 8,146	¥ 8,800	Cut	-	-	-	2000 x In meter unit	0.86

Contact us: 0120-509-849 <http://www.orange-book.com/>

**ASAHI SANGYO** Stock **29** Items

## Spatter Sheet "Beta" (double coated)

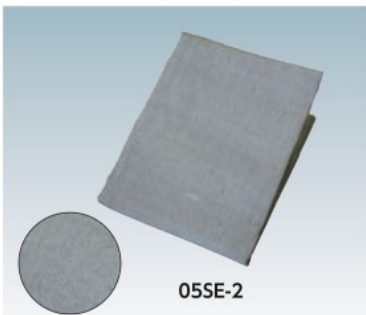

05SE-2

**Features** • Optimum for fire proof curtains and heat insulating curtains. • Twill weave, and excellent in tensile strength. • Repels received sparks. **Repel**

**Use** • Spatter sheet for welding spark scattering prevention. • As spark curing. • For welding spark scattering prevention curtains.

**Specs** • JIS A 1323 Class C Passed Product • Thickness: 0.6mm

**Materials** • Flame Resistant Fiber Fabrics • Silicone resin double-sided processing **Origin** • Japan

**Order Unit:** 1 Sheet | **Blue** Factory direct | Shipping not included | **ASAHI SANGYO**

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
836-4135	05SE-1	¥ 3,857	¥ 5,000	No. 1	4	880	880	920 x 920	20	0.4
★431-0144	05SE-2	¥ 7,637	¥ 9,900	No. 2	12	440	470	920 x 1920	10	0.8
★431-0152	05SE-4	¥ 15,274	¥ 19,800	No. 4	16	470	470	1920 x 1920	6	1.6
★836-4136	05SE-6	¥ 22,989	¥ 29,800	No. 6	20	470	480	1920 x 2920	4	2.4

**Roll Type**

**Order Unit:** 1 Roll | Factory direct | No freight charge | Excluding remote islands

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (roll)	Weight (kg)
						A	B			
★836-4137	05SE-R	¥ 92,571	¥ 120,000	Roll	-	-	-	1000 x 30m	1	12
★836-4138	05SE-WR	¥ 150,429	¥ 195,000	Roll	-	-	-	2000 x 30m	1	24

Contact us: 052-761-4321 <http://www.asahisangyou.com/>