

Prices displayed include 8% tax.


TRUSCO **Stock 38,650 Items**

Flat Bar (5 piece sets)




Specs •Long Hole: 11 x 40mm
Origin •Japan

TKF3-180-S

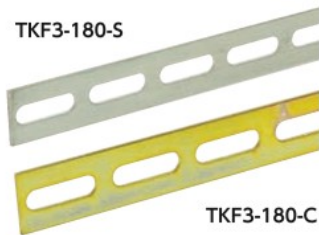

TKF3-180-C

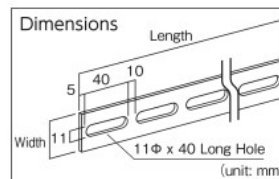

| Item No. | Materials |
|------------|---|
| TKF3-180-S | Stainless Steel (SUS304) |
| TKF3-180-C | Steel (SPHC) (chromate plating finishing) |

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per set) | MSRP (per set) | W x L (mm) | Thickness (mm) | Q'ty Per Set (piece) | SPQ (set) | Weight (kg/set) |
|------------|------------|-----------------|----------------|------------|----------------|----------------------|-----------|-----------------|
| 490-0171 | TKF3-180-S | ¥22,217 | ¥24,000 | 36 x 1800 | 3.0 | 5 | 1 | 8 |
| 490-0189 | TKF3-180-C | ¥4,999 | ¥5,400 | 36 x 1800 | 3.2 | 5 | 1 | 8 |

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Perforated U Fitting (4 piece set)




Specs •Long Hole: 11 x 40mm
Origin •Japan

TKU3-240-S
TKU3-240-U



TKU3H-240-C

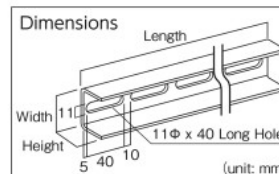

| Item No. | Materials |
|-------------|---|
| TKU3-240-S | Stainless Steel (SUS304) |
| TKU3H-240-C | Steel (SPHC) (chromate plating finishing) |
| TKU3-240-U | Steel (SPHC) (unichrome-plated) |

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per set) | MSRP (per set) | W x H x L (mm) | Thickness (mm) | Q'ty Per Set (piece) | SPQ (set) | Weight (kg/set) |
|------------|-------------|-----------------|----------------|------------------|----------------|----------------------|-----------|-----------------|
| 490-0146 | TKU3-240-S | ¥40,731 | ¥44,000 | 44.0 x 17 x 2400 | 3.0 | 4 | 1 | 15 |
| 490-0162 | TKU3H-240-C | ¥17,403 | ¥18,800 | 44.4 x 25 x 2400 | 3.2 | 4 | 1 | 20 |
| 490-0154 | TKU3-240-U | ¥13,886 | ¥15,000 | 44.4 x 17 x 2400 | 3.2 | 4 | 1 | 16 |

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Angle Cover



Features •Installation and removal is easy and can be used repeatedly.
•Safety is secured by fitting onto the cutting surface of the angle.
•Please apply an adhesive and fix the cover if necessary.
Use •For angle end surface.
Specs •Soft PVC
•For L type angle 40 corners, 50 corners
Materials •Soft PVC
Origin •Japan




TVL-40-2-BK (black)



TVL-40-2-GY (ash)



TVL-40-2-Y (yellow)

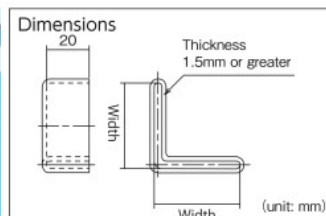

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | Color | W x L (mm) | Supporting angle thickness (mm) | Q'ty Per Bag (piece) | SPQ (bag) | Weight (g/bag) |
|------------|--------------|-----------------|----------------|--------|------------|---------------------------------|----------------------|-----------|----------------|
| 781-3503 | TVL-40-2-BK | ¥454 | ¥490 | Black | 40 x 20 | 3.0, 3.2 | 2 | 80 | 18 |
| 781-3511 | TVL-40-2-GY | ¥454 | ¥490 | Ash | 40 x 20 | 3.0, 3.2 | 2 | 80 | 18 |
| 781-3520 | TVL-40-2-Y | ¥454 | ¥490 | Yellow | 40 x 20 | 3.0, 3.2 | 2 | 80 | 18 |
| 781-3562 | TVL-50-2-BK | ¥573 | ¥620 | Black | 50 x 20 | 4.0, 4.5 | 2 | 60 | 22 |
| 781-3571 | TVL-50-2-GY | ¥573 | ¥620 | Ash | 50 x 20 | 4.0, 4.5 | 2 | 60 | 22 |
| 781-3589 | TVL-50-2-Y | ¥573 | ¥620 | Yellow | 50 x 20 | 4.0, 4.5 | 2 | 60 | 22 |
| 781-3473 | TVL-40-10-BK | ¥1,426 | ¥1,540 | Black | 40 x 20 | 3.0, 3.2 | 10 | 20 | 90 |
| 781-3481 | TVL-40-10-GY | ¥1,426 | ¥1,540 | Ash | 40 x 20 | 3.0, 3.2 | 10 | 20 | 90 |
| 781-3490 | TVL-40-10-Y | ¥1,426 | ¥1,540 | Yellow | 40 x 20 | 3.0, 3.2 | 10 | 20 | 90 |
| 781-3538 | TVL-50-10-BK | ¥1,713 | ¥1,850 | Black | 50 x 20 | 4.0, 4.5 | 10 | 20 | 110 |
| 781-3546 | TVL-50-10-GY | ¥1,713 | ¥1,850 | Ash | 50 x 20 | 4.0, 4.5 | 10 | 20 | 110 |
| 781-3554 | TVL-50-10-Y | ¥1,713 | ¥1,850 | Yellow | 50 x 20 | 4.0, 4.5 | 10 | 20 | 110 |

Contact us:0120-509-849 <http://www.orange-book.com/>