

For Single Roller Mounting Steps, see p. 8-1262

The number next to the logo mark indicates items in stock for each brand.

Steel Roller Conveyors

Stainless Steel Roller Conveyors

Aluminum Roller Conveyors

Resin Roller Conveyors

Extension Roller Conveyors

Wheels Conveyors

Ball Casters Units

Upward Ball Casters

Downward Ball Casters

Upward/Downward Combined Use Ball Casters

Cleanroom Type Ball Casters

Ball Casters for Special Purpose

Motor Pulleys, Motor Rollers

Belt Conveyors

Mini Belt Conveyors

Belts



KGS Type Stand



KGS4060

Materials •Made of stainless steel
Origin •Japan

Height of roller upper surface (±45)

| Applicable model type | MA22 MU38 MUS38 | MA45A MR42 MR50B | MA57 MU60 MUS60 |
|-----------------------|-----------------|------------------|-----------------|
| | KGS-□40 | 390 | 395 |
| KGS-□45 | 440 | 445 | 480 |
| KGS-□50 | 490 | 495 | 530 |
| KGS-□55 | 540 | 545 | 580 |
| KGS-□60 | 590 | 595 | 630 |
| KGS-□65 | 640 | 645 | 680 |
| KGS-□70 | 690 | 695 | 730 |
| KGS-□75 | 740 | 745 | 780 |
| KGS-□80 | 790 | 795 | 830 |

Item No. Example (order code 858-4219)

KGS - 20 - 40

Display Roller Width (cm) Nominal height in (cm)

*Inside □ indicates the roller width.
(example: 750H for 400RW→KGS-4075)

Order Unit: 1 Piece | Factory direct | Freight: ¥2,000 | Excluding remote islands |

MISUZU KOKI Co.Ltd.

| Nominal height (mm) | Roller Width (W) (mm) | | | | | | | | | |
|---------------------|-----------------------|-------------------|------------|-------------------|------------|-------------------|------------|-------------------|------------|-------------------|
| | 200 | | 300 | | 400 | | 500 | | 600 | |
| | Order Code | Price (per piece) | Order Code | Price (per piece) | Order Code | Price (per piece) | Order Code | Price (per piece) | Order Code | Price (per piece) |
| 400 | ★858-4219 | ¥26,325 | ★858-4234 | ¥26,325 | ★858-4249 | ¥26,325 | ★858-4264 | ¥26,325 | ★858-4279 | ¥26,325 |
| 450 | ★858-4220 | ¥26,325 | ★858-4235 | ¥26,325 | ★858-4250 | ¥26,325 | ★858-4265 | ¥26,325 | ★858-4280 | ¥26,325 |
| 500 | ★858-4221 | ¥26,325 | ★858-4236 | ¥26,325 | ★858-4251 | ¥26,325 | ★858-4266 | ¥26,325 | ★858-4281 | ¥26,325 |
| 550 | ★858-4222 | ¥26,325 | ★858-4237 | ¥26,325 | ★858-4252 | ¥26,325 | ★858-4267 | ¥26,325 | ★858-4282 | ¥26,325 |
| 600 | ★858-4223 | ¥27,783 | ★858-4238 | ¥27,783 | ★858-4253 | ¥27,783 | ★858-4268 | ¥27,783 | ★858-4283 | ¥27,783 |
| 650 | ★858-4224 | ¥27,783 | ★858-4239 | ¥27,783 | ★858-4254 | ¥27,783 | ★858-4269 | ¥27,783 | ★858-4284 | ¥27,783 |
| 700 | ★858-4225 | ¥27,783 | ★858-4240 | ¥27,783 | ★858-4255 | ¥27,783 | ★858-4270 | ¥27,783 | ★858-4285 | ¥27,783 |
| 750 | ★858-4226 | ¥29,727 | ★858-4241 | ¥29,727 | ★858-4256 | ¥29,727 | ★858-4271 | ¥29,727 | ★858-4286 | ¥29,727 |
| 800 | ★858-4227 | ¥29,727 | ★858-4242 | ¥29,727 | ★858-4257 | ¥29,727 | ★858-4272 | ¥29,727 | ★858-4287 | ¥29,727 |


Contact us:059-397-3220 <http://www.misuzukoki.jp/>

| Nominal height (mm) | Roller width W (mm) | | | | |
|---------------------|---------------------|-----|-----|-----|-----|
| | 200 | 300 | 400 | 500 | 600 |
| 400 | 3.4 | 3.4 | 3.4 | 3.4 | 3.4 |
| 450 | 3.6 | 3.6 | 3.6 | 3.6 | 3.6 |
| 500 | 3.8 | 3.8 | 3.8 | 3.8 | 3.8 |
| 550 | 4.0 | 4.0 | 4.0 | 4.0 | 4.0 |
| 600 | 4.2 | 4.2 | 4.2 | 4.2 | 4.2 |
| 650 | 4.4 | 4.4 | 4.4 | 4.4 | 4.4 |
| 700 | 4.5 | 4.5 | 4.5 | 4.5 | 4.5 |
| 750 | 4.7 | 4.7 | 4.7 | 4.7 | 4.7 |
| 800 | 4.9 | 4.9 | 4.9 | 4.9 | 4.9 |



Stock 38,650 Items

Roller with Shaft

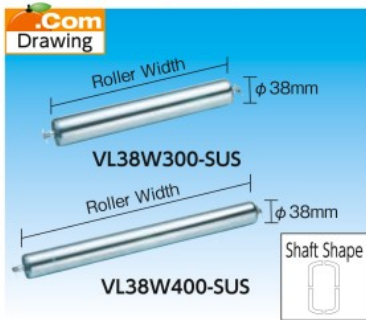

Features •It is a roller that can be installed as a replacement for each manufacturer's conveyor by adjusting the auxiliary color. It is an all stainless steel roller with water resistant and chemical resistant specs.


Materials •Stainless Steel (SUS304) Accessories •Auxiliary Color, Pin Origin •Japan

In case of combining into Maki/Meiki type




•An auxiliary collar (accessory) is required for installation.

In case of combining into Misuzu, Terauchi, and Central type

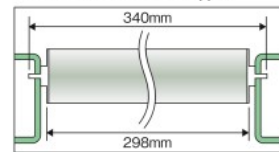

•When installing, auxiliary collar (accessory) is unnecessary.

In case of combining into Okura type

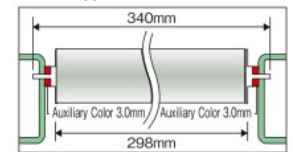

•An auxiliary collar (accessory) is required for installation.

Roller diameter 38mm, thickness 1.0mm/stainless steel

Order Unit: 1 Piece | Factory direct | Freight: ¥800 | Excluding remote islands |

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Roller Diameter (mm) | Thickness (mm) | Roller Width (W) (mm) | Shaft Width (mm) | Shaft Diameter (mm) | Roller Load Capacity (kg/piece) | SPQ (piece) | Weight (kg) |
|------------|--------------|-------------------|------------------|----------------------|----------------|-----------------------|------------------|---------------------|---------------------------------|-------------|-------------|
| ★461-2574 | VL38W300-SUS | ¥3,230 | ¥3,490 | 38 | 1.0 | 298 | 340 | 12 | 70 | 1 | 0.39 |
| ★461-2582 | VL38W400-SUS | ¥3,990 | ¥4,310 | 38 | 1.0 | 388 | 440 | 12 | 70 | 1 | 0.52 |
| ★461-2591 | VL38W500-SUS | ¥4,360 | ¥4,710 | 38 | 1.0 | 488 | 540 | 12 | 60 | 1 | 0.65 |
| ★461-2604 | VL38W600-SUS | ¥5,295 | ¥5,720 | 38 | 1.0 | 598 | 652 | 12 | 50 | 1 | 0.78 |

Roller diameter 60.5mm, thickness 1.5mm/stainless steel

Order Unit: 1 Piece | Factory direct | Freight: ¥800 | Excluding remote islands |

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Roller Diameter (mm) | Thickness (mm) | Roller Width (W) (mm) | Shaft Width (mm) | Shaft Diameter (mm) | Roller Load Capacity (kg/piece) | SPQ (piece) | Weight (kg) |
|------------|---------------|-------------------|------------------|----------------------|----------------|-----------------------|------------------|---------------------|---------------------------------|-------------|-------------|
| ★461-2612 | VL605W300-SUS | ¥5,601 | ¥6,050 | 60.5 | 1.5 | 298 | 340 | 12 | 100 | 1 | 0.92 |
| ★461-2621 | VL605W400-SUS | ¥6,786 | ¥7,330 | 60.5 | 1.5 | 388 | 440 | 12 | 100 | 1 | 1.08 |
| ★461-2639 | VL605W500-SUS | ¥7,730 | ¥8,350 | 60.5 | 1.5 | 488 | 540 | 12 | 90 | 1 | 1.24 |
| ★461-2647 | VL605W600-SUS | ¥8,850 | ¥9,560 | 60.5 | 1.5 | 598 | 652 | 12 | 65 | 1 | 1.40 |

Contact us:0120-509-849 <http://www.orange-book.com/>