

Wheel Conveyors for Picking Rack

For Pipe Systems, see p. 8-384 to 396

The number next to the logo mark indicates items in stock for each brand.

Conveyors

Steel Roller Conveyors

Stainless Steel Roller Conveyors

Aluminum Roller Conveyors

Resin Roller Conveyors

Extension Roller Conveyors

Wheels Conveyors

Ball Casters Units

Upward Ball Casters

Downward Ball Casters

Upward/Downward Combined Use Ball Casters

Cleanroom Type Ball Casters

Ball Casters for Special Purpose

Motor Pulleys, Motor Rollers


Belt Conveyors

Mini Belt Conveyors


Belts




Wheel Conveyors for Picking Rack (wheel diameter 36mm)

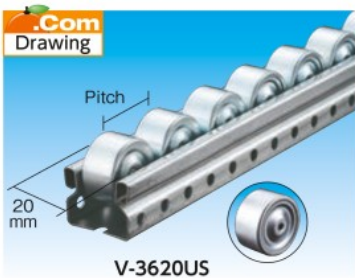


- Features**
- Steel wheels are used.
 - Excellent in resistance to oil and impact.
- Use**
- For mounting FIFO racks, hand carts and line pallets.
- Specs**
- Load per wheel: 15kg
 - Wheel width: 20mm
- Materials**
- Frame: Hot dip zinc-plated steel plate
 - Wheel: Steel
 - Wheel surface treatment: Trivalent uni-chrome-plated finishing
- Origin**
- Japan

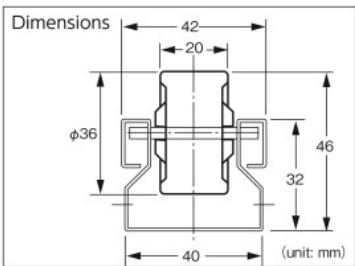

Wheel Conveyors for Picking Rack (wheel diameter 36mm)

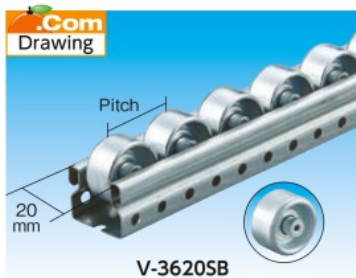

- Features**
- Steel wheels with bearings are used.
 - Excellent in oil resistance, durability and impact resistance.
- Use**
- For mounting FIFO racks, hand carts and line pallets.
- Specs**
- Load per wheel: 15kg
 - Wheel width: 20mm
- Materials**
- Frame: Hot dip zinc-plated steel plate
 - Wheel: Steel bearing type
 - Wheel surface treatment: Trivalent uni-chrome-plated finishing
- Origin**
- Japan

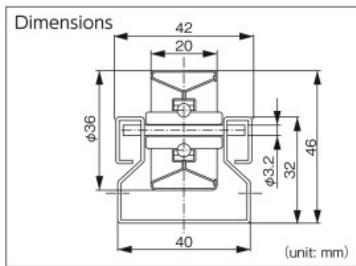

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	Conveyor Length (mm)	SPQ (piece)	Weight (kg)
★285-2233	V-3620US-40-1000	¥ 3,323	¥ 3,590	40	1000	1	1.80
★285-2241	V-3620US-40-1500	¥ 4,971	¥ 5,370	40	1500	1	2.70
★285-2250	V-3620US-40-1800	¥ 5,962	¥ 6,440	40	1800	1	3.24
★285-2268	V-3620US-40-2000	¥ 6,628	¥ 7,160	40	2000	1	3.60
★285-2276	V-3620US-40-2400	¥ 7,952	¥ 8,590	40	2400	1	4.32
★285-2284	V-3620US-40-3000	¥ 10,016	¥ 10,820	40	3000	1	5.40
★285-2292	V-3620US-50-1000	¥ 2,879	¥ 3,110	50	1000	1	1.45
★285-2306	V-3620US-50-1500	¥ 4,332	¥ 4,680	50	1500	1	2.17
★285-2314	V-3620US-50-1800	¥ 5,184	¥ 5,600	50	1800	1	2.51
★285-2322	V-3620US-50-2000	¥ 5,757	¥ 6,220	50	2000	1	2.90
★285-2331	V-3620US-50-2400	¥ 6,915	¥ 7,470	50	2400	1	3.48
★285-2349	V-3620US-50-3000	¥ 8,637	¥ 9,330	50	3000	1	4.35

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	Conveyor Length (mm)	SPQ (piece)	Weight (kg)
★854-9343	V-3620SB-40-1000	¥ 4,723	¥ 5,830	40	1000	1	2.23
★854-9344	V-3620SB-40-1500	¥ 7,088	¥ 8,750	40	1500	1	3.35
★854-9345	V-3620SB-40-2000	¥ 9,445	¥ 11,660	40	2000	1	4.46
★854-9346	V-3620SB-40-2400	¥ 11,340	¥ 14,000	40	2400	1	5.35
★854-9347	V-3620SB-40-3000	¥ 14,167	¥ 17,490	40	3000	1	6.69
★854-9348	V-3620SB-50-1000	¥ 3,929	¥ 4,850	50	1000	1	2.01
★854-9349	V-3620SB-50-1500	¥ 5,897	¥ 7,280	50	1500	1	3.02
★854-9350	V-3620SB-50-2000	¥ 7,866	¥ 9,710	50	2000	1	4.02
★854-9351	V-3620SB-50-2400	¥ 9,438	¥ 11,650	50	2400	1	4.82
★854-9352	V-3620SB-50-3000	¥ 11,794	¥ 14,560	50	3000	1	6.03

Contact us:0120-509-849 <http://www.orange-book.com/>

Made to order Inquiry for conveyor safety cover

ISEL Co.Ltd.

Safety cover machine shutter system

Problem I want a cover on the conveyor to protect the products from dust!

Solution We will make custom made covers to fit your conveyor.



Conveyor in hand

+



Machine shutter

=



Shutter for conveyor (image of adopted shutter)

Adoption of machine shutter benefits

1. The cover has a sliding door so there is no protrusion.
2. The shutter is light and opens/closes smoothly.
3. Workability improves with the wide opening.

ISEL Co.Ltd. TEL: 072-991-0450 <http://isel.jp/>