 



Prices displayed include 8% tax.



Stock
38,650
Items

Ball Conveyor



For Single Ball Casters U-8B/U-8P,
see p. 8-1318, 1323

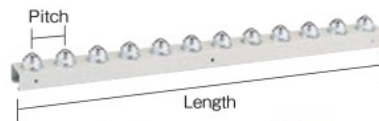

U8B-90-75



U-8B

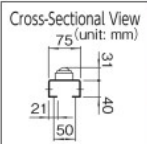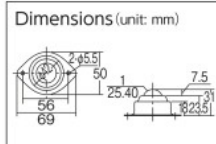

- Features
- It is an upward ball conveyor.
- Specs
- Allowable Load Per Ball: 30kg
- Materials
- Frame: Steel
 - Ball Caster Main Body: Steel
- Origin
- Japan


Steel Ball Conveyor

- Features
- Ball casters are made of durable steel.
- Materials
- Main Ball: Steel

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION



Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	L x W x H (mm)	Used Ball Caster (unit)	SPQ (piece)	Weight (kg)
512-3151	U8B-45-75	¥ 5,832	¥ 6,300	75	450 x 75 x 71	U-8B x 6	1	1.9
512-3178	U8B-60-75	¥ 7,683	¥ 8,300	75	600 x 75 x 71	U-8B x 8	1	2.5
512-3194	U8B-75-75	¥ 9,442	¥ 10,200	75	750 x 75 x 71	U-8B x 10	1	3.2
512-3216	U8B-90-75	¥ 11,201	¥ 12,100	75	900 x 75 x 71	U-8B x 12	1	3.8
512-3143	U8B-45-100	¥ 5,277	¥ 5,700	100	450 x 75 x 71	U-8B x 5	1	1.7
512-3160	U8B-60-100	¥ 6,573	¥ 7,100	100	600 x 75 x 71	U-8B x 6	1	2.2
512-3186	U8B-75-100	¥ 8,331	¥ 9,000	100	750 x 75 x 71	U-8B x 8	1	2.9
512-3208	U8B-90-100	¥ 9,535	¥ 10,300	100	900 x 75 x 71	U-8B x 9	1	3.4

 

U8P-75-75



U-8P

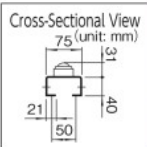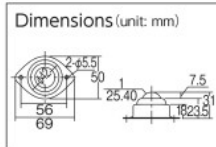

Plastic Ball Conveyor

- Features
- Ball caster is quiet sound, scratch resistant and resin type.
- Materials
- Main Ball: Polypropylene (PP)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	L x W x H (mm)	Used Ball Caster (unit)	SPQ (piece)	Weight (kg)
512-3232	U8P-45-75	¥ 7,128	¥ 7,700	75	450 x 75 x 71	U-8P x 6	1	1.5
512-3259	U8P-60-75	¥ 9,257	¥ 10,000	75	600 x 75 x 71	U-8P x 8	1	2.0
512-3275	U8P-75-75	¥ 11,479	¥ 12,400	75	750 x 75 x 71	U-8P x 10	1	2.6
512-3291	U8P-90-75	¥ 13,701	¥ 14,800	75	900 x 75 x 71	U-8P x 12	1	3.1
512-3224	U8P-45-100	¥ 6,295	¥ 6,800	100	450 x 75 x 71	U-8P x 5	1	1.4
512-3241	U8P-60-100	¥ 7,683	¥ 8,300	100	600 x 75 x 71	U-8P x 6	1	1.9
512-3267	U8P-75-100	¥ 9,905	¥ 10,700	100	750 x 75 x 71	U-8P x 8	1	2.4
512-3283	U8P-90-100	¥ 11,294	¥ 12,200	100	900 x 75 x 71	U-8P x 9	1	2.8

Ball Conveyor Table

- Features
- Most suitable for turning table, packing table and working table.
 - Most suitable for assembly with conveyor system.
 - The size can be changed by combining the ball conveyor.
 - With the ball conveyor attached, the height is 740mm.
- Specs
- Equal Load: 300kg
- Materials
- Steel



FTU-4545

(ball conveyor table)



U8B-45-75

(uses 6 pieces ball conveyors)



Set Example



Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x D x H (mm)	Maximum Used Quantity of Ball Conveyor (pieces)	SPQ (piece)	Weight (kg)
512-3305	FTU-4545	¥ 16,385	¥ 17,700	455 x 455 x 670	U8B (U8P) -45-100 x 6 U8B (U8P) -45-75 x 6	1	14.3
512-3313	FTU-6060	¥ 19,440	¥ 21,000	605 x 605 x 670	U8B (U8P) -60-100 x 8 U8B (U8P) -60-75 x 8	1	17.2
512-3321	FTU-7575	¥ 23,328	¥ 25,200	755 x 755 x 670	U8B (U8P) -75-100 x 10 U8B (U8P) -75-75 x 10	1	20.2
512-3330	FTU-9090	¥ 27,494	¥ 29,700	905 x 905 x 670	U8B (U8P) -90-100 x 12 U8B (U8P) -90-75 x 12	1	23.7

Contact us: 0120-509-849 <http://www.orange-book.com/>

 


Stock
38,650
Items

Ball Caster Unit





For Single Ball Caster T-8LB,
see p. 8-1318



TU-9-100



T-8LB

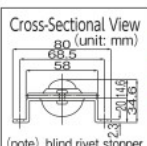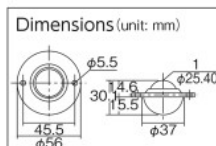

(note) blind rivet stopper

- Features
- Ball casters are made of durable steel.
 - It is an upward ball conveyor.
- Specs
- Allowable Load Per Ball: 30kg
- Materials
- Frame: Steel
 - Ball Caster Main Body: Steel
 - Main Ball: Steel
- Origin
- Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	L x W x H (mm)	Used Ball Caster (unit)	SPQ (piece)	Weight (kg)
★ 461-0946	TU-9-75	¥ 12,118	¥ 13,090	75	900 x 80 x 34.6	T-8LB x 12	1	3.2
★ 461-0920	TU-18-75	¥ 22,402	¥ 24,200	75	1800 x 80 x 34.6	T-8LB x 24	1	6.4
★ 461-0938	TU-9-100	¥ 9,572	¥ 10,340	100	900 x 80 x 34.6	T-8LB x 9	1	2.8
★ 461-0911	TU-18-100	¥ 18,329	¥ 19,800	100	1800 x 80 x 34.6	T-8LB x 18	1	5.6

Contact us: 0120-509-849 <http://www.orange-book.com/>