

Prices displayed include 8% tax.


For Submersible Pumps, see p. 7-696 to 715

TRUSCO
 Stock 38,650 Items

Coupling for Braided Hose



- Features**
- Coupling for braided hose
 - Compatible with RoHS directive (low cadmium brass).
- Specs**
- Working Fluid: Water, Air
 - Fluid Temperature: 0 to 70° C
 - Working Pressure: 1.0MPa
- Materials**
- Brass (low cadmium type)
- Origin**
- Japan

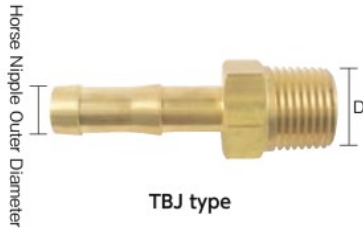

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Connection Port Diameter D	Connection Port Diameter (horse nipple outer diameter) (mm)	SPQ (piece)	Weight (g)
496-4136	TBJ-6	¥ 583	¥ 630	R1/4	6.0	20	25
496-4144	TBJ-8	¥ 630	¥ 680	R1/4	8.0	20	25
496-4152	TBJ-9	¥ 676	¥ 730	R3/8	9.0	10	35
496-4055	TBJ-10	¥ 703	¥ 760	R3/8	10.0	10	35
496-4063	TBJ-12	¥1,018	¥1,100	R1/2	12.0	10	65
496-4071	TBJ-15	¥1,111	¥1,200	R1/2	15.0	10	75
496-4080	TBJ-19	¥1,759	¥1,900	R3/4	19.0	10	135
496-4098	TBJ-25	¥2,777	¥3,000	R1	25.0	4	260
496-4101	TBJ-32	¥5,091	¥5,500	R1 1/4	32.0	2	345
496-4110	TBJ-38	¥6,295	¥6,800	R1 1/2	38.0	2	405
496-4128	TBJ-50	¥8,702	¥9,400	R2	50.0	2	710

Contact us:0120-509-849 <http://www.orange-book.com/>

ASOH
 Stock 895 Items

Hose Nipple



- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: -50 to 150° C
 - Working Pressure: 3.45MPa
- Materials**
- Brass (C3771)
- Origin**
- Japan



HN-1034

Order Unit: 1 Piece

ASOH Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Connection Port Diameter D	Connection Port Diameter (horse nipple outer diameter) (mm)	SPQ (piece)	Weight (g)
325-6081	HN-1827	¥1,174	¥1,170	R1	27	15	195
325-6057	HN-1034	¥2,257	¥2,250	R1 1/4	34	12	415
325-6065	HN-1040	¥3,009	¥3,000	R1 1/2	40	10	550
325-6073	HN-1052	¥5,516	¥5,500	R2	52	6	1080

Contact us:06-6755-3301 <http://www.asoh.co.jp/>

SANYOKASEI
 Stock 54 Items

"Jointer Set"

- Specs**
- Working Fluid: Water
 - Fluid Temperature: Room Temperature
- Materials**
- ABS resin
- Origin**
- Japan



JT-SH Type

Connection Method



Example

Order Unit: 1 Piece

SANYOKASEI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Connection Port Diameter (horse nipple outer diameter) (mm)	SPQ (piece)	Weight (g)
215-5915	JT-SH15BK	¥ 551	-	15	1	30.2
215-5923	JT-SH19BK	¥ 582	-	19	1	33.2
215-5931	JT-SH25BK	¥ 690	-	25	1	49.6
215-5940	JT-SH32BK	¥ 795	-	32	1	61.8
215-5958	JT-SH38BK	¥ 921	-	38	1	84.6
215-5966	JT-SH50BK	¥1,462	-	50	1	157.2

Contact us:0268-62-1631 <http://www.sanyokasei.co.jp/>

TRUSCO
 Stock 38,650 Items

Hose Protection Spring for Braided Hose



- Features**
- Attaching it to a bending part of a hose prevent the hose from squashing and folding (kinking), and you can flow fluid in the hose with security.
 - The band on the one side of the spring can fix a hose and the spring does not slip off.
 - Resistant to rust since it is made entirely out of stainless steel.
- Use**
- Prevention of folding of the bending part when arranging the hose.
- Specs**
- With flat band
- Materials**
- Stainless Steel (SUS304)
- Origin**
- Japan



THPS type

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable hose (mm) Inner diameter x outer diameter	Length of spring (stationary state)	Recommended spring pitch when installed (mm)	SPQ (piece)	Weight (g)
495-9850	THPS-12	¥2,407	¥2,600	12 x 18	250	4	10	80
495-9868	THPS-15	¥2,592	¥2,800	15 x 22	250	5	10	100
495-9876	THPS-19	¥2,777	¥3,000	19 x 26	300	5	10	120
495-9884	THPS-25	¥2,962	¥3,200	25 x 33	300	6	10	125
495-9892	THPS-32	¥4,582	¥4,950	32 x 41	350	7	10	220
495-9906	THPS-38	¥4,953	¥5,350	38 x 48	400	7	10	280
495-9914	THPS-50	¥5,314	¥5,740	50 x 62	500	10	10	350

Contact us:0120-509-849 <http://www.orange-book.com/>