


Prices displayed include 8% tax.

For Partition Panels, see p. 10-178

TRUSCO Stock 38,650 Items

## Catalogue Case (A4/A3 type)

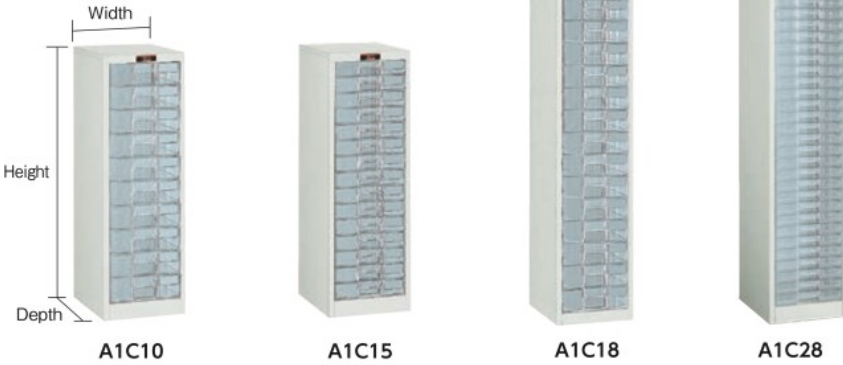

- Specs**
- Color: Neo Gray
  - Shallow Drawer: A4-20
  - A4 medium-deep type drawer: A4-15H
  - A3 medium-deep type drawer: LA3-1
  - Deep Type Drawer: A4-10
- Materials**
- Main Body: Steel
  - Drawer: PS resin
- Accessories**
- With each header card x 2Sheets for each drawer
- Origin**
- Japan

**Warning**  
•Partition panel is sold separately.

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Drawers (A4)			Drawer (A3) medium-deep type	Drawers Effective Internal Dimension (mm) W x D x H	Weight (kg)
						Shallow Type	Medium Depth Type	Deep Type			
★504-5185	A1C10	¥30,734	¥33,200	20	295 x 360 x 880	-	-	1 row 10 stages	-	234 x 318 x 72	13.5
★504-6211	A1C14	¥44,064	¥47,600	30	295 x 360 x 1200	-	-	1 row 14 stages	-	234 x 318 x 72	18.5
★504-5754	A1C15	¥34,807	¥37,600	20	295 x 360 x 880	-	1 row 15 stages	-	-	234 x 318 x 45	14.5
★504-6297	A1C18	¥52,581	¥56,800	40	295 x 360 x 1500	-	-	1 row 18 stages	-	234 x 318 x 72	22.0
★504-6254	A1C20	¥39,065	¥42,200	20	295 x 360 x 880	1 row 20 stages	-	-	-	234 x 318 x 32	15.5
★504-6238	A1C28	¥52,858	¥57,100	30	295 x 360 x 1200	1 row 28 stages	-	-	-	234 x 318 x 32	20.0
★504-6319	A1C36	¥63,597	¥68,700	40	295 x 360 x 1500	1 row 36 stages	-	-	-	234 x 318 x 32	25.0



Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Drawers (A4)			Drawer (A3) medium-deep type	Drawers Effective Internal Dimension (mm) W x D x H	Weight (kg)
						Shallow Type	Medium Depth Type	Deep Type			
★504-5576	A2C10	¥55,728	¥60,200	40	560 x 360 x 880	-	-	2 rows 10 stages	-	234 x 318 x 72	18.3
★504-5908	A2C14	¥73,224	¥79,100	60	560 x 360 x 1200	-	-	2 rows 14 stages	-	234 x 318 x 72	30.5
★504-5932	A2C15	¥65,818	¥71,100	40	560 x 360 x 880	-	2 rows 15 stages	-	-	234 x 318 x 45	21.0
★504-6351	A2C20	¥72,298	¥78,100	40	560 x 360 x 880	2 rows 20 stages	-	-	-	234 x 318 x 32	26.0
★504-6025	A2C21	¥82,481	¥89,100	60	560 x 360 x 1200	-	2 rows 21 stages	-	-	234 x 318 x 45	35.8
★504-6050	A2C1015	¥59,153	¥63,900	40	560 x 360 x 880	-	1 row 15 stages	1 row 10 stages	-	234 x 318 x (medium-deep type/45, deep type/72)	19.7
★504-6190	A2C1020	¥63,967	¥69,100	40	560 x 360 x 880	1 row 20 stages	-	1 row 10 stages	-	234 x 318 x (shallow type/32, deep type/72)	20.0
★504-6378	BWA2C15	¥75,538	¥81,600	80	805 x 360 x 880	-	1 row 15 stages	-	1 row 15 stages	484 x 322 x 42, 234 x 318 x 45	33.5



Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Drawers (A4)			Drawer (A3) medium-deep type	Drawers Effective Internal Dimension (mm) W x D x H	Weight (kg)
						Shallow Type	Medium Depth Type	Deep Type			
★504-5738	A3C10	¥ 81,278	¥ 87,800	60	825 x 360 x 880	-	-	3 rows 10 stages	-	234 x 318 x 72	36.5
★504-5975	A3C15	¥ 92,664	¥100,100	60	825 x 360 x 880	-	3 rows 15 stages	-	-	234 x 318 x 45	40.5
★504-6394	A3C20	¥105,161	¥113,600	60	825 x 360 x 880	3 rows 20 stages	-	-	-	234 x 318 x 32	41.0

Contact us: 0120-509-849 <http://www.orange-book.com/>

- Desks
- PC Desks
- Meeting Tables
- Cafeteria Tables
- Office Chairs
- Meeting Chairs
- Working Chairs
- Anti-Static Stools
- Benches
- Umbrella Stands
- Reception Room Furnitures
- Hanger Racks
- Partitions
- Book Cabinets
- Counters
- Filing Cabinets
- Catalog Cases
- Map Cases·Letter Cases
- Pamphlet Stands
- File Wagons
- Lockers
- Shoes Boxes
- Safes
- Mailboxes
- Key Boxes
- Window Films
- Interior Blinds
- OA Floors
- System Kitchens