

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Storage Case

Com Drawing



BS2A-T540C (files sold separately)

Specs Origin •Double wheel caster ϕ 40mm: Flexible type with stopper x 2, Flexible type without stopper x 2
•Japan



DM-A452-C



BS2A4-W2C



DM-A4W1-C



BS2A4-S4C



BF-700C (inclined shelf type)

Standard Type

Features •Can be neatly stored under a desk in compliance with old JIS standards (desk height: 740mm).

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Caster Diameter (mm)	SPQ (piece)	Weight (kg)
★504-6327	BS2A-T540C	¥17,681	¥19,100	60	521 x 330 x 602	40	1	11.5
★000-6807	BS2A4-S4C	¥25,550	¥27,600	60	521 x 330 x 602	40	1	14.1
★000-6831	DM-A452-C	¥21,847	¥23,600	60	523 x 332 x 602	40	1	12.9
★000-6785	BS2A4-W2C	¥24,346	¥26,300	60	521 x 330 x 602	40	1	13.2
★000-6823	DM-A4W1-C	¥21,477	¥23,200	60	523 x 332 x 602	40	1	12.7

Inclined Shelf Type

Features •Convenient file wagon of the inclined shelf type.

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Caster Diameter (mm)	SPQ (piece)	Weight (kg)
★504-6548	BF-700C	¥22,865	¥24,700	60	702 x 432 x 844	40	1	18.5

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Storage Case

Com Drawing



DM50-2C



KDM50-2C (with cylinder lock)



When the door is closed

Features •Can be neatly stored under a desk in compliance with old JIS standards (desk height: 740mm).

Specs •Double wheel caster ϕ 40mm: Flexible type with stopper x 2, Flexible type without stopper x 2

Origin •Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Caster Diameter (mm)	SPQ (piece)	Weight (kg)
★507-2611	DM50-2C	¥19,810	¥21,400	60	502 x 302 x 616	40	1	11.0
★507-2620	KDM50-2C	¥22,587	¥24,400	60	502 x 302 x 616	40	1	12.4

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

"Desk-side Wagon"

Com Drawing

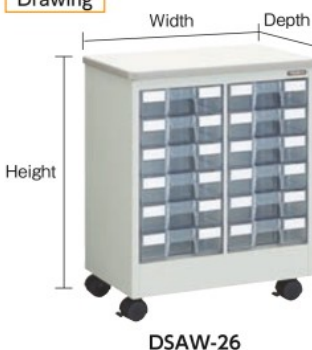

DSAW-26



DSAW-16



DS-AC80T

Features •It is as high as a desk in compliance with new JIS standards (height: 700mm) and optimum for use by the side of a desk.

Specs •With top and drawer
•Top: Melamine decorative plywood
•Double wheel caster ϕ 60mm: Flexible type with stopper x 2, Flexible type without stopper x 2

Origin •Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	W x D x H (mm)	Caster Diameter (mm)	SPQ (piece)	Weight (kg)
★507-2654	DSAW-16	¥43,416	¥46,900	60	315 x 390 x 700	60	1	11.2
★507-2662	DSAW-26	¥62,856	¥67,900	60	580 x 390 x 700	60	1	19.0
★511-2214	DS-AC80T	¥51,655	¥55,800	60	580 x 390 x 700	60	1	17.4

Contact us: 0120-509-849 <http://www.orange-book.com/>