


CONCRETE DRILLS

Hexagonal Shank Drill Bit **HEX** Type

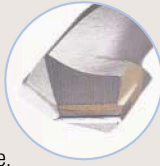


- The drill bit exclusive to hammer drills enables efficient transfer of the hammering impact and the spinning force.
- The integral design from chuck section to cutting edge offers outstanding performance in piercing and deep drilling work.
- The range also includes bits for drilling holes for anchors, and bits for slope-finishing work, widely meeting work requirements.



*For hole drilling of stone material, use a drill for stone.

Applicable Electric Tool Hammer Drill

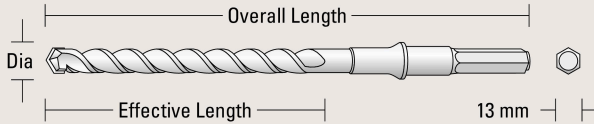

CONCRETE	* STONE
BLOCK / BRICK	MORTAR
SLATE	JAPANESE WALL

HEX Type Short

	Code		Diameter (mm)	Overall Length (mm)	Effective Length (mm)	Pcs/Box
	Non-pack	Blister Pack				
	HEX 10.0x2.80	HEX 10.0x2.80BP	10.0	280	162	6
○	HEX 10.5x2.80	HEX 10.5x2.80BP	10.5			
	HEX 11.0x2.80	HEX 11.0x2.80BP	11.0			
△	HEX 12.0x2.80	HEX 12.0x2.80BP	12.0			
○	HEX 12.5x2.80	HEX 12.5x2.80BP	12.5			
○	HEX 12.7x2.80	HEX 12.7x2.80BP	12.7			
	HEX 13.0x2.80	HEX 13.0x2.80BP	13.0			
	HEX 13.5x2.80	HEX 13.5x2.80BP	13.5			
	HEX 14.0x2.80	HEX 14.0x2.80BP	14.0			
	HEX 14.3x2.80	HEX 14.3x2.80BP	14.3			
○	HEX 14.5x2.80	HEX 14.5x2.80BP	14.5			
	HEX 15.0x2.80	HEX 15.0x2.80BP	15.0			
○	HEX 16.0x2.80	HEX 16.0x2.80BP	16.0			
	HEX 16.5x2.80	HEX 16.5x2.80BP	16.5	280	162	6
○	HEX 17.0x2.80	HEX 17.0x2.80BP	17.0			
	HEX 17.5x2.80	HEX 17.5x2.80BP	17.5			
○	HEX 18.0x2.80	HEX 18.0x2.80BP	18.0			
○	HEX 19.0x2.80	HEX 19.0x2.80BP	19.0			
	HEX 20.0x2.80	HEX 20.0x2.80BP	20.0			
△	HEX 21.5x2.80	HEX 21.5x2.80BP	21.5			
○	HEX 22.0x2.80	HEX 22.0x2.80BP	22.0			
	HEX 22.5x2.80		22.5	280	162	3
	HEX 23.0x2.80		23.0			
△	HEX 24.0x2.80		24.0			
	HEX 25.0x2.80		25.0			
	HEX 25.5x2.80		25.5			
	HEX 26.0x2.80		26.0			
	HEX 26.5x2.80		26.5			
○	HEX 28.0x2.80		28.0			
	HEX 28.5x2.80		28.5			
	HEX 29.0x2.80		29.0			
	HEX 30.0x2.80		30.0			
△	HEX 32.0x2.80		32.0			
	HEX 35.0x2.80		35.0	280	162	2
	HEX 38.0x2.80		38.0			
	HEX 40.0x2.80		40.0			

HEX Type Long

	Code	Diameter (mm)	Overall Length (mm)	Effective Length (mm)	Pcs/Box
	HEX L10.5x505	10.5	505	387	1
	HEX L12.0x505	12.0			
	HEX L12.5x505	* 12.5			
△	HEX L12.7x505	12.7			
	HEX L14.3x505	14.3			
○	HEX L14.5x505	14.5			
	HEX L15.0x505	15.0			
△	HEX L16.0x505	16.0			
	HEX L16.5x505	* 16.5			
	HEX L17.0x505	17.0			
	HEX L17.5x505	17.5			
○	HEX L18.0x505	18.0			
○	HEX L19.0x505	19.0			
○	HEX L20.0x505	20.0			
	HEX L21.5x505	21.5			
△	HEX L22.0x505	22.0			
△	HEX L24.0x505	24.0	505	387	1
	HEX L25.0x505	25.0			
	HEX L25.5x505	25.5			
	HEX L26.0x505	26.0			
	HEX L28.0x505	28.0			
○	HEX L28.5x505	28.5			
	HEX L29.0x505	29.0			
	HEX L30.0x505	30.0			
	HEX L32.0x505	32.0			
	HEX L34.0x505	34.0			
	HEX L35.0x505	35.0			
	HEX L38.0x505	38.0			
	HEX L40.0x505	40.0			

Items marked * are special size. Please confirm stock before ordering.

HEX Type Super Long

Code	Overall Length (mm)	Effective Length (mm)	Code	Overall Length (mm)	Effective Length (mm)	Code	Overall Length (mm)	Effective Length (mm)
HEX LL 14.3x600	600	460	HEX LL 14.3x800	800	660	HEX LL 14.3x1000	1,000	860
HEX LL 14.5x600			HEX LL 14.5x800			HEX LL 14.5x1000		
HEX LL 16.0x600			HEX LL 16.0x800			HEX LL 16.0x1000		
HEX LL 17.0x600			HEX LL 17.0x800			HEX LL 17.0x1000		
HEX LL 17.5x600			HEX LL 17.5x800			HEX LL 17.5x1000		
HEX LL 18.0x600			HEX LL 18.0x800			HEX LL 18.0x1000		
HEX LL 19.0x600			HEX LL 19.0x800			HEX LL 19.0x1000		
HEX LL 21.5x600			HEX LL 21.5x800			HEX LL 21.5x1000		
HEX LL 22.0x600			HEX LL 22.0x800			HEX LL 22.0x1000		
HEX LL 25.0x600			HEX LL 25.0x800			HEX LL 25.0x1000		