


2GT

〈ピッチ:2.0mm〉

● ベルト歯形寸法

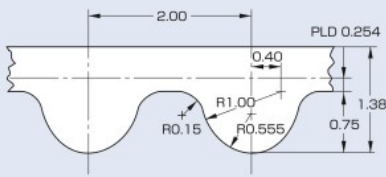


● ベルト呼称例

200-2GT-4




● プーリ歯形寸法

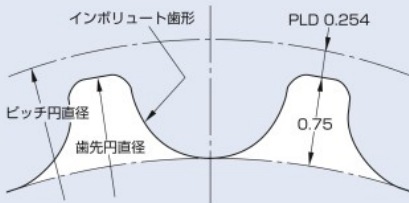

● プーリ呼称例

P 30-2GT-4-6F

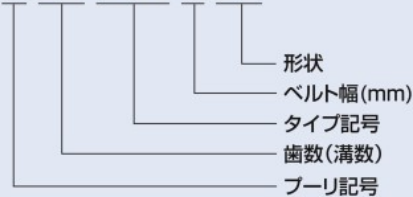

2GTプーリ **P.116** 参照

ベルトサイズ一覧表

呼称	ピッチ周長(mm)	歯数	呼称	ピッチ周長(mm)	歯数	呼称	ピッチ周長(mm)	歯数
54-2GT	54.00	27	232-2GT	232.00	116	504-2GT	504.00	252
58-2GT	58.00	29	236-2GT	236.00	118	506-2GT	506.00	253
60-2GT	60.00	30	240-2GT	240.00	120	508-2GT	508.00	254
66-2GT	66.00	33	242-2GT	242.00	121	516-2GT	516.00	258
72-2GT	72.00	36	244-2GT	244.00	122	524-2GT	524.00	262
74-2GT	74.00	37	248-2GT	248.00	124	530-2GT	530.00	265
76-2GT	76.00	38	250-2GT	250.00	125	544-2GT	544.00	272
78-2GT	78.00	39	252-2GT	252.00	126	550-2GT	550.00	275
80-2GT	80.00	40	254-2GT	254.00	127	558-2GT	558.00	279
82-2GT	82.00	41	256-2GT	256.00	128	570-2GT	570.00	285
84-2GT	84.00	42	258-2GT	258.00	129	572-2GT	572.00	286
86-2GT	86.00	43	260-2GT	260.00	130	578-2GT	578.00	289
88-2GT	88.00	44	264-2GT	264.00	132	586-2GT	586.00	293
90-2GT	90.00	45	266-2GT	266.00	133	598-2GT	598.00	299
92-2GT	92.00	46	268-2GT	268.00	134	600-2GT	600.00	300
94-2GT	94.00	47	270-2GT	270.00	135	606-2GT	606.00	303
96-2GT	96.00	48	278-2GT	278.00	139	616-2GT	616.00	308
98-2GT	98.00	49	280-2GT	280.00	140	630-2GT	630.00	315
100-2GT	100.00	50	282-2GT	282.00	141	634-2GT	634.00	317
102-2GT	102.00	51	284-2GT	284.00	142	646-2GT	646.00	323
106-2GT	106.00	53	286-2GT	286.00	143	660-2GT	660.00	330
108-2GT	108.00	54	288-2GT	288.00	144	670-2GT	670.00	335
110-2GT	110.00	55	290-2GT	290.00	145	676-2GT	676.00	338
112-2GT	112.00	56	292-2GT	292.00	146	690-2GT	690.00	345
114-2GT	114.00	57	294-2GT	294.00	147	696-2GT	696.00	348
116-2GT	116.00	58	300-2GT	300.00	150	702-2GT	702.00	351
118-2GT	118.00	59	302-2GT	302.00	151	726-2GT	726.00	363
120-2GT	120.00	60	304-2GT	304.00	152	742-2GT	742.00	371
122-2GT	122.00	61	308-2GT	308.00	154	752-2GT	752.00	376
124-2GT	124.00	62	310-2GT	310.00	155	760-2GT	760.00	380
126-2GT	126.00	63	314-2GT	314.00	157	772-2GT	772.00	386
128-2GT	128.00	64	318-2GT	318.00	159	782-2GT	782.00	391
130-2GT	130.00	65	320-2GT	320.00	160	800-2GT	800.00	400
132-2GT	132.00	66	322-2GT	322.00	161	810-2GT	810.00	405
134-2GT	134.00	67	324-2GT	324.00	162	828-2GT	828.00	414
136-2GT	136.00	68	326-2GT	326.00	163	852-2GT	852.00	426
138-2GT	138.00	69	328-2GT	328.00	164	860-2GT	860.00	430
140-2GT	140.00	70	332-2GT	332.00	166	866-2GT	866.00	433
142-2GT	142.00	71	336-2GT	336.00	168	892-2GT	892.00	446
144-2GT	144.00	72	338-2GT	338.00	169	900-2GT	900.00	450
146-2GT	146.00	73	340-2GT	340.00	170	930-2GT	930.00	465
148-2GT	148.00	74	344-2GT	344.00	172	950-2GT	950.00	475
150-2GT	150.00	75	346-2GT	346.00	173	976-2GT	976.00	488
152-2GT	152.00	76	348-2GT	348.00	174	994-2GT	994.00	497
154-2GT	154.00	77	350-2GT	350.00	175	1004-2GT	1004.00	502
156-2GT	156.00	78	352-2GT	352.00	176	1028-2GT	1028.00	514
158-2GT	158.00	79	354-2GT	354.00	177	1066-2GT	1066.00	533
160-2GT	160.00	80	358-2GT	358.00	179	1068-2GT	1068.00	534
162-2GT	162.00	81	360-2GT	360.00	180	1078-2GT	1078.00	539
164-2GT	164.00	82	366-2GT	366.00	183	1110-2GT	1110.00	555
166-2GT	166.00	83	370-2GT	370.00	185	1140-2GT	1140.00	570
168-2GT	168.00	84	372-2GT	372.00	186	1164-2GT	1164.00	582
170-2GT	170.00	85	376-2GT	376.00	188	1166-2GT	1166.00	583
172-2GT	172.00	86	380-2GT	380.00	190	1180-2GT	1180.00	590
174-2GT	174.00	87	382-2GT	382.00	191	1210-2GT	1210.00	605
176-2GT	176.00	88	386-2GT	386.00	193	1228-2GT	1228.00	614
178-2GT	178.00	89	394-2GT	394.00	197	1234-2GT	1234.00	617
180-2GT	180.00	90	400-2GT	400.00	200	1256-2GT	1256.00	628
182-2GT	182.00	91	406-2GT	406.00	203	1310-2GT	1310.00	655
184-2GT	184.00	92	412-2GT	412.00	206	1320-2GT	1320.00	660
186-2GT	186.00	93	420-2GT	420.00	210	1344-2GT	1344.00	672
188-2GT	188.00	94	426-2GT	426.00	213	1360-2GT	1360.00	680
190-2GT	190.00	95	430-2GT	430.00	215	1434-2GT	1434.00	717
192-2GT	192.00	96	436-2GT	436.00	218	1524-2GT	1524.00	762
194-2GT	194.00	97	440-2GT	440.00	220	1660-2GT	1660.00	830
196-2GT	196.00	98	444-2GT	444.00	222	1688-2GT	1688.00	844
200-2GT	200.00	100	446-2GT	446.00	223	1700-2GT	1700.00	850
202-2GT	202.00	101	448-2GT	448.00	224	1810-2GT	1810.00	905
204-2GT	204.00	102	452-2GT	452.00	226	1850-2GT	1850.00	925
206-2GT	206.00	103	454-2GT	454.00	227	1860-2GT	1860.00	930
208-2GT	208.00	104	460-2GT	460.00	230	1910-2GT	1910.00	955
210-2GT	210.00	105	470-2GT	470.00	235	2218-2GT	2218.00	1109
212-2GT	212.00	106	478-2GT	478.00	239			
214-2GT	214.00	107	484-2GT	484.00	242			
216-2GT	216.00	108	486-2GT	486.00	243			
220-2GT	220.00	110	488-2GT	488.00	244			
224-2GT	224.00	112	492-2GT	492.00	246			
226-2GT	226.00	113	494-2GT	494.00	247			
228-2GT	228.00	114	500-2GT	500.00	250			
230-2GT	230.00	115	502-2GT	502.00	251			

注) 周長994.0mm以上で幅2.5mm以下のベルトは製作できません。