
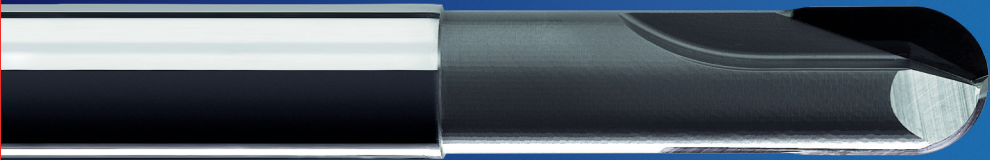


Standard

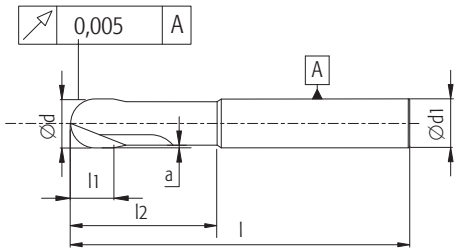

Article Number Artikelnummer	Ød (mm)	r (mm)	Ød1 (mm)	L (mm)	L1 (mm)	L2 (mm)	a (mm)	z	γ (°)
Standard/ Standard Ausführung									
VHDB 2 030 078 L09	3,0	1,50	6	78	2,50	9,00	0,250	2	25
VHDB 2 030 078 L15	3,0	1,50	6	78	2,50	15,00	0,250	2	25
VHDB 2 040 078 L12	4,0	2,00	6	78	2,50	12,00	0,250	2	25
VHDB 2 040 078 L20	4,0	2,00	6	78	2,50	20,00	0,250	2	25
VHDB 2 050 078 L15	5,0	2,50	6	78	3,00	15,00	0,300	2	25
VHDB 2 050 078 L25	5,0	2,50	6	78	3,00	25,00	0,300	2	25
VHDB 2 060 102 L18	6,0	3,00	6	102	6,00	18,00	0,300	2	-
VHDB 2 060 102 L30	6,0	3,00	6	102	6,00	30,00	0,300	2	-
VHDB 2 080 102 L24	8,0	4,00	8	102	7,00	24,00	0,400	2	-
VHDB 2 080 102 L40	8,0	4,00	8	102	7,00	40,00	0,400	2	-
VHDB 2 100 102 L30	10,0	5,00	10	102	8,00	30,00	0,500	2	-
VHDB 2 100 102 L50	10,0	5,00	10	102	8,00	50,00	0,500	2	-
VHDB 2 120 107 L36	12,0	6,00	12	107	9,00	36,00	0,500	2	-
VHDB 2 120 107 L60	12,0	6,00	12	107	9,00	60,00	0,500	2	-
Long / Lange Ausführung									
VHDB 2 030 078	3,0	1,50	6	78	3,00	9,00	0,100	2	15
VHDB 2 040 078	4,0	2,00	6	78	4,00	12,00	0,100	2	15
VHDB 2 050 078	5,0	2,50	6	78	5,00	15,00	0,100	2	15
VHDB 2 060 078	6,0	3,00	6	78	6,00	18,00	0,100	2	-
VHDB 2 080 078	8,0	4,00	8	78	8,00	24,00	0,100	2	-
VHDB 2 100 078	10,0	5,00	10	78	10,00	30,00	0,100	2	-
VHDB 2 120 078	12,0	6,00	12	78	12,00	30,00	0,100	2	-

Available in special dimensions on request.
Sondermaße auf Anfrage lieferbar.