



スーパートルクタイミングベルト S8M

High Torque Timing Belt S8M




BEIDI

Original MISUMI Type The products in this page are different from the published types in the MISUMI product catalogs. To order MISUMI products, please use the original MISUMI types.



HTBNV

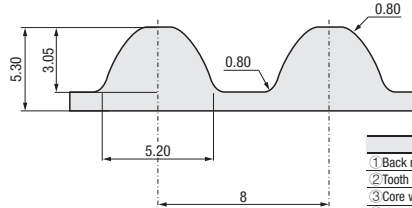

M	
① Back rubber	Chloroprene rubber
② Tooth rubber	Chloroprene rubber
③ Core wire	Glass fiber cord S and Z twist alternative series
④ Base cloth	Nylon fabric

Type S8M (pitch: 8mm)

Type	Part Number	Belt nominal width	Teeth	Belt circum. length (mm)
HTBNV	424-S8M	150 (15mm)	53	424
	432-S8M		54	432
	440-S8M		55	440
	464-S8M		58	464
	480-S8M		60	480
	496-S8M		62	496
	512-S8M		64	512
	520-S8M		65	520
	560-S8M		70	560
	584-S8M		73	584
	592-S8M		74	592
	600-S8M		75	600
	616-S8M		77	616
	632-S8M		79	632
	640-S8M		80	640
	656-S8M		82	656
	680-S8M		85	680
	704-S8M		88	704
	712-S8M		89	712
	720-S8M		90	720
	752-S8M		94	752
	760-S8M		95	760
	776-S8M		97	776
	792-S8M		99	792
	800-S8M		100	800
	816-S8M		102	816
	824-S8M		103	824
	840-S8M		105	840
	848-S8M		106	848
	880-S8M		110	880
	888-S8M		111	888
	896-S8M		112	896
	904-S8M		113	904
	920-S8M		115	920
	944-S8M		118	944
	960-S8M		120	960
	976-S8M		122	976
	984-S8M		123	984
	1000-S8M		125	1000
	1008-S8M		126	1008
	1016-S8M		127	1016
	1024-S8M		128	1024
	1032-S8M		129	1032
	1040-S8M		130	1040
	1056-S8M		132	1056
	1072-S8M		134	1072
	1080-S8M		135	1080
	1088-S8M		136	1088
1096-S8M	137	1096		
1120-S8M	140	1120		
1128-S8M	141	1128		
1136-S8M	142	1136		
1144-S8M	143	1144		
1152-S8M	144	1152		
1160-S8M	145	1160		
1184-S8M	148	1184		
1200-S8M	150	1200		
1216-S8M	152	1216		
1224-S8M	153	1224		
1240-S8M	155	1240		
1248-S8M	156	1248		

Type	Part Number	Belt nominal width	Teeth	Belt circum. length (mm)
HTBNV	1256-S8M	150 (15mm)	157	1256
	1264-S8M		158	1264
	1280-S8M		160	1280
	1304-S8M		163	1304
	1312-S8M		164	1312
	1320-S8M		165	1320
	1344-S8M		168	1344
	1352-S8M		169	1352
	1360-S8M		170	1360
	1376-S8M		172	1376
	1384-S8M		173	1384
	1400-S8M		175	1400
	1424-S8M		178	1424
	1440-S8M		180	1440
	1480-S8M		185	1480
	1512-S8M		189	1512
	1520-S8M		190	1520
	1544-S8M		193	1544
	1552-S8M		194	1552
	1600-S8M		200	1600
	1624-S8M		203	1624
	1640-S8M		205	1640
	1648-S8M		206	1648
	1680-S8M		210	1680
	1688-S8M		211	1688
	1728-S8M		216	1728
	1760-S8M		220	1760
	1776-S8M		222	1776
	1792-S8M		224	1792
	1800-S8M		225	1800
	1880-S8M		235	1880
	1904-S8M		238	1904
	1952-S8M		244	1952
	2000-S8M		250	2000
	2032-S8M		254	2032
	2040-S8M		255	2040
	2048-S8M		256	2048
	2056-S8M		257	2056
	2120-S8M		265	2120
	2136-S8M		267	2136
	2160-S8M		270	2160
	2200-S8M		275	2200
	2240-S8M		280	2240
	2272-S8M		284	2272
	2296-S8M		287	2296
	2304-S8M		288	2304
	2400-S8M		300	2400
	2496-S8M		312	2496
2600-S8M	325	2600		
2800-S8M	350	2800		
2848-S8M	356	2848		
2880-S8M	360	2880		
3200-S8M	400	3200		
3280-S8M	410	3280		
3400-S8M	425	3400		
3440-S8M	430	3440		
3600-S8M	450	3600		
3720-S8M	465	3720		
4000-S8M	500	4000		
5280-S8M	660	5280		



Order Sample

Part Number

Type Belt No. - Belt nominal width

HTBNV 2304-S8M - 150