




Fitting series

SQL series

CHELIC PNEUMATIC

SQL series Elbow 90°

Metric specification

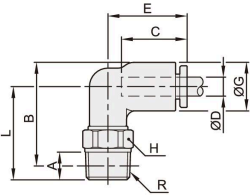

Port size ØD	Thread size Rc (PT)	Model	A	B	C	E	ØG	L	Opposite dim H	Effective area mm ²	Weight (g)
Ø4	M5	SQL 4 - M5	2.2	19.4	14.7	17.6	10.5	15.3	10	3.5	6
	1/8"	SQL 4 - 01	5.5	21.2	14.7	17.6	10.5	18.7	10	4.2	10
	1/4"	SQL 4 - 02	8	22.9	14.7	17.6	10.5	21.7	14	4.2	16
Ø6	M5	SQL 6 - M5	2.5	23.6	17.1	20.7	12.5	18.5	10	3.5	8.5
	1/8"	SQL 6 - 01	5.5	22.1	17.1	20.7	12.5	18.5	10	10	10.5
	1/4"	SQL 6 - 02	8	23.6	17.1	20.7	12.5	21.3	14	10	18
Ø8	3/8"	SQL 6 - 03	8	24.9	17.1	20.7	12.5	22.6	17	10	22.5
	1/8"	SQL 8 - 01	5.5	26.8	18.7	23	14.3	22.3	12	16	13.5
	1/4"	SQL 8 - 02	8	28.1	18.7	23	14.3	24.9	14	16	19
Ø10	3/8"	SQL 8 - 03	8	29.1	18.7	23	14.3	25.9	17	16	24.5
	1/8"	SQL 10 - 01	5.5	30.8	20.9	26.6	17.8	24.6	17	16	27
	1/4"	SQL 10 - 02	8	32.3	20.9	26.6	17.8	27.4	17	30	29
	3/8"	SQL 10 - 03	8	32.5	20.9	26.6	17.8	27.6	17	30	31
Ø12	1/2"	SQL 10 - 04	10	34.8	20.9	26.6	17.8	30.9	21	30	46
	1/4"	SQL 12 - 02	8	37	23.6	30.5	21.1	30.4	17	50	36
	3/8"	SQL 12 - 03	8	37	23.6	30.5	21.1	30.4	17	50	36
	1/2"	SQL 12 - 04	10	39.5	23.6	30.5	21.1	33.9	21	50	50

SQ
Fitting

MSQ
Mini type
Fitting

SP
Plug
Nipple

SQ J
Nipple
Fitting

SQR
Check
Fitting

SQ G
Pressure
Gauge
Fitting

Brass
Fitting

Inch specification

Port size ØD	Thread size NPT	Model	A	B	C	E	ØG	L	Opposite dim H	Effective area mm ²	Weight (g)
5/32"	NR 10/32"	SQL 5/32 - 10/32	2.4	20.4	14.7	17.6	10.5	16.4	10	3.5	6
	1/8"	SQL 5/32 - 01	6	22.4	14.7	17.6	10.5	20.2	10	4.2	10
	1/4"	SQL 5/32 - 02	9	24.1	14.7	17.6	10.5	23.4	14	4.2	16
1/4"	NR 10/32"	SQL 1/4 - 10/32	2.5	23.9	17	20.6	12.5	18.8	10	3.5	8.5
	1/8"	SQL 1/4 - 01	6	23.1	17	20.6	12.5	19.8	10	10	10.5
	1/4"	SQL 1/4 - 02	9	24.9	17	20.6	12.5	23.1	14	10	18
5/16"	3/8"	SQL 1/4 - 03	9	26.4	17	20.6	12.5	24.6	17	10	22.5
	1/8"	SQL 5/16 - 01	6	27.6	18.7	23	14.3	23.4	12	16	13.5
	1/4"	SQL 5/16 - 02	9	29.4	18.7	23	14.3	26.7	14	16	19
3/8"	3/8"	SQL 5/16 - 03	9	30.1	18.7	23	14.3	27.4	17	16	24.5
	1/8"	SQL 3/8 - 01	6	31.6	21.3	27	17.8	25.7	17	16	27
	1/4"	SQL 3/8 - 02	9	33.4	21.3	27	17.8	29	17	30	29
1/2"	3/8"	SQL 3/8 - 03	9	34.1	21.3	27	17.8	29.7	17	30	31
	1/2"	SQL 3/8 - 04	11	36.1	21.3	27	17.8	32.7	21	30	46
	1/4"	SQL 1/2 - 02	9	38.1	24.2	31.1	21.1	32.1	17	50	36
	3/8"	SQL 1/2 - 03	9	38.1	24.2	31.1	21.1	32.1	17	50	36
	1/2"	SQL 1/2 - 04	11	40.2	24.2	31.1	21.1	35.1	21	50	50

SC
Speed
Controller

QS
Speed
Controller

QH
Hand
Valve

QV
Union
Straight

QST
Panel type
Speed
Controller

PU
Tube