


LM-L <Built-in Synthetics Resin Retainer>



This type is a metric dimension series widely used in Japan and other countries.

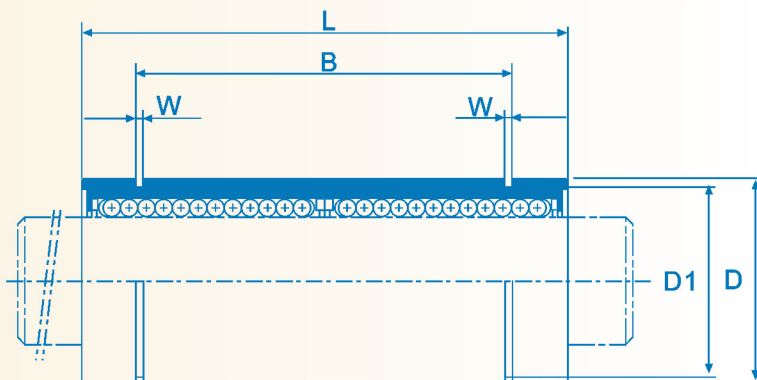

Nominal Part No.				Nominal Shaft Diameter (mm)	
Standard Type	Seal Type	Ball Circuit	Weight g	dr	Tolerance
LM 6L	LM 6L UU	4	16	6	[]
LM 8L	LM 8L UU	4	31	8	[]
LM 10L	LM 10L UU	4	62	10	0
LM 12L	LM 12L UU	4	80	12	-0.010
LM 13L	LM 13L UU	4	90	13	[]
LM 16L	LM 16L UU	5	145	16	[]
LM 20L	LM 20L UU	5	180	20	0
LM 25L	LM 25L UU	6	440	25	-0.012
LM 30L	LM 30L UU	6	480	30	[]
LM 35L	LM 35L UU	6	795	35	0
LM 40L	LM 40L UU	6	1,170	40	-0.015
LM 50L	LM 50L UU	6	3,100	50	[]
LM 60L	LM 60L UU	6	3,500	60	0 -0.020