



## LMF-L <Built-in Synthetic Resin Retainer>

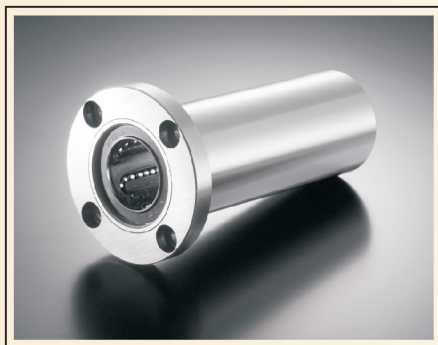

This type is a metric dimension series widely used in Japan and other countries.

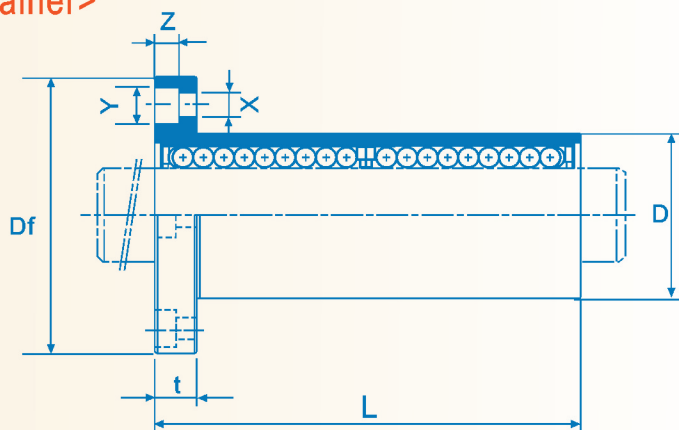

| Nominal Part No. |            |              |          | Major Dimensions and Tolerance (mm) |                |                |
|------------------|------------|--------------|----------|-------------------------------------|----------------|----------------|
| Standard Type    | Seal Type  | Ball Circuit | Weight g | dr<br>Tolerance                     | D<br>Tolerance | L<br>Tolerance |
| LMF 6L           | LMF 6L UU  | 4            | 31       | 6                                   | 12             | 35             |
| LMF 8L           | LMF 8L UU  | 4            | 51       | 8                                   | 15             | 45             |
| LMF 10L          | LMF 10L UU | 4            | 98       | 10                                  | 19             | 55             |
| LMF 12L          | LMF 12L UU | 4            | 110      | 12                                  | 21             | 57             |
| LMF 13L          | LMF 13L UU | 4            | 130      | 13                                  | 23             | 61             |
| LMF 16L          | LMF 16L UU | 5            | 190      | 16                                  | 28             | 70             |
| LMF 20L          | LMF 20L UU | 5            | 260      | 20                                  | 32             | 80             |
| LMF 25L          | LMF 25L UU | 6            | 540      | 25                                  | 40             | 112            |
| LMF 30L          | LMF 30L UU | 6            | 680      | 30                                  | 45             | 123            |
| LMF 35L          | LMF 35L UU | 6            | 1,020    | 35                                  | 52             | 135            |
| LMF 40L          | LMF 40L UU | 6            | 1,570    | 40                                  | 60             | 151            |
| LMF 50L          | LMF 50L UU | 6            | 3,600    | 50                                  | 80             | 192            |
| LMF 60L          | LMF 60L UU | 6            | 4,500    | 60                                  | 90             | 209            |