


## LMH-L <Built-in Synthetic Resin Retainer>



This type is a metric dimension series widely used in Japan and other countries.

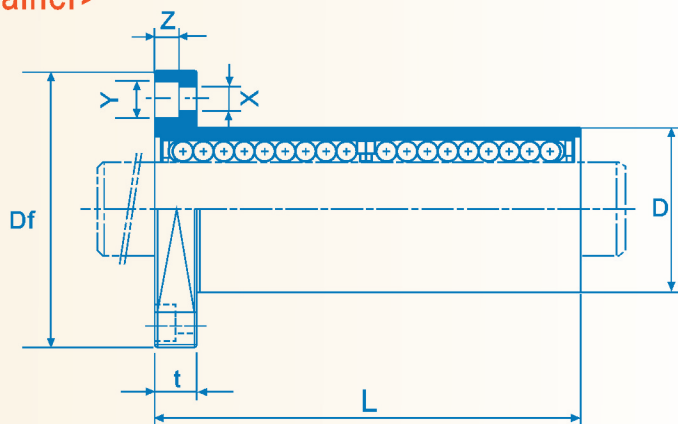

Nominal Part No.				Major Dimensions and Tolerance (mm)		
Standard Type	Seal Type	Ball Circuit	Weight g	dr Tolerance	D Tolerance	L Tolerance
LMH 6L	LMH 6L UU	4	28	6	12	35
LMH 8L	LMH 8L UU	4	47	8	15	45
LMH 10L	LMH 10L UU	4	90	10	19	55
LMH 12L	LMH 12L UU	4	102	12	21	57
LMH 13L	LMH 13L UU	4	123	13	23	61
LMH 16L	LMH 16L UU	5	182	16	28	70 ±0.3
LMH 20L	LMh 20L UU	5	247	20	32	80
LMH 25L	LMh 25L UU	6	525	25	40	112
LMH 30L	LMh 30L UU	6	645	30	45	123