
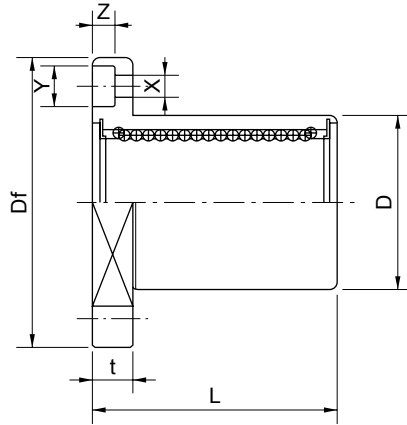


LMH...UU尼龙保持架  
该类型尺寸是公制的，广泛应用于亚洲和其他国家。

LMH...UU (Resin retainer)  
This type is a metric dimension series widely used in Asia and other countries.

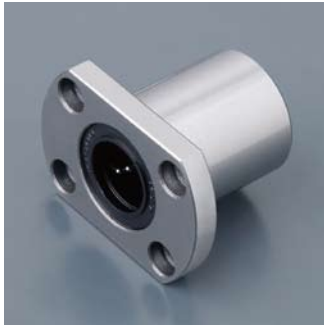

LMH...UU

公称轴径 Nominal shaft diameter mm	椭圆法兰 LMH...UU	重量 Weight (gf)	主要尺寸和公差 Major dimensions and tolerance					
			dr		D		L	
			mm	公差 Tolerance $\mu m$	mm	公差 Tolerance $\mu m$	mm	公差 Tolerance $\mu m$
6	LMH6UU	21	6	0	12	0	19	$\pm 300$
8	LMH8UU	33	8		15	-11	24	
10	LMH10UU	64	10		19	0	29	
12	LMH12UU	68	12	-9	21	0	30	0
13	LMH13UU	81	13		23	-13	32	
16	LMH16UU	112	16		28	0	37	
20	LMH20UU	167	20	0	32	0	42	-200
25	LMH25UU	325	25		40	-16	59	
30	LMH30UU	388	30		45	0	64	

注：所有LMH型均为双密封。  
Note: All sizes of LMH type are sealed on both sides.