
 
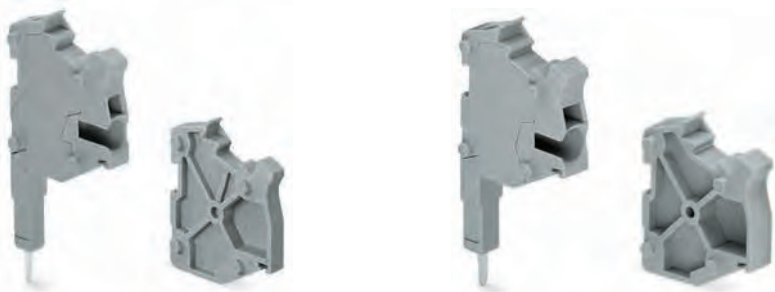















TOPJOB® S

Connectors and Connector Strips

2001/2002 Series

0.25 ... 1.5 (2.5) mm ² ① AWG 22 ... 14 500 V/6 kV/3 ③ I _N 18 A Terminal block width 4.2 mm / 0.165 in.  9 ... 11 mm / 0.39 in. ④	0.25 ... 2.5 (4) mm ² ② AWG 22 ... 12 500 V/6 kV/3 ③ I _N 24 A Terminal block width 5.2 mm / 0.205 in.  10 ... 12 mm / 0.43 in. ④
---	---



Item No.	Pack. Unit	Item No.	Pack. Unit	Accessories
Modular TOPJOB® S connector, for jumper contact slot, can be snapped together, gray ● 1-pole 2001-511 100 (4x25)		Modular TOPJOB® S connector, for jumper contact slot, can be snapped together, gray ● 1-pole 2002-511 100 (4x25)		Appropriate marking systems: WMB/Marking Test plug,  with 500 mm cable, 2.3 mm Ø yellow 210-137 50
Spacer module, can be snapped together, e.g., for bridging commoned terminal blocks ● gray 2001-549 100 (4x25)		Spacer module, can be snapped together, e.g., for bridging commoned terminal blocks ● gray 2002-549 100 (4x25)		
TOPJOB® S connector strip, for jumper contact slot, gray ● 2-pole 2001-552 25 ● 3-pole 2001-553 25 ● 4-pole 2001-554 25 ● 5-pole 2001-555 10 ● 6-pole 2001-556 10 ● 7-pole 2001-557 10 ● 8-pole 2001-558 10 ● 9-pole 2001-559 10 ● 10-pole 2001-560 10		TOPJOB® S connector strip, for jumper contact slot, gray ● 2-pole 2002-552 25 ● 3-pole 2002-553 25 ● 4-pole 2002-554 25 ● 5-pole 2002-555 10 ● 6-pole 2002-556 10 ● 7-pole 2002-557 10 ● 8-pole 2002-558 10 ● 9-pole 2002-559 10 ● 10-pole 2002-560 10		Test plug,  with 500 mm cable, 2 mm Ø red 210-136 50 Strain relief plate, gray  35 mm width 734-326 100 (4x25) 6 mm wide 734-327 100 (4x25) 12.5 mm width 734-328 100 (4x25) 25 mm wide 734-329 100 (4x25)
Item-Specific Accessories		Item-Specific Accessories		
End plate,  for modular TOPJOB® S connectors, 1.5 mm thick gray 2002-541 100 (4x25)		End plate,  for modular TOPJOB® S connectors, 1.5 mm thick gray 2002-541 100 (4x25)		Marking strip, plain,  11 mm wide, 50 m roll white 2009-110 1
WMB Inline, plain,  stretchable 4 ... 4.2 mm, 2,000 WMB markers, 4 mm, on roll white 2009-114 1		WMB Inline, plain,  stretchable 5 ... 5.2 mm, 1,500 WMB markers, 5 mm, on roll white 2009-115 1		
WMB Multi marking system,  10 strips with 10 markers per card, stretchable 4 ... 4.2 mm plain 793-4501 5		WMB Multi marking system,  10 strips with 10 markers per card, stretchable 5 ... 5.2 mm plain 793-5501 5		
WMB Multi marking system, plain,  10 strips with 10 markers per card, stretchable 4 ... 4.2 mm yellow 793-4501/000-002 red 793-4501/000-005 blue 793-4501/000-006 gray 793-4501/000-007 orange 793-4501/000-012 light green 793-4501/000-017 green 793-4501/000-023 violet 793-4501/000-024 5		WMB Multi marking system, plain,  10 strips with 10 markers per card, stretchable 5 ... 5.2 mm yellow 793-5501/000-002 red 793-5501/000-005 blue 793-5501/000-006 gray 793-5501/000-007 orange 793-5501/000-012 light green 793-5501/000-017 green 793-5501/000-023 violet 793-5501/000-024 5		
		Miniature WSB Quick marking system,  10 strips with 10 markers per card, 5 mm wide markers plain 248-501 5		