










Banana Plugs (Only for Safety Extra-Low Voltage)

0.08 ... 2.5 mm² | AWG 28 ... 14
 42 V
 I_N 20 A
 for socket 4 mm Ø
 9 ... 11 mm / 0.39 in.




	Item No.	Pack. Unit
Banana plug, for socket 4 mm Ø, color mixed, 10 x each - orange, white, black, blue, yellow	215-111	50
single plugs		
 Banana plug, for socket 4 mm Ø orange	215-211	50
 Banana plug, for socket 4 mm Ø red	215-212	50
 Banana plug, for socket 4 mm Ø black	215-311	50
 Banana plug, for socket 4 mm Ø green	215-411	50
 Banana plug, for socket 4 mm Ø yellow	215-511	50
 Banana plug, for socket 4 mm Ø white	215-611	50
 Banana plug, for socket 4 mm Ø blue	215-711	50
 Banana plug, for socket 4 mm Ø gray	215-811	50
 Banana plug, for socket 4 mm Ø green-yellow	215-911	50



Conductor termination: Press button fully and insert stripped conductor into square entry until it hits backstop and release.



Banana plug used as test plug. Picture shows 209-170 test plug adapter.

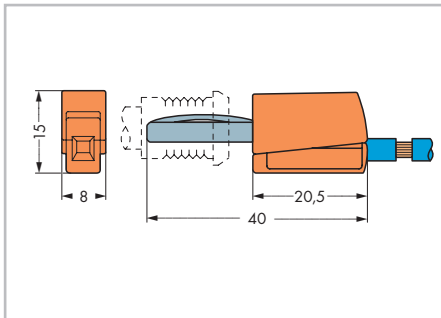

Dimensions in mm