
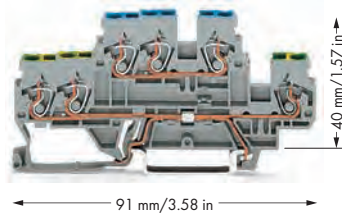


3-Conductor Double-Deck Terminal Blocks 2.5 mm² (4 mm² "f-st")



870 Series

0.08 ... 2.5 (4 "f-st") mm ² ① 500 V/6 kV/3 ② I _N 24 A Terminal block width 5 mm / 0.197 in. 6 ... 7 mm / 0.26 in. ③	AWG 28 ... 12 300 V, 20 A ④	0.08 ... 2.5 (4 "f-st") mm ² ① 500 V/6 kV/3 ② I _N 24 A Terminal block width 5 mm / 0.197 in. 6 ... 7 mm / 0.26 in. ③	AWG 28 ... 12
--	--------------------------------	--	---------------

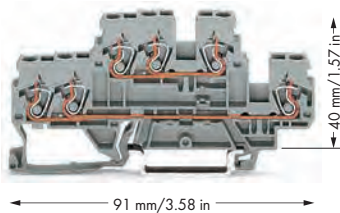

- ① Max. insulation diameter: 4.4 mm
- ② 500 V = rated voltage
6 kV = rated surge voltage
3 = pollution degree
(also see Section 14)
- ③ Strip length, see packaging or instructions.
- ④ Suitable for Ex i applications
- ⑤ See application notes for:
Insulation stop, page 293

Item No.	Pack. Unit	Item No.	Pack. Unit	Accessories		
Through/through terminal block, gray housing		Ground conductor/through terminal block, gray housing		WMB/Miniature WSB (see Section 13)		
○ L/L	870-531	50	○ PE/N	870-535	50	End and intermediate plate, 2 mm thick orange 870-574 100 (4x25) gray 870-573 100 (4x25)
○ N/L	870-532	50	○ PE/L	870-536	50	
○ L/N	870-533	50				
Through/through terminal block, blue housing				Insulation stop,		
● N/N	870-534 ④	50		⑤ 5 pcs/strip, 0.08 ... 0.2 mm ² "s" (0.14 mm ² "f-st") white 280-470 200 (8x25)		

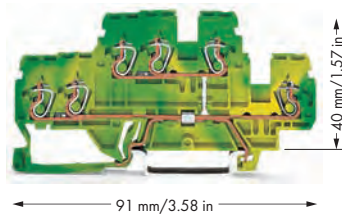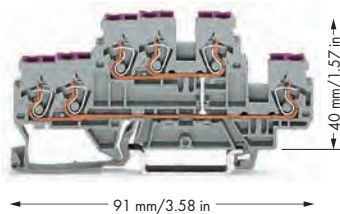

Item No.	Pack. Unit	Item No.	Pack. Unit	Accessories		
6-conductor through terminal block, internal commoning, conductor entry position colored in violet, gray housing		6-conductor ground terminal block, internal commoning, green-yellow housing		Insulation stop,		
○ L	870-538	50	● PE	870-537	50	⑤ 5 pcs/strip, 0.25 ... 0.5 mm ² light gray 280-471 200 (8x25)
6-conductor through terminal block, internal commoning, conductor entry position colored in violet, blue housing					Insulation stop,	
● N	870-539 ④	50			⑤ 5 pcs/strip, 0.75 ... 1 mm ² dark gray 280-472 200 (8x25)	
					Push-in type jumper bar, insulated,	
					I _N 18 A, light gray	
					2-way 870-402 200 (8x25)	
					3-way 870-403 200 (8x25)	
					4-way 870-404 100 (4x25)	
					5-way 870-405 100 (4x25)	
					6-way 870-406 100 (4x25)	
					7-way 870-407 100 (4x25)	
					8-way 870-408 100 (4x25)	
					9-way 870-409 100 (4x25)	
					10-way 870-410 50 (2x25)	
					Push-in type jumper bar, insulated,	
					I _N 18 A, light gray	
					from 1 to 3 870-433 200 (8x25)	
					from 1 to 4 870-434 200 (8x25)	
					from 1 to 5 870-435 100 (4x25)	
					from 1 to 6 870-436 100 (4x25)	
					from 1 to 7 870-437 100 (4x25)	
					from 1 to 8 870-438 100 (4x25)	
					from 1 to 9 870-439 100 (4x25)	
					from 1 to 10 870-440 50 (2x25)	
					Protective warning marker,	
					with high-voltage symbol, black, for 5 terminal blocks yellow 280-405 100 (4x25)	
					Marking strip, plain,	
					7.5 mm wide, 1 m/3'3" long translucent 709-196 1	