

Feed-through terminals

Compact style

In hazardous area applications, the installation instructions and the rated data specifications for accessories given in the technical appendix must be followed.

Width/Length/height with TS35x7.5	mm
max. current / max. cond. cross-section	A/mm ²
Max. clamping range	mm ²

Technical data

Rated data	
Rated voltage	V
Rated current	A
Rated cross-section	mm ²
Rated impulse voltage / Pollution severity	kV/-
Gauge to IEC 60947-1 / UL94 Flammability class	Approvals
Clamped conductors (H05V/H07V)	
solid / stranded	mm ²
flexible / Stranded wire with end ferrules	mm ²
Stripping length / Blade size	mm/-
Note	

Ordering data

Version	
	Dark beige Wemid
	Blue Wemid
Note	

Accessories


Pluggable cross-connection	
	2-pole
	3-pole
	4-pole
	10-pole
	20-/24-pole
End plate / partition	
	Dark beige Wemid
End bracket	
	Dark beige Wemid
Test adapter	
	Standard
	With assembly peg
Screwdriver	
	Standard
Reducing sleeves	
	For conductors < 0,5 mm ² / AWG 20
	For conductors < 1,0 mm ² / AWG 18
Cover	
	With lightning flash symbol

Marking systems	
	(see assortment in catalogue 7)
	Marking tags
For detailed information on other accessories and applications, refer to the „Accessories“ section	

ZDK 2.5/3AN

2.5 mm²


Double-level terminal

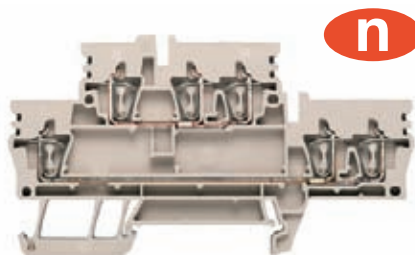

5.1 x 93 x 51.5

24 / 4

 0.05...4



IEC 60947-7-1

IEC	UL	CSA	EN 60079-7
800	300	300	550
24	20	20	20.5
2.5	AWG 30...12	AWG 30...12	2.5
8 / 3			
A2 / V0			



Rated connection

0.5...4 / 0.5...2.5

0.5...2.5 / 0.5...2.5

10 / 0.6 x 3.5 mm

2.5 mm² flexible conductors with wire end ferrules are crimped with the Weidmüller PZ 6/5 crimping tool.

Type	Qty	Order No.
ZDK 2.5/3AN	50	1924510000
ZDK 2.5/3AN BL	50	1924500000
Terminal with diode ZDK 2.5/3AN D1, 1924440000 and ZDK 2.5/3AN D2, 1924450000		

Type	current	Qty	Order No.
ZQV 2.5/2	24 A	60	1608860000
ZQV 2.5/3	24 A	60	1608870000
ZQV 2.5/4	24 A	60	1608880000
ZQV 2.5/10	24 A	20	1608940000
ZQV 2.5/20	24 A	20	1908960000
Width			
ZAP/TW ZDK 2.5/3AN	2 mm	20	1924910000
ZEW 35			
	6 mm	20	9540000000
ZTA ZT2.5			
	5.1 mm	25	1827080000
ZTA ZT2.5/ZA			
	5.1 mm	25	1847600000
SD 0.6x3.5x100			
		1	9008330000
ZRH 1.5H/1			
		1000	1678810000
ZRH 1.5H/2			
		1000	1678800000
ZAD 9/4			
		20	1934160000


Snap Mark / DEK 5/5 / WS 10/5

2.5 mm² conductors with plastic collar wire end ferrules only with optimised diameter collar (order No. 1333100000, 500 pcs).

ZDK 2.5/3AN V

2.5 mm²


Vertical cross-connected double-level terminal

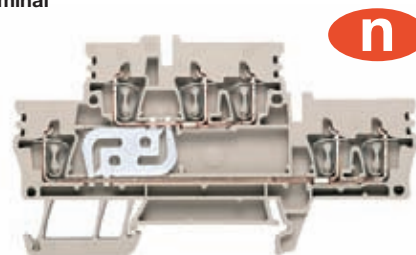

5.1 x 93 x 51.5

24 / 4

 0.05...4



IEC 60947-7-1

IEC	UL	CSA	EN 60079-7
800	300	300	550
24	20	20	20.5
2.5	AWG 30...12	AWG 30...12	2.5
8 / 3			
A2 / V0			



Rated connection

0.5...4 / 0.5...2.5

0.5...2.5 / 0.5...2.5

10 / 0.6 x 3.5 mm

2.5 mm² flexible conductors with wire end ferrules are crimped with the Weidmüller PZ 6/5 crimping tool.

Type	Qty	Order No.
ZDK 2.5/3AN V	50	1924490000
ZDK 2.5/3AN V BL	50	1924480000

Type	current	Qty	Order No.
ZQV 2.5/2	24 A	60	1608860000
ZQV 2.5/3	24 A	60	1608870000
ZQV 2.5/4	24 A	60	1608880000
ZQV 2.5/10	24 A	20	1608940000
ZQV 2.5/20	24 A	20	1908960000
Width			
ZAP/TW ZDK 2.5/3AN	2 mm	20	1924910000
ZEW 35			
	6 mm	20	9540000000
ZTA ZT2.5			
	5.1 mm	25	1827080000
ZTA ZT2.5/ZA			
	5.1 mm	25	1847600000
SD 0.6x3.5x100			
		1	9008330000
ZRH 1.5H/1			
		1000	1678810000
ZRH 1.5H/2			
		1000	1678800000
ZAD 9/4			
		20	1934160000

Snap Mark / DEK 5/5 / WS 10/5

2.5 mm² conductors with plastic collar wire end ferrules only with optimised diameter collar (order No. 1333100000, 500 pcs).