


2083

ニップル Nipple

External pipe/External pipe

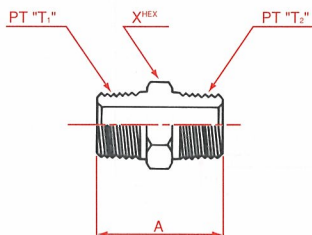


呼称サイズ	T ₁	T ₂	A	X
02	1/8	1/8	26	14
02-04	1/8	1/4	32	17
04	1/4	1/4	34	17
04-06	1/4	3/8	37	19
04-08	1/4	1/2	42	24
06	3/8	3/8	36	19
06-08	3/8	1/2	43	24
06-12	3/8	3/4	46	30
08	1/2	1/2	43	24
08-12	1/2	3/4	50	30
12	3/4	3/4	48	30
12-16	3/4	1	56	36
16	1	1	53	36

2084

ロング ニップル Long nipple

External pipe/External pipe

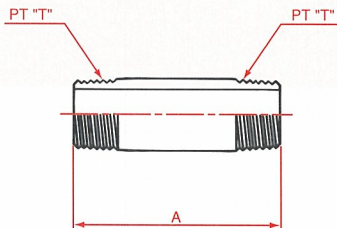


呼称サイズ	T	A
02-50A	1/8	50
04-50A	1/4	50
06-55A	3/8	55
06-75A	3/8	75
06-100A	3/8	100
06-150A	3/8	150
08-65A	1/2	65
12-80A	3/4	80
16-85A	1	85

SK-11

オス回転ニップル Male swivel nipple

External pipe swivel/External pipe

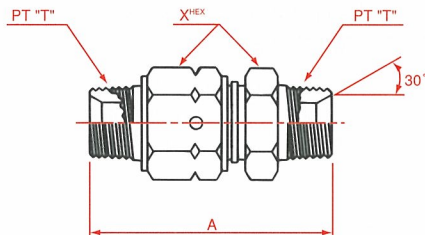


呼称サイズ	T	A	X
04	1/4	65	19
06	3/8	70	22
08	1/2	81	27
12	3/4	91	36
16	1	95	41

※PF30° MISにも接続可能

2081

ブッシング Bushing

External pipe/Internal pipe

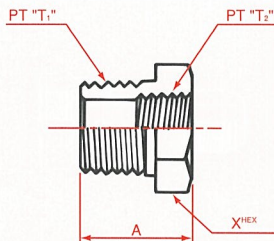

呼称サイズ	T ₁	T ₂	A	X
04-02	1/4	1/8	21	17
06-02	3/8	1/8	22	19
06-04	3/8	1/4	22	19
08-02	1/2	1/8	26	24
08-04	1/2	1/4	26	24
08-06	1/2	3/8	26	24
12-04	3/4	1/4	29	30
12-06	3/4	3/8	29	30
12-08	3/4	1/2	29	30
16-06	1	3/8	32	36
16-08	1	1/2	32	36
16-12	1	3/4	32	36
20-12	1 1/4	3/4	36	46
20-16	1 1/4	1	36	46