



SK-10 メス・オス回転ニップル
Female male swivel nipple
Internal pipe/External pipe

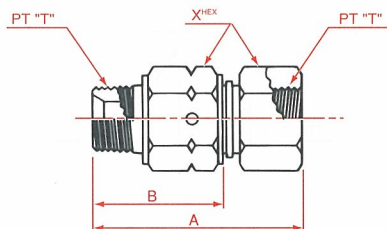

呼称サイズ	T	A	B	X
04	1/4	61	39	19
06	3/8	65	41	22
08	1/2	75	48	27
12	3/4	84	52	36
16	1	88	54	41


SK-14 オス・メス回転ニップル
Male female swivel nipple
External pipe/Internal pipe

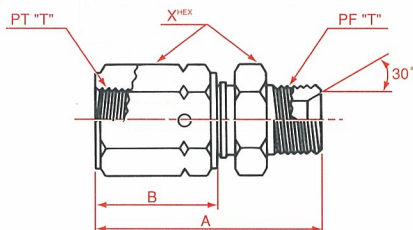

呼称サイズ	T	A	B	X
04	1/4	58	33	19
06	3/8	65	36	22
08	1/2	78	42	27
12	3/4	85	46	36
16	1	89	48	41


※PF30°MISにも接続可能

2096 ソケット
Socket
Internal pipe/Internal pipe

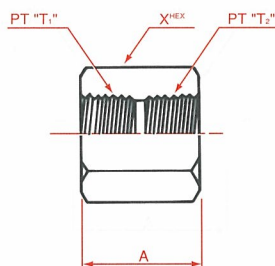

呼称サイズ	T ₁	T ₂	A	X
02	1/8	1/8	20	14
04	1/4	1/4	30	22
04-02	1/4	1/8	30	22
06	3/8	3/8	30	24
06-04	3/8	1/4	30	24
08	1/2	1/2	40	32
08-04	1/2	1/4	40	32
08-06	1/2	3/8	40	32
12	3/4	3/4	42	36
12-06	3/4	3/8	42	36
12-08	3/4	1/2	42	36
16	1	1	50	46
16-12	1	3/4	50	46

SK-12 メス回転ニップル
Female swivel nipple
Internal pipe/Internal pipe

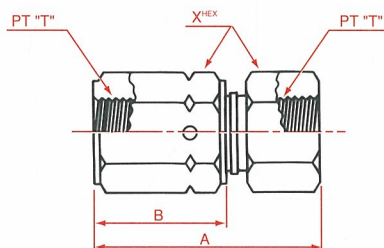

呼称サイズ	T	A	B	X
04	1/4	55	33	19
06	3/8	61	36	22
08	1/2	70	42	27
12	3/4	78	46	36
16	1	82	48	41