


2089


メス45°エルボ
Female 45° elbow
Internal pipe/Internal pipe

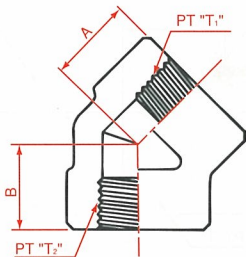

呼称サイズ	T ₁	T ₂	A	B
02	1/8	1/8	17	17
04	1/4	1/4	18	18
04-02	1/4	1/8	18	18
06	3/8	3/8	20	20
06-04	3/8	1/4	20	20
08	1/2	1/2	24	24
08-06	1/2	3/8	24	24
12	3/4	3/4	28	28
12-08	3/4	1/2	28	28
16	1	1	30	30
16-12	1	3/4	30	30

2087


メス90°エルボ
Female 90° elbow
Internal pipe/Internal pipe

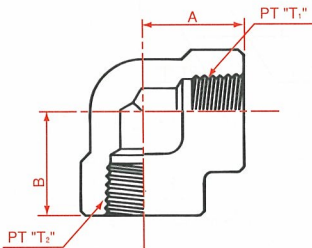

呼称サイズ	T ₁	T ₂	A	B
02	1/8	1/8	19	19
04-02	1/4	1/8	21	21
04	1/4	1/4	21	21
06-04	3/8	1/4	25	25
06	3/8	3/8	25	25
08-06	1/2	3/8	29	29
08	1/2	1/2	29	29
12-08	3/4	1/2	33	33
12	3/4	3/4	33	33
16-12	1	3/4	38	38
16	1	1	38	38

SKL-30


メス回転90°エルボ
Female 90° swivel elbow
Internal pipe/Internal pipe

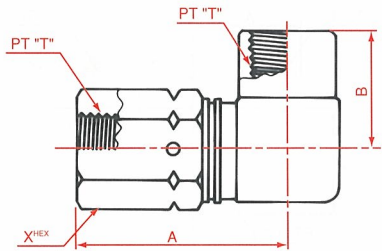

呼称サイズ	T	A	B	X
04	1/4	41	18	17
06	3/8	53	20	22
08	1/2	63	26	27
12	3/4	73	41	36

2090

オスねじ込みティー
Male screwed tee
External pipe/External pipe

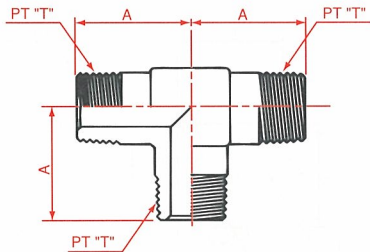

呼称サイズ	T	A
04	1/4	26
06	3/8	30
08	1/2	34
12	3/4	37
16	1	43