


1015


メス コネクター
Female connector
(internal pipe/PF30° FCS)

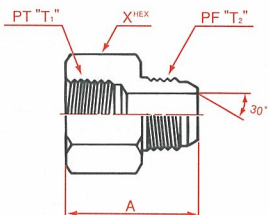

呼称サイズ	T ₁	T ₂	A	X
02-04	1/8	1/4	30	17
04	1/4	1/4	33	19
04-06	1/4	3/8	34.5	19
06	3/8	3/8	36.5	22
06-04	3/8	1/4	35	22
06-08	3/8	1/2	39	22
08	1/2	1/2	42	27
08-06	1/2	3/8	39.5	27
08-12	1/2	3/4	43.5	27
12	3/4	3/4	46.5	36
12-08	3/4	1/2	45	36
12-16	3/4	1	47.5	36
16	1	1	49.5	41
16-12	1	3/4	48.5	41

9008

メス隔壁締付コネクター
Female bulkhead connector
(internal pipe/PF30° FCS bulkhead)

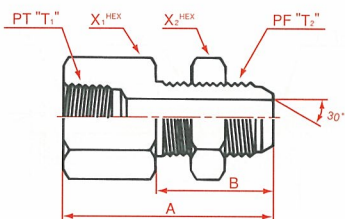

呼称サイズ	T ₁	T ₂	A	B	X ₁	X ₂
02-04	1/8	1/4	50	33	19	19
04	1/4	1/4	54	33	19	19
04-06	1/4	3/8	55	36	22	22
06	3/8	3/8	59	36	22	22
06-04	3/8	1/4	52	33	22	19
06-08	3/8	1/2	62	40	27	27
08	1/2	1/2	68	40	27	27
08-06	1/2	3/8	58	36	27	22
08-12	1/2	3/4	66	41	36	36
12	3/4	3/4	73	41	36	36
12-08	3/4	1/2	65	40	36	27
12-16	3/4	1	67	40	41	41
16	1	1	76	40	41	41
16-12	1	3/4	68	41	41	36