


9062 両メスティー Female both tee


(Internal pipe /PF30° FCS)

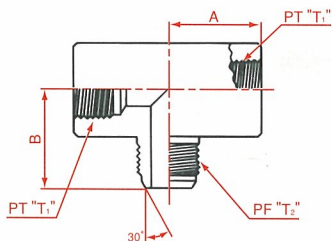

呼称サイズ	T ₁	T ₂	A	B
02-04	1/8	1/4	23	23
04	1/4	1/4	26	26
04-06	1/4	3/8	30	30
06	3/8	3/8	30	30
06-08	3/8	1/2	34	34
08	1/2	1/2	34	34
08-12	1/2	3/4	37	37
12	3/4	3/4	37	37

9066 片メス/中オスティー Female branch & male run tee


Internal pipe /External pipe /PF30° FCS

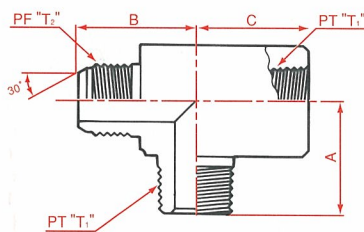

呼称サイズ	T ₁	T ₂	A	B
02-04	1/8	1/4	23	23
04	1/4	1/4	26	26
04-06	1/4	3/8	30	30
06	3/8	3/8	30	30
06-08	3/8	1/2	34	34
08	1/2	1/2	34	34
08-12	1/2	3/4	37	37
12	3/4	3/4	37	37

9064 片・中メスティー Female branch & run tee


Internal pipe /PF30° FCS

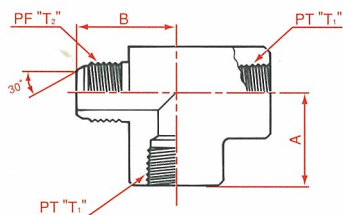

呼称サイズ	T ₁	T ₂	A	B
02-04	1/8	1/4	23	23
04	1/4	1/4	26	26
04-06	1/4	3/8	30	30
06	3/8	3/8	30	30
06-08	3/8	1/2	34	34
08	1/2	1/2	34	34
08-12	1/2	3/4	37	37
12	3/4	3/4	37	37
12-16	3/4	1	43	43

1042 メスプラグ Female plug

PF30° FCS Female plug

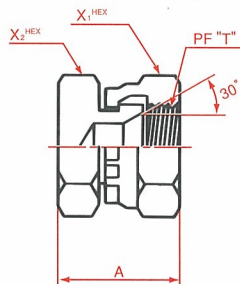

呼称サイズ	T	A	X ₁
02	1/8	19.5	17
04	1/4	22.5	19
06	3/8	27	22
08	1/2	32	27
12	3/4	36	36
16	1	37	41