


BT30 EYチャック

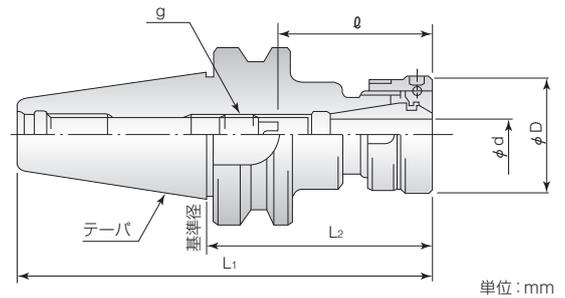

単位：mm

型番	コレット ツカミ能力 d	ナット 外径 D	全長 L ₁	基準径 からの 長さ L ₂	長さ調整ネジ		テーパ	質量 (kg)	使用する コレット	使用する スパナ
					g	φ 最大				
BT30-EYC11- 60	0.5~7.0	23	108.4	60	M8X0.75	35	BT30 7/24	0.45	EY11	FS22
-EYC11- 90			134.8	90				0.53		
-EYC11-105			153.4	105				0.58		
BT30-EYC16- 60	0.5~10.0	30	108.4	60	M11X1.5	50	BT30 7/24	0.50	EY16	FS30
-EYC16- 90			134.8	90				0.62		
-EYC16-105			153.4	105				0.69		
BT30-EYC20- 60	0.5~13.0	36	108.4	60	M14X1.5	55	BT30 7/24	0.53	EY20	FS36
-EYC20- 90			134.8	90				0.72		
-EYC20-105			153.4	105				0.82		
BT30-EYC25- 60	0.5~16.0	42	108.4	60	M18X1.5	50	BT30 7/24	0.57	EY25	FS42
-EYC25- 90			134.8	90				0.85		
-EYC25-105			153.4	105				1.00		
BT30-EYC32- 75	1.5~20.0	50	123.4	75	M24X1.5	55	BT30 7/24	0.72	EY32	FS50
-EYC32-105			153.4	105		80		0.98		