




RUBBER WHETSTONE E CYLINDER TYPE

ゴム砥石E 円筒型



3mm
軸長30mm

6mm
軸長35mm

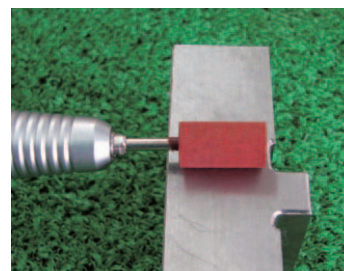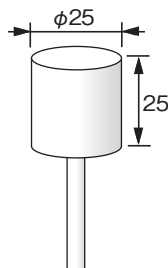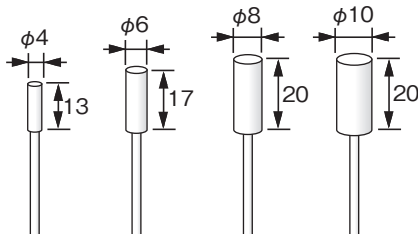

サイズ Size(mm) 外径×長さ×軸径	粒度 Grit 品番 NO.							入数 Pack	MAX min ⁻¹	Price ¥
	#80	#120	#180	#220	#400	#800	#1500			
4×13×3	GCME-45	GCME-47	GCME-49	GCME-410	GCME-412	GCME-414	GCME-417	10本	30,000	180
6×17×3	GCME-65	GCME-67	GCME-69	GCME-610	GCME-612	GCME-614	GCME-617			210
8×20×3	GCME-85	GCME-87	GCME-89	GCME-810	GCME-812	GCME-814	GCME-817			220
10×20×3	GCME-105	GCME-107	GCME-109	GCME-110	GCME-112	GCME-114	GCME-1117			230
25×25×6	GCME-255	GCME-257	GCME-259	GCME-2510	GCME-2512	GCME-2514	GCME-2517			20,000

RUBBER WHETSTONE TRIAL KIT

ゴム砥石お試しキット



- 特殊硬質ゴムに砥粒を結合させた弾性砥石で、優れた研削力と耐摩耗性を持っています。
- 硬い砥石に比べ非常に柔軟性に富み、ワークによく馴染みます。

3mm



【用途】

- 一般金属の研削・研磨
- 超硬合金・セラミックの研削・研磨
- 金型の研削・研磨

キット内容

品番 NO.	粒度 Grit	サイズ Size(mm) 外径×長さ	入数 Pack
GCM-45	#80	4×13	5本
GCM-47	#120		
GCM-49	#180		
GCM-410	#220		
GCM-411	#320		
DOX-413	#600		

サイズ Size(mm)	タイプ Type	品番 NO.	入数 Pack	MAX min ⁻¹	Price ¥
3mm軸	30本入	GCM-SET	1SET	30,000	7,400