


GRINDING RUBBER WHETSTONE

# 研磨用ゴム砥石

●光沢のある仕上げ面が要求される場合に適しています。


【特長】

- 軸付砥石と比べ深いキズを残さず均一な研磨面が得られます。
- 二次バリや返りバリ、チッピングの発生がおこりにくいです。

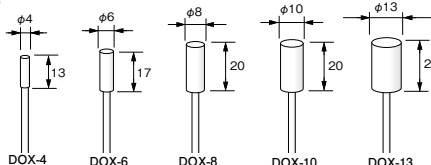


## 円筒タイプ φ3mm 軸長30mm

サイズ Size(mm) 外径×長さ	粒度 Grit 品番 NO. Price ¥(1本単価)						入数 Pack	MAX min <sup>-1</sup>
	#400	#600	#800	#1000	#1500	#2000		
4×13	DOX-412	DOX-413	DOX-414	DOX-415	DOX-417	DOX-418	10本	30,000
	280	300	330		350	400		
6×17	DOX-612	DOX-613	DOX-614	DOX-615	DOX-617	DOX-618		
	320	340	370		390	450		
8×20	DOX-812	DOX-813	DOX-814	DOX-815	DOX-817	DOX-818		
	330	350	380		410	460		
10×20	DOX-1012	DOX-1013	DOX-1014	DOX-1015	DOX-1017	DOX-1018		
	340	370	400		430	480		
13×20	DOX-1312	DOX-1313	DOX-1314	DOX-1315	DOX-1317	DOX-1318		
	370	410	440		470	530		

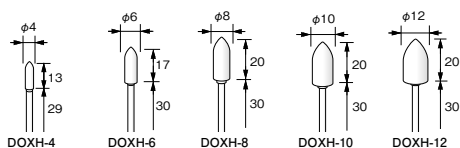


## 砲弾タイプ φ3mm

サイズ Size(mm) 外径×長さ	粒度 Grit 品番 NO. Price ¥(1本単価)						入数 Pack	MAX min <sup>-1</sup>
	#400	#600	#800	#1000	#1500	#2000		
4×13	DOXH-412	DOXH-413	DOXH-414	DOXH-415	DOXH-417	DOXH-418	10本	30,000
	280	300	330		350	400		
6×17	DOXH-612	DOXH-613	DOXH-614	DOXH-615	DOXH-617	DOXH-618		
	320	340	370		390	450		
8×20	DOXH-812	DOXH-813	DOXH-814	DOXH-815	DOXH-817	DOXH-818		
	330	350	380		410	460		
10×20	DOXH-1012	DOXH-1013	DOXH-1014	DOXH-1015	DOXH-1017	DOXH-1018		
	340	370	400		430	480		
12×20	DOXH-1212	DOXH-1213	DOXH-1214	DOXH-1215	DOXH-1217	DOXH-1218		
	370	410	440		470	530		

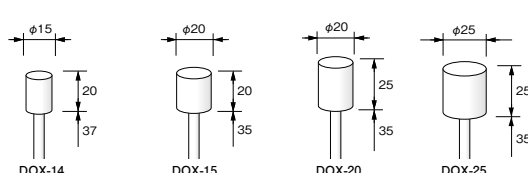

## 円筒タイプ φ6mm

サイズ Size(mm) 外径×長さ	粒度 Grit 品番 NO. Price ¥(1本単価)						入数 Pack	MAX min <sup>-1</sup>
	#400	#600	#800	#1000	#1500	#2000		
15×20	DOX-1412	DOX-1413	DOX-1414	DOX-1415	DOX-1417	DOX-1418	10本	20,000
	520	560	600		650	730		
20×20	DOX-1512	DOX-1513	DOX-1514	DOX-1515	DOX-1517	DOX-1518		
	550	590	640		680	770		
20×25	DOX-2012	DOX-2013	DOX-2014	DOX-2015	DOX-2017	DOX-2018		
	630	680	740		790	890		
25×25	DOX-2512	DOX-2513	DOX-2514	DOX-2515	DOX-2517	DOX-2518		
	820	880	950		1,020	1,160		

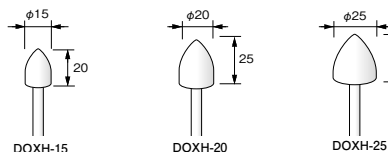

## 砲弾タイプ φ6mm 軸長35mm

サイズ Size(mm) 外径×長さ	粒度 Grit 品番 NO. Price ¥(1本単価)						入数 Pack	MAX min <sup>-1</sup>
	#400	#600	#800	#1000	#1500	#2000		
15×20	DOXH-1512	DOXH-1513	DOXH-1514	DOXH-1515	DOXH-1517	DOXH-1518	10本	20,000
	550	590	640		680	770		
20×25	DOXH-2012	DOXH-2013	DOXH-2014	DOXH-2015	DOXH-2017	DOXH-2018		
	630	680	740		790	890		
25×25	DOXH-2512	DOXH-2513	DOXH-2514	DOXH-2515	DOXH-2517	DOXH-2518		
	820	880	950		1,020	1,160		