



HB-k型

重荷重用ゴム車輪付固定車


(単位：mm)

重荷重用ゴム車輪付 固定車 (HB-k型)

FCDダクタイトル製金具




HB-k250x75

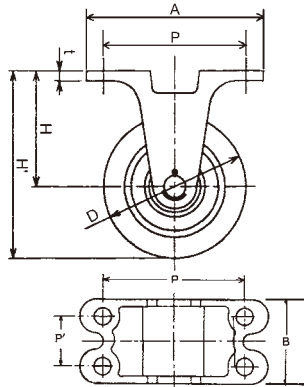

ゴム車輪付固定車 車輪外径x車輪巾	許容荷重 (kg)	金具高さ H	車輪取付 総高 H'	取付ピッチ PxP'	取付穴径	取付座 厚さt	取付座寸法 AxB	自重 (kg)
HB-k100x50	150	90	140	85	11	9.5	113x76	2.2
HB-k100x65	195	90	140	90x40	11	9.5	118x91	2.8
HB-k130x50	200	115	178	128	11	12.0	155x75	2.9
HB-k130x65	250	115	178	105x40	11	9.5	133x93	4.6
HB-k150x50	225	135	210	150	15	12.0	183x75	4.0
HB-k150x65	270	135	210	120x45	13	11.5	153x93	5.5
HB-k150x75	345	135	210	135x73	13	11.5	166x106	6.3
HB-k150x100	520	150	225	140x45	15	17.5	177x145	10.5
HB-k180x50	270	140	230	160	13	12.0	205x82	4.8
HB-k180x65	325	145	235	140x45	13	16.5	180x100	7.3
HB-k180x75	350	145	235	160x50	13	18.5	203x117	8.5
HB-k200x50	300	155	255	165	13	13.0	208x85	5.5
HB-k200x65	385	155	255	163x45	13	11.5	195x95	7.0
HB-k200x75	450	155	255	160x70	13	12.0	192x106	7.9
HB-k200x90	535	155	255	162x85	15	12.0	195x120	10.3
HB-k230x65	445	190	305	158x50	13	12.0	196x103	8.8
HB-k230x90	615	190	305	180x65	15	12.0	217x128	10.5
HB-k250x65	480	190	315	160x50	15	12.0	196x103	9.3
HB-k250x75	570	190	315	160x50	15	12.0	196x116	11.9
HB-k250x90	670	190	315	180x65	15	12.0	217x128	14.3
HB-k250x100	700	205	330	183x90	18	14.0	220x155	16.8
HB-k300x65	580	225	375	173x63	15	12.5	210x107	12.3
HB-k300x75	685	225	375	173x63	15	12.5	210x107	13.1
HB-k300x90	805	225	375	180x63	15	12.5	215x125	16.2
HB-k300x100	900	205	355	183x90	18	14.0	220x155	18.8

重荷重用ゴム車輪付 固定車 (HB-k型) 鉄製金具

(単位：mm)

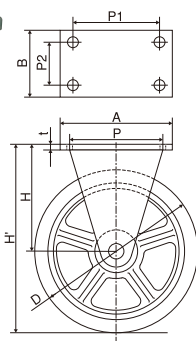

ゴム車輪付固定車 車輪外径x車輪巾	許容荷重 (kg)	金具高さ H	車輪取付 総高 H'	取付ピッチ P1xP2	取付穴径	取付座 厚さt	取付座寸法 AxB
HB-k360x90	800	242	422	230x200	16	16.0	280x250
HB-k410x65	840	280	485	230x180	16	16.0	280x220
HB-k410x75	780	280	485	230x180	16	16.0	280x220
HB-k410x90	900	280	485	230x200	16	16.0	280x250
HB-k410x100	1000	292	497	230x200	16	16.0	280x250
HB-k500x75	900	350	600	260x190	22	19.0	320x250
HB-k500x100	1300	350	600	260x190	22	19.0	320x250
HB-k500x130	1500	350	600	260x210	22	19.0	320x270
HB-k500x150	1800	350	600	260x210	22	19.0	320x270

※360x90以上は鉄板金具製です。
※走行速度は4km/h以下にて走行してください。

HB-k500x100