

SUS-J₂ TYPE



There are some non-conforming products.



Swivel



Plate type




Double bearing



Stainless steel



SUS-NJ₂-150

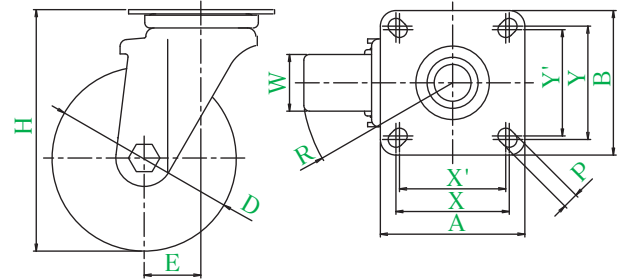

Description of product number

SUS - N J₂ - 150

Bracket type	Wheel type	Bracket type	Wheel diameter
--------------	------------	--------------	----------------

Bracket = Stainless steel

Product number	Wheels										
		Wheel diameter D(mm)	Wheel width W(mm)	Mounting height H(mm)	Mounting base A × B(mm)	Mounting dimensions X × Y (X' × Y') (mm)	Hole diameter P(mm)	Eccentricity E(mm)	Turning radius R(mm)	Allowance load daN(kgf)	Wheel weight (g)
SUS-	NR	130	40	170	102 × 102	80 × 80 (75 × 75)	11	40	105	160(163.2)	1365
	N J ₂ -130									150(153.0)	1330
	GU									160(163.2)	1400
	NR	150	40	190	102 × 102	80 × 80 (75 × 75)	11	40	115	180(183.6)	1490
	N J ₂ -150									160(163.2)	1410
	GU									180(183.6)	1470

Wheel in use

Refer to P162 for detailed specifications.



NR
Rubber wheel with nylon wheel assembly (including B)



N
Nylon wheel (including B)



GU
Urethane wheel with nylon wheel assembly (including B)

J

PM

J₂

RJ₂

SJ

S

E

G

L

SA

H

CAL

-H

M

PL

Silence

SUS

-J₂

SUS

-SJ

SUS

-S

SUS

-E

SUS

-H

P

SKY

Equipped with adjuster foot

Special

Easy lock

Wheels