

Guide Rail Brackets

Engineering Plastic Rails



Conveyor Engineering Plastic Guide Rail Brackets - Standard Type





RoHS 10

CGX (W=50, 60) CGXL (W=100)

 No.55

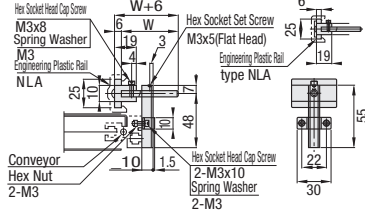



No.80

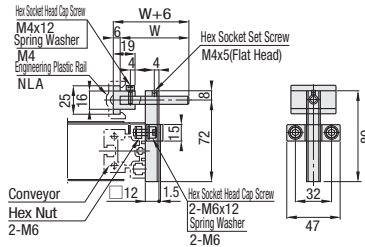 

- ⊙ NO.55 ~ 80 have different bolt size for the conveyor mount part. Select an appropriate bolt according to the conveyor you are using.
- ⊙ Engineering plastic rail is not included.

 No.70

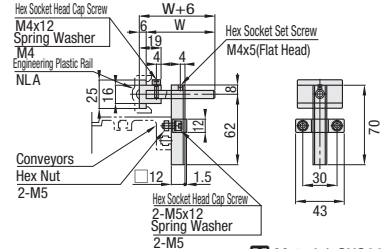

Material: SUS304

Part Number		W	Unit Price
Type	No.		
CGX (W=50,60)	55	50	
	70	60	
	80	60	
CGXL (W=100)	55	100	
	70		
	80		



Part Number	
Type	No.
CGX	55



Conveyor Engineering Plastic Guide Rail Brackets - Offset Type





RoHS 10

CGY (W=50, 60) CGYL (W=100)

 No.55

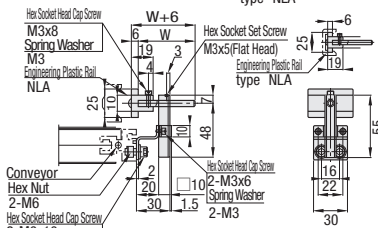



No.80

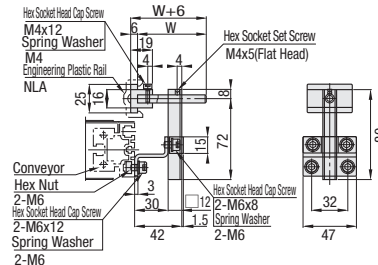 

- ⊙ NO.55 ~ 80 have different bolt size for the conveyor mount part. Select an appropriate bolt according to the conveyor you are using.
- ⊙ Engineering plastic rail is not included.

 No.70

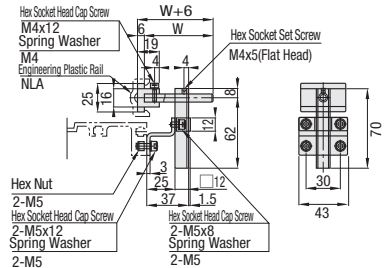

Material: SUS304

Part Number		W	Unit Price
Type	No.		
CGY (W=50,60)	55	50	
	70	60	
	80	60	
CGYL (W=100)	55	100	
	70		
	80		



Part Number	
Type	No.
CGY	70



Alterations




Part Number	
Type	No.
CGX	70
CGYL	80

- (CL)
- CL
- CL

Alterations

Change to Product with Clamp Lever

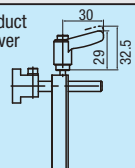

CL

Code

Spec.

Hex socket set screws are replaced with the clamp lever (Orange, CLDMC4-8-M equivalent).

⊗ Not applicable to CGX55/CGXL55/CGY55/CGYL55