


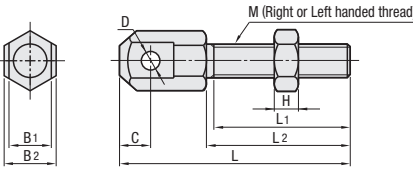
# Turnbuckle Components

■ **Features:** Turnbuckle Components can be purchased as separate items.

■ **Standard Long**



Type		Parts	Material	Surface Treatment	Hardness
Standard	Long				
Right-Hand Thread	Left-Hand Thread	Right-Hand Thread	Main Body: S45C Nut: SS400	Black Oxide	35-40HRC
SRC-R	SRC-L	LSRC-R			
SRCs-R	SRCs-L	-	Main Body: SUS303 Equivalent Nut: SUS304 Equivalent	-	-



RoHS10

■ **Standard**

Part Number Type	Applicable Roller Chain Nominal	M (Coarse)	L <sub>1</sub>	L <sub>2</sub>	L	C	D	B <sub>1</sub>	B <sub>2</sub>	H	Max. Load (kN)		Mass (g)	Unit Price	
											SRC-R, L	SRCs-R, L		SRC-R, L	SRCs-R, L
SRC-R (Right-hand Thread)	*15	3	10	12	20.6	2.2	1.7	3.4	6	1.8	0.44	-	2.8	-	-
	*25	4	16.5	18	28.2	3	2.4	4.8	7	2.4	0.78	0.68	5	-	-
SRC-L (Left-hand Thread)	*35	6	23.5	25	40	4.5	3.7	7.4	10	3.6	1.96	1.57	12	-	-
	*40	8	31	33	52.5	6	4	11.2	13	5	3.53	2.84	30	-	-
SRCs-R (Right-hand Stainless Steel Thread)	*50	10	39	41	65	7.5	5.2	13.8	17	6	5.68	4.51	60	-	-
SRCs-L (Left-hand Stainless Steel Thread)	60	12	47	49	78	9	6	17.8	19	7	8.23	6.57	100	-	-
	80	16	57	60	98	12	8	22.6	24	10	15.4	12.3	210	-	-


⚠ 15 is not available for SRCs-R. SRCs-L is available for sizes marked with \* only.

⚠ Please check the Allowable Tension of the paired Chains.


■ **Long**

Part Number Type	Applicable Roller Chain Nominal	M (Coarse)	L <sub>1</sub>	L <sub>2</sub>	L	C	D	B <sub>1</sub>	B <sub>2</sub>	H	Max. Load (kN)	Mass (g)	Unit Price
	35	8	50	54	69	4.5	3.7	7.4	10	5	1.96	27	-
	40	10	60	64.5	84	6	4	11.2	13	6	3.53	56	-
	50	12	65	71	95	7.5	5.2	13.8	17	7	5.68	94	-
	60	16	100	106	135	9	6	17.8	19	10	8.23	218	-
	80	20	119	127	165	12	8	22.6	24	12	15.4	414	-

■ **Threaded**



Type		Parts	Material	Surface Treatment	Hardness
Right-Hand Thread	Left-Hand Thread				
HSB-R	HSB-L	Main Body: S45C Nut: SS400	S45C SS400	Black Oxide	35-40HRC

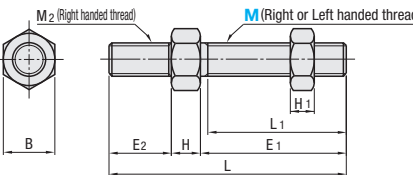


RoHS10


■ **Threaded**

Part Number Type	M (Coarse)	L <sub>1</sub>	E <sub>1</sub>	M <sub>2</sub>	E <sub>2</sub>	H	H <sub>1</sub>	L	B	Mass (g)	Unit Price
	6	23.5	25	M6	12	5	3.6	42	10	10	-
	8	31	33	M8	16	6.5	5	55.5	13	25	-
HSB-L (Left-Hand Thread)	10	39	41	M10	20	8	6	69	17	45	-
	12	47	49	M12	24	10	7	83	19	80	-
	16	57	60	M16	32	13	10	105	24	170	-

 ■ **Tapped**



Type Tapped	Material	Surface Treatment
SJN	SUM22L	Black Oxide
SJNS	SUS303	-

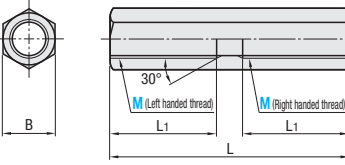

RoHS10

■ **Tapped**

Part Number Type	M (Coarse)	L	L <sub>1</sub>	B	Mass (g)	Unit Price	
						SJN	SJNS
SJN SJNS (Stainless Steel)	3	22	9	6	4	-	-
	4	33	14	7	8	-	-
	*6	43	19	10	20	-	-
	*8	55	25	13	45	-	-
	*10	67	31	17	95	-	-
	12	81	38	19	130	-	-
	16	95	45	24	260	-	-

⚠ SJNS is available for sizes marked with \* only.

Ordering Example: Part Number SRC-R40 HSB-R8 SJN10