


# Plastic Covered Chains

Registration of a design pending

■ **Features:** Metal chains with easy-mountable plastic covers. Has good allowable tension and suitable for accumulation conveyance of heavy objects.

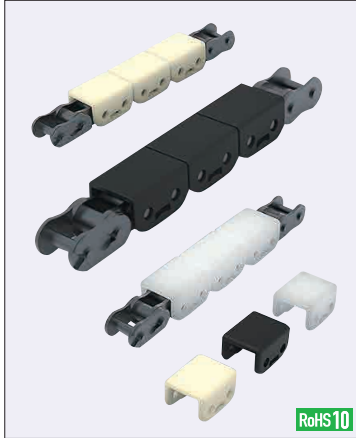

RoHS 10

 
 
 
 
Part Number		Specification	Material	Color	Sliding Friction Coefficient f1	Operating Temp. (°C)
Set	Cover Only					
CHECV	CHETC	General Use	POM	White	0.14~0.18	-5~65
CHECVS	CHETCS	Extra Low Friction	POM + Lubricant	Cream	0.12~0.15	-5~65
CHECVC	CHETCC	Conductivity, Heat Resistant	POM + Glass Fiber	Black	0.20~0.24	-20~120
CHECVY	CHETCY	Chemical Resistant	Fluororesin	White	0.18~0.22	-20~80

■ **Set**

CHECV  
CHECVS  
CHECVC  
CHECVY

■ **Cover Only**

CHETC  
CHETCS  
CHETCC  
CHETCY



■ **Allowable Tension and Reference Weight**

Nominal	Allowable Tension (kN)			Reference Weight (kg/m)		
	SS	SUS	M	SS	SUS	M
40	3.63	0.44	3.63	0.89	0.91	0.95
60	8.83	1.03	8.83	1.94	1.95	2.07

☞ For Allowable Tension and Corrosion Resistance List, see P.1577

Part Number			Number of Links (Specifiable Unit : 2 Links)	L	W	H1	H2	Part Number			Number of Links (Specifiable Unit : 1 Link)	L	W	H1	H2
Type	Nominal	Chain Type						Type	Nominal	Chain Type					
Set CHECV CHECVS CHECVC CHECVY	40	SS (Steel) SUS (Stainless Steel)	20~1000	20.6	12.7	6	8.9	Cover Only CHETC CHETCS CHETCC CHETCY	40	SS (Steel) SUS (Stainless Steel)	20~1000	20.6	12.7	6	8.9
	60	M (Lubrication-Free)		30.1	19.05	9	12		60	M (Lubrication-Free)		30.1	19.05	9	12

☞ Specify links by even numbers. The last link is the Joint Link.

■ **Set (Metal Chains + Plastic Cover)**

Type	Nominal	Chain Type	Unit Price (Unit : 1 Link)											
			CHECV	CHECVS	CHECVC	CHECVY	CHECV	CHECVS	CHECVC	CHECVY	CHECV	CHECVS	CHECVC	CHECVY
Set CHECV CHECVS CHECVC CHECVY	40	SS (Steel) SUS (Stainless Steel)	Chain Type : SS				Chain Type : SUS				Chain Type : OL			
	60	M (Lubrication-Free)												

■ **Plastic Cover Only**

Part Number		Number of Links (Specifiable Unit : 20 Links)	Chain Type	Unit Price (Unit : 20 Links)			
Type	Nominal			CHETC	CHETCS	CHETCC	CHETCY
Cover Only CHETC CHETCS CHETCC CHETCY	40	20	(SS, SUS) Not Specified (M) M				
	60						

■ **How to be delivered**

When the ordered number of links exceeds the given number of links per unit, the qty. of links per unit and the extra qty. of links are packaged separately. (Ex.) For CHECV40-300, 2 separate packages: 240 links x 1 unit + 60 links



Ordering Example  
Part Number - Number of Links  
CHECV40SS - 474  
CHETC60M - 28



Example

