

Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, Indonesia and/or India offices.

Square Shim Package / Square Shims (Adjustment)

For Motor Base / For Pillow Block




Type		Material	Hardness	Thickness (T) Tolerance				
For Motor Base	For Pillow Block			0.05	0.1	0.2	0.5	1.0
PACK-CIMMS	PACK-CIMSS	SUS304H	370~430HV	±0.005	±0.02	±0.03	±0.04	±0.05

For Motor Base / For Pillow Block Sold by the package (1 package contains 10 pieces.)

Part Number Type	No.	T Selection	A	B	C	Q	D	E	Unit Price					
									T0.05	T0.1	T0.2	T0.5	T1.0	
For Motor Base (SUS304H) PACK-CIMMS	1035		10	-	5	3.5	-	-						
	1245		12	-	6	4.5	-	-						
	1455		14	-	7	5.5	-	-						
	1665		16	-	8	6.5	-	-						
	2009		20	-	10	9	-	-						
	3013		30	-	15	13	-	-						
	4312		43	-	22	12	-	-						
	4814		48	-	24	14	-	-						
	5314		53	-	27	14	-	-						
	6816		68	-	34	16	-	-						
8320		83	-	42	20	-	-							
9825		98	-	49	25	-	-							
For Pillow Block (SUS304H) PACK-CIMSS	10	0.05	16	17.5	10.5	7	7	2						
	12	0.1	16	18	10.5	7	7	2.5						
	15	0.2	16	20	11.5	7	7	2.5						
	17	0.5	18	21	12	7	8	2.5						
	20	1.0	20	24.5	14.5	10	10	3						
	25		20	27.5	16.5	10	10	3						
	30		26	33	20	13	13	4						
	204A		40	27	15	13	-	-						
	205A		45	30	16	13	-	-						
	206A		50	36	22	17	-	-						
	207A		55	41	26	17	-	-						
	208A		58	41	25	17	-	-						
	204		38	42	26	13	-	-						
	205		38	42	25	13	-	-						
	206		48	54	32	17	-	-						
	207		48	54	34	17	-	-						
	208		54	58	35	17	-	-						
	209		54	60	38	17	-	-						
210		60	65	42	20	-	-							

Ordering Example	Part Number	T
	PACK-CIMMS2009	0.5
	PACK-CIMSS204A	0.1

Please specify number of packages to order. Quantity 1 means one package.

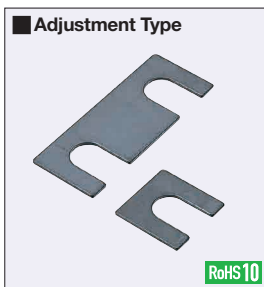

Type		Material	Surface Treatment	Hardness	Thickness (T) Tolerance	
One Slot	Two Slots				0.5	1.0
ASA	ASF	SPPC Equivalent	Black Oxide	-	±0.05	±0.1
ASAS	-	SUS304H	-	370~430HV		

Part Number Type	T	No.	A	C	Q	ASA				ASAS				
						T0.5		T1.0		T0.5		T1.0		
						Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	
ASA ASAS	0.5 1.0	1035	10	5	3.5									
		1245	12	6	4.5									
		1455	14	7	5.5									
		1665	16	8	6.5									
		2009	20	10	9									

Part Number Type	T	P	L	Unit Price	Volume Discount Rate
				1 - 49 pc(s)	50~100
ASF	0.5 1.0	30	50		
		40	60		
		50	70		
		30	50		
		40	60		

For orders larger than indicated quantity, please check with WOS.

Ordering Example	Part Number	No.
	ASA0.5	1035
Ordering Example	Part Number	P
	ASF0.5	30

For orders larger than indicated quantity, please check with WOS.