

Note that, for some of the types shown here, order might be unable to be received by the MISUMI Thailand, Malaysia, Indonesia, and/or India offices.

Hex Socket Head Cap Screws


Stainless Steel (Available in Box)



Box package is cost-saving for in-house stock or when large quantities are needed.

Type	Material
BOX-SCB	SUS304 Equivalent

Strength Class A2-70

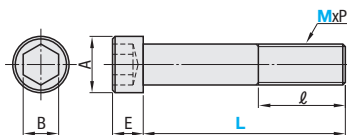

MxP (Coarse)	A	E	B
2 x0.4	3.8	2	1.5
2.5x0.45	4.5	2.5	2
2.6x0.45	4.5	2.6	2
3 x0.5	5.5	3	2.5
4 x0.7	7	4	3
5 x0.8	8.5	5	4
6 x1.0	10	6	5
8 x1.25	13	8	6
10 x1.5	16	10	8

Can be ordered as a separate item. **P.174**

*The strength class signifies the screw's tensile strength.

(Ex.) A2 - 70

This indicates that the minimum value of tensile strength is 700N/mm².
The steel class is A2 (Austenitic Stainless Steel)

Please specify in box quantity when ordering.
One box is shipped for an order of 1.



Ordering Example

Part Number

BOX-SCB3-6

ℓ	Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
	Type	M-L	Price per pkg.	1 Box	
18	Studs - Fully Threaded	2- 5			1,000 pcs./box
		8			
		10			
		12			
		15			
		2.5- 5			
		8			
		10			
		2.6- 5			
		8			
		10			
		3- 5			
		6			
		8			
		10			
18	Studs - Fully Threaded	12			500 pcs./box
		15			
		20			
		25			
		30			
		4- 5			
20	Studs - Fully Threaded	6			1,000 pcs./box
		8			
		10			
		12			
		15			
		20			
		25			
		30			
		35			
		40			
20	Studs - Fully Threaded	40			400 pcs./box
		5- 8			
		10			
		12			
		15			
		20			
		25			
		30			
		35			
		40			
22	Studs - Fully Threaded	5- 8			1,000 pcs./box
		10			
		12			
		15			
		20			
		25			
		30			
		35			
		40			
		40			
24	Studs - Fully Threaded	6- 8			1,000 pcs./box
		10			
		12			
		15			
		20			
		25			
		30			
		35			
		40			
		40			
28	Studs - Fully Threaded	8-12			500 pcs./box
		15			
		20			
		25			
		30			
		35			
		40			
		40			
		40			
		40			
28	Studs - Fully Threaded	10-20			200 pcs./box
		25			
		30			
		35			
		40			
		40			