

Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, Indonesia and/or India offices.


# Hex Socket Head Cap Screws / Hex Socket Head Cap Screws

Trivalent Chromate (Available in Pkg.)-

Bright Chromate Plating



## PACK-SCBE

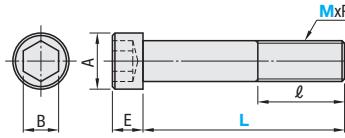


- M** Material SCM435
- S** Surface Treatment Trivalent Chromate
- H** Hardness HRC32~39 \* Strength Class: 10.9

RoHS10



## CBM

Ⓢ CBM is not RoHS compliant.

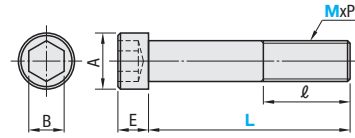

- M** Material SCM435
- S** Surface Treatment Bright Chromate Plating
- H** Hardness HRC32~39 \* Strength Class: 10.9

Part Number	ℓ	PACK-SCBE	
		Unit Price	Volume Discount Rate
Type M-L		Pcs. per Pkg.	1-4 pks./s, 5-20 pkg.
PACK-SCBE 2-5	Studs - Fully Threaded		
6			
8			
10			
PACK-SCBE 2.6-5	Studs - Fully Threaded		
6			
8			
10			
PACK-SCBE 3-5	Studs - Fully Threaded		
6			
8			
10			
12			
15			
20			
25			
30			
35			
PACK-SCBE 4-6	Studs - Fully Threaded		
8			
10			
12			
15			
20			
25			
30			
35			
40			
45			
PACK-SCBE 5-8	Studs - Fully Threaded		
10			
12			
15			
20			
25			
30			
35			
40			
45			
50			

Part Number	ℓ	PACK-SCBE	
		Unit Price	Volume Discount Rate
Type M-L		Pcs. per Pkg.	1-4 pks./s, 5-20 pkg.
PACK-SCBE 6-8	Studs - Fully Threaded		
10			
12			
15			
20			
25			
30			
35			
40			
45			
50			
60			
PACK-SCBE 8-12	Studs - Fully Threaded		
15			
20			
25			
30			
35			
40			
45			
50			
60			
PACK-SCBE 10-15	Studs - Fully Threaded		
20			
25			
30			
35			
40			
45			
50			
55			
60			
PACK-SCBE 12-15	Studs - Fully Threaded		
20			
25			
30			
35			
40			
45			
50			
55			
60			

Part Number	ℓ	CBM	
		Unit Price	Volume Discount Rate
Type M-L		1-99 pcs.	100 - 200 pcs.
CBM 3-6	Studs - Fully Threaded		
8			
10			
12			
15			
20			
25			
30			
35			
40			
45			
50			
55			
60			
CBM 4-6	Studs - Fully Threaded		
8			
10			
12			
15			
20			
25			
30			
35			
40			
45			
50			
55			
60			
CBM 5-8	Studs - Fully Threaded		
10			
12			
15			
20			
25			
30			
35			
40			
45			
50			
CBM 6-8	Studs - Fully Threaded		
10			
12			
15			
20			
25			
30			
35			
40			
45			
50			

Part Number	ℓ	CBM	
		Unit Price	Volume Discount Rate
Type M-L		1-99 pcs.	100 - 200 pcs.
CBM 8-12	Studs - Fully Threaded		
15			
20			
25			
30			
35			
40			
45			
50			
55			
60			
CBM 10-15	Studs - Fully Threaded		
20			
25			
30			
35			
40			
45			
50			
55			
60			
CBM 12-15	Studs - Fully Threaded		
20			
25			
30			
35			
40			
45			
50			
55			
60			

\*The (ℓ) part is based on JIS B 1176

\*The (ℓ) part is based on JIS B 1176 (2000).



Ordering Example

Part Number  
PACK-SCBE6-10  
CBM8-20

- Ⓢ PACK-SCBE is sold by the package, and CBM is sold as a single item.
- Ⓢ For package sales, minimum order is 1 pack.