 



One End Tapped




RoHS10

Type	D Tolerance	M Material	H Hardness
MST	p6	SUU2	45~50HRC
MSTM	m6	SUS440C	45~50HRC
MSTMS		SUS440C	

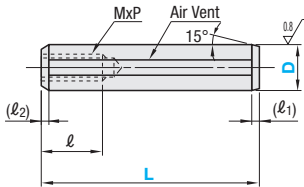

Air Vent Depth

All air vents are identical in depth.

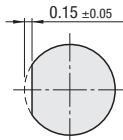

⚠ When D=5 or 6 and L=10, the pilot hole for tapping may go through.

⚠ * ℓ=6 only when D=6 and L=10

⚠ ℓ1, ℓ2 dimension may become larger than the value shown in the catalog due to polishing process.

ℓ1	ℓ2	M x P	ℓ	Dp6	Part Number		L	Unit Price	Volume Discount Rate	
					Type	D				
1.5	0.5	3 x 0.5	6	+0.020	MST	p6 Type	5	10 15 20 25 30	1~299	300~500
							6	20 30		
2.0	0.5	4 x 0.7	*8	+0.012	MST	p6 Type	6	10 15 25 35 40 50	1~299	300~500
							8	15 20 25 30 40 45 50 60 70 80		
2.5	1.0	5 x 0.8	10	+0.024	MST	p6 Type	10	15 20 25 30 35 40 45 50 60 70 80	1~299	300~500
							12	20 30 40 50 60 70 80		
3.0	1.0	6 x 1.0	15	+0.015	MST	p6 Type	13	40 50 60 70 80	1~299	300~500
							16	40 50 60 70 80		
3.0	1.5	8 x 1.25	18	+0.029	MST	p6 Type	20	50 60 70 80	1~299	300~500
							20	50 60 70 80		

⚠ For orders larger than indicated quantity, please check with WOS.

ℓ1	ℓ2	M x P	ℓ	Dm6	Part Number		L	Unit Price	Volume Discount Rate	
					Type	D				
1.5	0.3	3 x 0.5	6	+0.012	MSTM	m6 Type	5	10 15 20 25 30	1~299	300~500
							6	20 30		
2.0	0.5	4 x 0.7	*8	+0.004	MSTM	m6 Type	6	10 15 25 35 40 50	1~299	300~500
							8	15 20 25 30 40 45 50 60 70 80		
2.5	1.0	5 x 0.8	10	+0.015	MSTM	m6 Type	10	15 20 25 30 35 40 45 50 60 70 80	1~299	300~500
							12	20 30 40 50 60 70 80		
3.0	1.0	6 x 1.0	15	+0.006	MSTM	m6 Type	13	40 50 60 70 80	1~299	300~500
							16	40 50 60 70 80		
3.0	1.5	8 x 1.25	18	+0.018	MSTM	m6 Type	20	50 60 70 80	1~299	300~500
							20	50 60 70 80		

⚠ MST, MSTM For orders of 1 ~ 9 pc(s); Unit Price + Low Quantity Surcharge (1 Line Item) ⚠ For orders larger than indicated quantity, please check with WOS.

ℓ1	ℓ2	M x P	ℓ	Dm6	Part Number		L	Unit Price	Volume Discount Rate			
					Type	D						
1.5	0.3	3 x 0.5	6	+0.012	MSTMS	m6 Type	5	10 15 20	1~19 pc(s)	20~29	30~49	50~100
							6	20 30				
2.0	0.5	4 x 0.7	*8	+0.004	MSTMS	m6 Type	6	10 15 25 30	1~19 pc(s)	20~29	30~49	50~100
							8	15 20 25 35 40				
2.0	0.5	5x0.8	*8	+0.015	MSTMS	m6 Type	10	20 25 30 35	1~19 pc(s)	20~29	30~49	50~100
							10	20 25 30 35				


⚠ For orders larger than indicated quantity, please check with WOS.

Tapered, Tapped



MTT

Material: SK95 Equivalent
Hardness: 45 ~ 50HRC

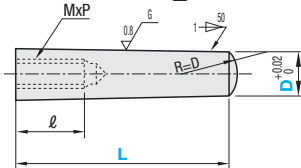

MxP	ℓ	Part Number		L	Unit Price	Volume Discount Rate			
		Type	D						
5x0.8	9	MTT	p6 Type	8	30 40	1~499 pc(s)	500~999	1000~1999	2000~4000
				10	40 50				
6x1.0	10	MTT	p6 Type	12	40 50	1~499 pc(s)	500~999	1000~1999	2000~4000
				13	50 60				
8x1.25	14	MTT	p6 Type	16	60 70	1~499 pc(s)	500~999	1000~1999	2000~4000
				16	60 70				

⚠ For orders larger than indicated quantity, please check with WOS.

For orders larger than indicated quantity, please request a quotation. P99



Ordering Example

Part Number	-	L
MSTP5	-	10
MSTMS6	-	20