 


Note that, for some of the types shown here, order might be unable to be received by the MISUMI Malaysia, and/or Indonesia offices.

Post-Assembly Insertion Nuts for Aluminum Extrusions - Others

For 8 Series (Slot Width 10mm)




Tightening Torque P.526

Post-Assembly Insertion Lock Nuts with Leaf Springs

RoHS 10

Part	Material	Surface Treatment
Main Body	S10C Equivalent	Trivalent Chromate
Wing Part	SUS304	-

HNTRP8

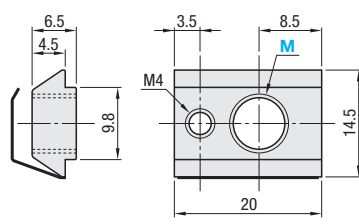

Reference Tightening Torque (N·m)	
M	S10C Equivalent
8	23.5

Part Number	M	Accessory	Unit Price	Volume Discount Rate		
			1 ~ 499 pc(s).	500~749	750~999	1000~1500
HNTRP8	8	M4x4 Set Screw for Locking				


Post-Assembly Insertion Lock Nuts

RoHS 10

* Electrically conductive

Type	Material	Surface Treatment
HNTR8, HNTRZ8	S10C Equivalent	Trivalent Chromate
HNTRS8*	SUS316 Equivalent (Sintered)	-

HNTR8 (S10C Equivalent)
HNTRS8 (SUS316 Equivalent, Sintered)
HNTRZ8 (Thread Locking, S10C Equivalent)

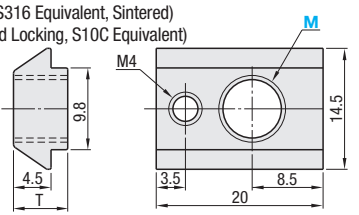

Reference Tightening Torque (N·m)	
M	S10C Equivalent / SUS316 Equivalent (Sintered)
8	23.5

Part Number Type	M	T	Accessory	Unit Price	Volume Discount Rate		
				1 ~ 499 pc(s).	500~749	750~999	1000~1500
HNTR8 (S10C Equivalent)	4 5 6 8	6.5	M4x6 Set Screw for Locking 1 pc.				
HNTRS8 (SUS316 Equivalent, Sintered)		6.0					
HNTRZ8 (Thread Locking, S10C Equivalent)		8		6.5			

Ordering Example Part Number - M
HNTR8 - 8

Example **Post-Assembly Insertion Lock Nut**

The nut can be fixed in place by itself by tightening the included set screw.

Suitable for use where high repeatability is required, such as mounting sensors or repeatedly replacing panels.

Post-Assembly Insertion Lock Nut with Leaf Springs

Welded Leaf Springs prevents nuts from slipping off even if inserted into the vertically-oriented extrusions, leading to easy locking.

Also, the nut can be fixed in place by tightening the included set screw.

Post-Assembly Insertion Short Nut

HNTAJ8
PACK-HNTAJ8

• Overall length is shorter than Pre-Assembly Insertion Nuts HNTT. Suitable for installing sensors or other components closely together.

Ordering Example Part Number - M
HNTAJ8 - 8

Part Number	M	L	HNTAJ8				PACK-HNTAJ8			
			Unit Price	Volume Discount Rate			Unit Price	Volume Discount Rate		
			1 ~ 499 pc(s).	500~749	750~999	1000~1500	1 pkg.	2~4	5~9	10~20
HNTAJ8 PACK-HNTAJ8	3 4 8	10 12								