 



Aluminum Pull Handles / Sheet Metal Pull Handles



Type		Material	Surface Treatment
L Fixed	L and F Configurable		
① UADL	UADLF	Aluminum Alloy	Tumble Polish
② UADR	UADRF		Electrostatic Paint (Mat Black)
③ UADLA	-		Buffing
④ UADEL	-		Clear Anodize
⑤ UADS	UADSF	SUS304	Sandblasting

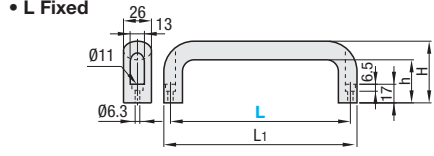


Part Number	Type	L	L1	H	h	Allowable Load (N)	Unit Price				
							UADL	UADR	UADLA	UADEL	UADS
(L Fixed)	100	114	47	30	1200			-	-		
UADL	116	130	53	36	1200						
UADR	132	146	55	38	800						
UADLA	150	164	67	50	600						
UADEL	164	178	57	40	600						
UADS	196	210			390						

Part Number	Type	D	1mm Increment		Allowable Load for Reference (N)	Unit Price		
			L	F		UADLF	UADRF	UADSF
(L and F Configurable)	26	100-200	30-50	390-1200				
UADLF								
UADRF								
UADSF								

Ordering Example: Part Number - L - F
 UADR 116
 UADLF26 - 100 - 40
 *"- is not necessary for L Fixed Type.




Type	Material	Surface Treatment
① HHDF	Aluminum Alloy	Electrostatic Paint (Mat Black)
② HHDFL	Aluminum Alloy	Tumble Polish
③ HH DFA	Aluminum Alloy	Buffing

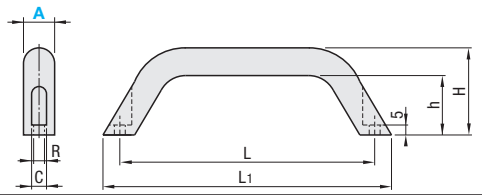



Part Number	Type	A	Mass (g)	L	L1	H	h	R	C	Unit Price		
										HHDF	HHDFL	HH DFA
19	HHDF	64	90	107	41	29	5.3	9				
20	HHDFL	110	93.5	112	44	31	6.5	10.5				
26	HH DFA	250	130	149	57	40	8.5	13.3				



Type	Material	Surface Treatment
UWDSU	SS400	Chrome Plating
UWDSUS	SUS304	Buffing

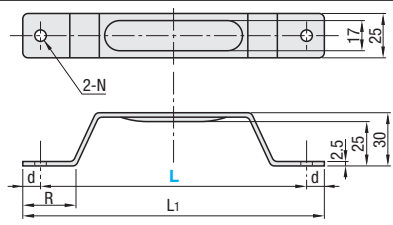

Part Number	Type	L	L1	R	d	N	Allowable Load (N)	Mass (g)	Unit Price	
									UWDSU	UWDSUS
UWDSU (Steel)	80	96	20	8	5.5	400	61			
UWDSU (Stainless Steel)	100	116	23	8	5.5	380	70			
UWDSU (Stainless Steel)	150	170	30	10	6.5	160	93			

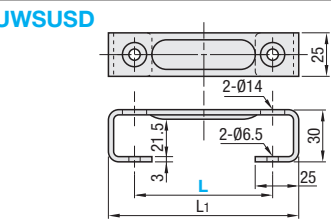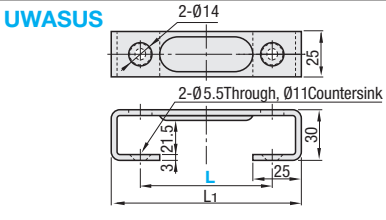

Part Number	Type	L	L1	Mass (g)	Unit Price	
					UWASUS	UWSUSD
68	UWASUS	98	105			
100	UWASUS	130	120			
110	UWASUS	140	130			
120	UWASUS	150	135			
150	UWASUS	180	155			
188	UWASUS	218	185			
238	UWASUS	268	215			
288	UWASUS	318	235			

Ordering Example: Part Number UWASUS100

Material: SUS304
 Surface Treatment: Buffing