


# Pull Handles - Folding / Round Bar Threaded / Side Mount / T-Shaped Threaded




## UWAFN

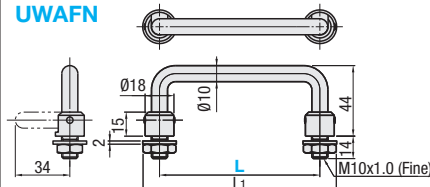

M	Material	S	Surface Treatment	A	Accessory
SUM22L	Chrome Plating	Washer (SUS304) 2 pcs.		Nut (SUS304) 2 pcs.	

Part Number Type	L	L <sub>1</sub>	Allowable Load (N)	Mass (g)	Unit Price
				UWAFN	100
	120	138	156		
	180	198	225		


ex Example

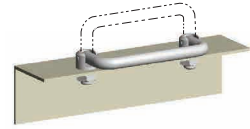


Ordering Example Part Number UWAFN100



Type	M	Material	S	Surface Treatment
UWANM	SUM22L or SUM24L	Chrome Plating		
UWANSM	SUS304	Buffing		

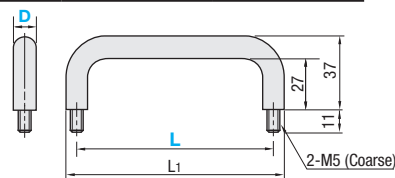

ex Example

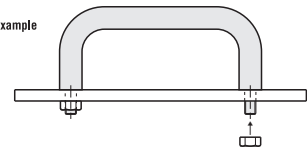


Part Number Type	D	L	L <sub>1</sub>	Allowable Load (N)	Mass (g)	Unit Price	
						UWANM	UWANSM
UWANM (Steel) UWANSM (Stainless Steel)	10	80	90	2500	76		
		100	110		88		
		110	120		94		
		120	130		100		
		125	135		103		
		160	170		125		
		200	210		150		
		250	260		180		

Ordering Example Part Number - L UWANM10 - 100




Type	M	Material	S	Surface Treatment
UWANY	SUS304 Equivalent	Buffing		

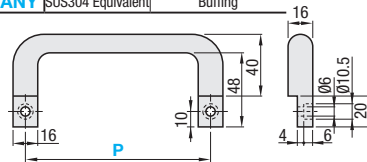

Part Number Type	P	Allowable Load (N)	Mass (g)	Unit Price
UWANY	120	500	270	


ex Example

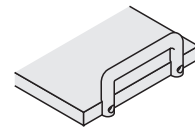

Ordering Example Part Number UWANY120



## Threaded Type TSPM

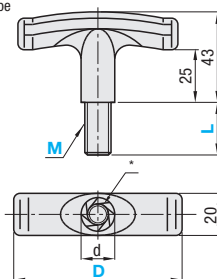

\* There is a 0.2 mm protrusion to prevent looseness.

	M	Material	S	Surface Treatment
Handle	Glass Fiber Reinforced Nylon (Mat Black)	-		
Thread	SS400 (Insert)	Trivalent Chromate		

Part Number Type	D	M	L Selection	d	Reference Mass (g)	Unit Price	
Threaded Type TSPM	50	4	10	11	30		
		5	15		32		
		6	20		34		
	80	6	15		16	53	
		8	20			65	
		10	25			69	

Ordering Example Part Number - M - L TSPM50 - 4 - 10