 


Manifold Blocks - Hydraulic / Pneumatic


Lateral Through Hole, Upper Hole



For details of recommended tapered male thread tightening torque and through pilot hole, see P.1224.



RoHS10

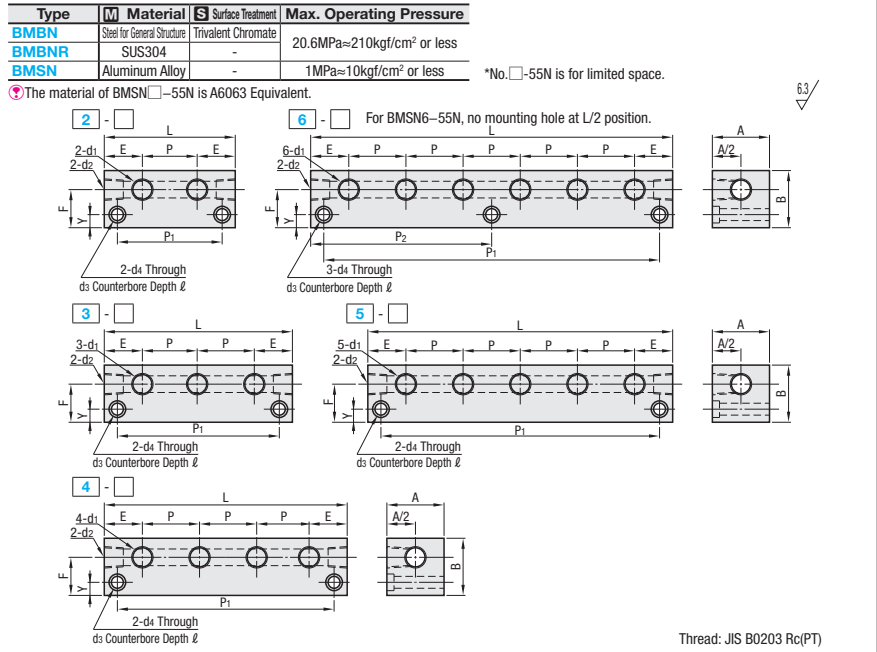

Part Number	Type	No.	d1 Rc(PT)	d2 Rc(PT)	A	B	L	P	P1	P2	E	F	Y	d3	d4	ℓ	Unit Price		
																	BMBN	BMBNR	
BMBN (Oil Hydraulic)	2	12	1/8	1/4	30	35	170	40	130	-	25	22	7	11	6.6	6.5			
		22	1/4	3/8															
		23	1/4	1/2															
		33	3/8	1/2															
		34	3/8	1/2															
		34	3/8	1/2															
	BMBNR (Water Hydraulic)	3	12	1/8	1/4	30	35	170	40	130	-	25	22	7	11	6.6	6.5		
			22	1/4	3/8														
			23	1/4	1/2														
			33	3/8	1/2														
			34	3/8	1/2														
			34	3/8	1/2														
BMBNR (Water Hydraulic)		*4	12	1/8	1/4	30	35	170	40	130	-	25	22	7	11	6.6	6.5		
			22	1/4	3/8														
			23	1/4	1/2														
			33	3/8	1/2														
			34	3/8	1/2														
			34	3/8	1/2														
	BMBNR (Water Hydraulic)	*5	12	1/8	1/4	30	35	170	40	130	-	25	22	7	11	6.6	6.5		
			22	1/4	3/8														
			23	1/4	1/2														
			33	3/8	1/2														
			34	3/8	1/2														
			34	3/8	1/2														
BMBNR (Water Hydraulic)		*6	12	1/8	1/4	30	35	170	40	130	125	25	22	7	11	6.6	6.5		
			22	1/4	3/8														
			23	1/4	1/2														
			33	3/8	1/2														
			34	3/8	1/2														
			34	3/8	1/2														

⚠ * 4, 5 and 6 are available for BMBN only.

Part Number	Type	No.	d1 Rc(PT)	d2 Rc(PT)	A	B	L	P	P1	P2	E	F	Y	d3	d4	ℓ	Unit Price		
																	BMBN	BMBNR	
BMSN (Pneumatic)	2	11	1/8	1/8	30	30	70	30	55	-	20	20	7	9.5	5.5	5.5			
		12	1/8	1/4															
		22	1/4	1/4															
		55	M5	M5															
		55	M5	M5															
		55N	M5	M5															
	BMSN (Pneumatic)	3	11	1/8	1/8	30	30	100	30	85	-	20	20	7	9.5	5.5	5.5		
			12	1/8	1/4														
			22	1/4	1/4														
			55	M5	M5														
			55	M5	M5														
			55N	M5	M5														
BMSN (Pneumatic)	4	11	1/8	1/8	30	30	130	30	115	-	20	20	7	9.5	5.5	5.5			
		12	1/8	1/4															
		22	1/4	1/4															
		55	M5	M5															
		55	M5	M5															
		55N	M5	M5															
BMSN (Pneumatic)	5	11	1/8	1/8	30	30	160	30	145	-	20	20	7	9.5	5.5	5.5			
		12	1/8	1/4															
		22	1/4	1/4															
		55	M5	M5															
		55	M5	M5															
		55N	M5	M5															
BMSN (Pneumatic)	6	11	1/8	1/8	30	30	190	30	175	95	20	20	7	9.5	5.5	5.5			
		12	1/8	1/4															
		22	1/4	1/4															
		55	M5	M5															
		55	M5	M5															
		55N	M5	M5															

Ordering Example
 Part Number
 BMBN2-12