

Pipe Supports

Vertical Pipe Bands, Paddle Shaped Legs, T-Shaped Legs

Vertical Pipe Bands

Type		Material		Surface Treatment
Standard	With Protection Material	Main Body	Protection Material	Treatment
KBND	KBND	SPHC	Flexible PVC (White)	Trivalent Chromate
KBNDS	-	SUS304	-	-

Standard

With Protection Material Type

*t of KBND means thickness of sheet metal. Thickness of protection material is (1.5).

Part Number		Applicable Pipe O.D. D	L	t			W	C	P	KBND		KBNDS		KBNDD				
Type	No.			KBND	KBNDS	KBNDD				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate			
Standard KBND KBNDS	10A	17.3	73	1.8	2	-	25	45	20	1 - 39 pcs.	40 - 50 pcs.	1 - 9 pc (s).	10 - 20 pcs.	1 - 9 pc (s).	10 - 20 pcs.			
	15A	21.7	77			0.6												
	20A	27.2	84															
	25A	34	88															
With Protection Material Type KBND	32A	42.7	98			0.8												
	40A	48.6	104															
	50A	60.5	116															

☞ Be sure to use KBND in ambient temperature up to 60°C for the properties of flexible PVC. ☞ For orders larger than indicated quantity, please check with WOS.

Paddle Shaped Legs

Type	Material	Surface Treatment
HGA	SS400	Trivalent Chromate
HGAS	SUS304	-

Part Number		L	HGA		HGAS	
Type	No.		Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
HGA HGAS	1	50	1 - 9 pc(s).	10 - 20 pcs.	1 - 9 pc(s).	10 - 20 pcs.
	2	75				
	3	100				

Ordering Example
Part Number
KBND25A
TGA2


☞ For orders larger than indicated quantity, please check with WOS.

T-Shaped Legs

Type	Material	Surface Treatment
TGA	SPHC	Trivalent Chromate
TGAS	SUS304	-

Part Number		L (ℓ)	TGA		TGAS	
Type	No.		Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
TGA TGAS	1S	50	1 - 39 pcs.	40 - 50 pcs.	1 - 9 pc(s).	10 - 20 pcs.
	1	60				
	2	80				
	3	100				

☞ For orders larger than indicated quantity, please check with WOS.

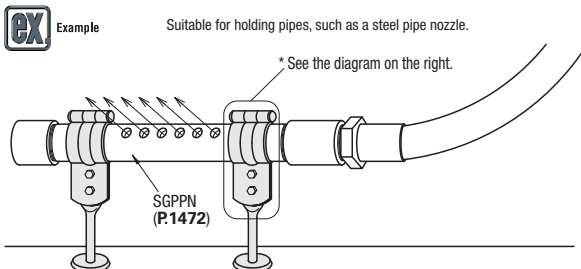

Enlarged view of * marked area

