


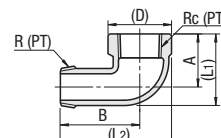
Low Pressure Screw Fittings

Thread Coated Type

■ **Features:** Male threads are coated. Provides immediate out of the box operation.

■ **Steel Pipe Fittings**
Female/Male Elbows

Type	Material	Surface Treatment
SGCEL	FCMB270	Hot Zinc Plating
SUCEL	SCS13A	-


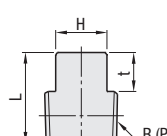
Ⓜ Allowable temperature: 150°C

Part Number	R Rc (PT)	SGCEL					SUCEL					SGCEL		SUCEL		
		(D)	(L1)	(L2)	A	B	(D)	(L1)	A	B	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate		
SGCEL SUCEL	6A	1/8	19	23	36	17	26	14.5	22	33	17	26	1-9 pcs.	10-30 pcs.	1-19 pcs.	20-50 pcs.
	8A	1/4	22	26	42	19	30	21	26	41	19	30				
	10A	3/8	27	31	48	23	35	25	32	48	23	35				
	15A	1/2	31	38	56	27	40	29	38	55	27	40				
	20A	3/4	36	45	66	32	47	36	46	65	32	47				
	25A	1	45	55	76.5	38	54	44	55	76	38	54				

Ⓜ For orders larger than indicated quantity, please check with WOS.

■ **Steel Pipe Fittings**
Plugs

Type	Material	Surface Treatment
SGCPP	FCMB270	Hot Zinc Plating
SUCPP	SCS13A	-


 
Ⓜ Allowable temperature: 150°C

Part Number	R (PT)	Square Size H	t	L		SGCPP		SUCPP	
				SGCPP	SUCPP	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
SGCPP SUCPP	6A	1/8	7	7	16	16			
	8A	1/4	9	8	19	19			
	10A	3/8	12	9	21	21			
	15A	1/2	14	10	26	25			
	20A	3/4	17	11	29	28			
	25A	1	19	12	31	31			

Ⓜ For orders larger than indicated quantity, please check with WOS.

■ **Steel Pipe Fittings**
Round Nipples

Type	Material	Surface Treatment
SGCNP	SGP	Hot Zinc Plating
SUCNP	SUS304	-


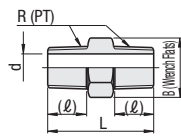
Ⓜ Allowable temperature: 150°C

Part Number	R (PT)	D	L	d		SGCNP		SUCNP	
				SGCNP	SUCNP	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
SGCNP SUCNP	6A	1/8	10.5	24	6.5	6.5			
	8A	1/4	13.8	26	8.7	9.7			
	10A	3/8	17.3	28	12.1	13.1			
	15A	1/2	21.7	34	15.8	15.5			
	20A	3/4	27.2	38	21.6	21.3			
	25A	1	34	42	27.8	28.1			

Ⓜ For orders larger than indicated quantity, please check with WOS.

■ **Steel Pipe Fittings**
Hex Nipples

Type	Material	Surface Treatment
SGCNR	FCMB270	Hot Zinc Plating
SUCNR	SCS13A	-


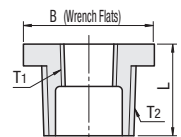
Ⓜ Allowable temperature: 150°C

Part Number	R (PT)	B	L		d		SGCNR		SUCNR	
			SGCNR	SUCNR	SGCNR	SUCNR	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
SGCNR SUCNR	8A	1/4	17	34	34	12.5	12	7	7	
	10A	3/8	21	36	36	13	13	9	9	
	15A	1/2	26	43	42	16.5	16	13	13	
	20A	3/4	32	48	47	18.5	18	18	16	
	25A	1	38	52	52	20	20	24	22	

Ⓜ For orders larger than indicated quantity, please check with WOS.

■ **Steel Pipe Fittings**
Bushings

Type	Material	Surface Treatment
SGCPB	FCMB270	Hot Zinc Plating
SUCPB	SCS13A	-

Ⓜ Allowable temperature: 150°C

Part Number	Rc (PT)	R (PT)	L	B	SGCPB		SUCPB	
					Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
SGCPB SUCPB	12	1/8	1/4	17	17			
	13	1/8	3/8	18	21			
	23	1/4	3/8	18	21			
	24	1/4	1/2	21	26			
	34	3/8	1/2	21	26			
	36	3/8	3/4	24	32			
	46	1/2	3/4	24	32			

Ⓜ For orders larger than indicated quantity, please check with WOS.

Ordering Example
Part Number
SGCEL25A
SGCPP20A

ⓘ Cautions

1. Not applicable to steam plumbing.
2. Once fittings are used, the function of the thread coating resin is impaired. Thus, Wrap seal tape around fittings before use.