


# Thread Conversion Fittings

## L-Shaped / T-Shaped

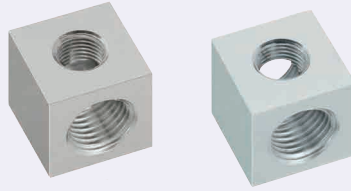


RoHS10

6.3


Type		Material	Surface Treatment	Max. Operating Pressure
L-Shaped	T-Shaped			
APBLM	APBTM	Steel for General Structure SUS304	Electroless Nickel Plating	20.6MPa
APBLS	APBTS			
APBLA	APBTA	Aluminum Alloy	-	1MPa

Thread JIS B 0203 R (PT)  
JIS B 0202 G (PF): ISO 228-1 Interchangeable  
ANSI/ASME B.1.20.1-1983 (NPT)

### L-Shaped

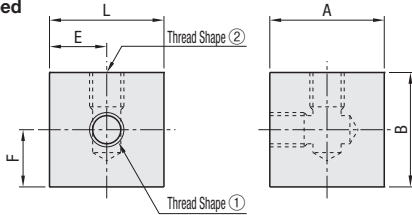

### T-Shaped

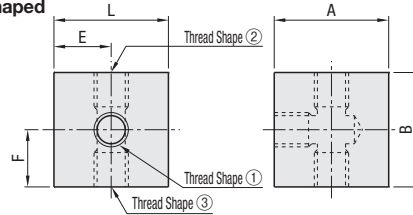

### L-Shaped

Part Number Type	Thread Shape①	No.	T (PT) G (PF) N (NPT)	Thread Shape②	No.	T (PT) G (PF) N (NPT)	L	A	B	E	F	Unit Price				
												APBLM	APBLS	APBLA		
<b>APBLM</b> (SS400) <b>APBLS</b> (SUS304) <b>APBLA</b> (A5052)	T (PT) G (PF) N (NPT)	1	1/8	-	M5	-	25	25 (30)	25 (30)	12.5	12.5 (15)					
				T (PT) G (PF) N (NPT)	1	1/8	25	25 (30)	25 (30)	12.5	12.5 (15)					
					2	1/4	30	30	30	15	15					
					2	1/4	30	30	30	15	15					
		2	1/4	-	M5	-	30	30	30	15	15					
				T (PT) G (PF) N (NPT)	1	1/8	30	30	30	15	15					
					2	1/4	35	35 (40)	35 (40)	17.5	17.5 (20)					
					3	3/8	40	40	40	20	20					
		3	3/8	T (PT) G (PF) N (NPT)	2	1/4	40	40	40	20	20					
					3	3/8	40	40	40	20	20					
					4	1/2	50	50	50	25	25					
					3	3/8	50	50	50	25	25					
		4	1/2				4	1/2	50	50	50	25	25			

Dimensions in ( ) are applicable to SUS304.

### T-Shaped

Part Number Type	Thread Shape①	No.	T (PT) G (PF) N (NPT)	Thread Shape②	No.	T (PT) G (PF) N (NPT)	Thread Shape③	No.	T (PT) G (PF) N (NPT)	L	A	B	E	F	Unit Price		
															APBTM	APBTS	APBTA
<b>APBTM</b> (SS400) <b>APBTS</b> (SUS304) <b>APBTA</b> (A5052)	T (PT) G (PF) N (NPT)	1	1/8	-	M5	-	-	M5	-	25	25 (30)	25 (30)	12.5	12.5 (15)			
				T (PT) G (PF) N (NPT)	1	1/8	25	25 (30)	25 (30)	12.5	12.5 (15)						
					2	1/4	30	30	30	15	15						
					2	1/4	30	30	30	15	15						
		2	1/4	-	M5	-	-	M5	-	30	30	30	15	15			
				T (PT) G (PF) N (NPT)	1	1/8	30	30	30	15	15						
					2	1/4	35	35 (40)	35 (40)	17.5	17.5 (20)						
					2	1/4	40	40	40	20	20						
		3	3/8	T (PT) G (PF) N (NPT)	3	3/8	40	40	40	20	20						
					2	1/4	40	40	40	20	20						
					3	3/8	40	40	40	20	20						
					4	1/2	50	50	50	25	25						
		4	1/2				3	3/8	50	50	50	25	25				
							4	1/2	50	50	50	25	25				
							2	1/4	50	50	50	25	25				
							3	3/8	50	50	50	25	25				

Dimensions in ( ) are applicable to SUS304.



Ordering Example

Part Number - Thread Shape① - Thread Shape② - Thread Shape③  
 APBLM - T1 - T2  
 APBTA - T1 - M5 - M5